



## CE-VX60 / CE-VX60B Vandal X True D/N Dome Camera

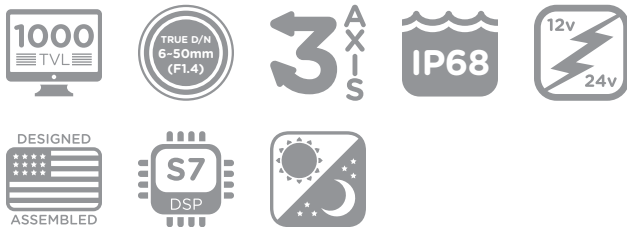


### INFO:

- 1/3" SONY 1.3 Megapixel CMOS Exmor Sensor
- 1,000 TVL Resolution
- 6-50mm (F1.4) Lens (True D/N Version)
- S7 Digital Signal Processor
- OSD Menu Control via Built-in Joystick or CE-REMOTE
- 3-Axis Adjustment
- IP 68 Weather Rated
- Dual Voltage (DC12V/AC24V)
- UL Listed

### DIMENSIONS:

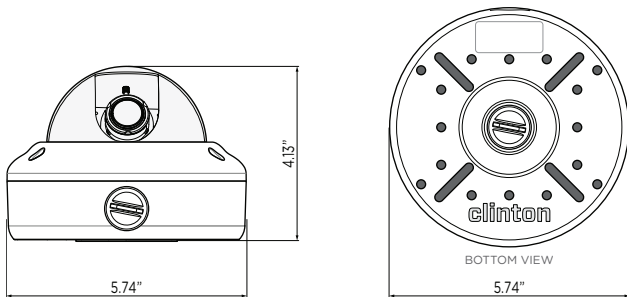

### MOUNTS TO:

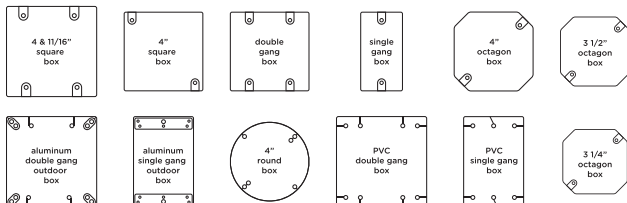

### SPECIFICATIONS:

Camera	
Image Sensor	1/3" SONY 1.3 Megapixel CMOS Exmor Sensor
Resolution	1,000 TVL
Effective Pixels	1305 (H) x 1049 (V), 1.37M Pixels
Scanning System	Progressive
S/N Ratio	52dB
Sync System	Internal
Minimum Illumination	0.00001 Lux (Sens-Up x64)
Shutter Speed	1/60 - 1/60,000 sec.
Dynamic Range	N/A
Lens	6-50mm (F1.4) Lens (True D/N Version)
Video Output	1.0 Vp-p, 75Ω
Frequency	Horizontal: 15.734 KHz, Vertical: 59.94 Hz
Power Consumption	Max. 220mA (DC12V), Max. 110mA (AC24V)
Power Requirement	DC12V / AC24V
Operating Temperature	-20°F - 122°F / -28.8°C - 50°C
Operating Humidity	95% RH Max.
Weather Rating	IP 68
IR LEDs	N/A
Heaters/Fan	N/A
Materials	Aluminum Case w/Polycarbonate Dome
Dimensions	5.74" (Dia.) x 4.13" (H) / 145.8mm (Dia.) x 104.9mm (H)
Weight	1.5 lbs / 680.38g

OSD	
DSP Type	S7
Menu Control	OSD Menu Control via Built-In Joystick or CE-REMOTE
Exposure	Brightness, Shutter, AGC
Sens-Up	Yes (x2 - x64)
White Balance	ATW, AWB, AWC-Set, Manual
Digital Dynamic Range	Yes
Backlight Control	BLC, HLC, WDR
Day/Night	Auto, Color, B&W, External
Noise Reduction	3DNR
Camera Title/ID	N/A
Sync	N/A
Monitor	View Angle (4:3 / 16:9)
Motion Detection	(Intelligent) 4 Zones
Privacy Masking	15 Zones
Digital Image Stabilization	N/A
Dead Pixel Control	N/A
Digital Effects	Digital Zoom, D-WDR, Defog, Image Flip
Languages	English, Chinese, Japanese, Korean
Other	Sharpness, Gamma, Pedestal, Color Gain

ACCESSORIES	
CE-REMOTE	Plug in OSD remote
VXWB / VXWBB	Wall Bracket (White or Black)
VXAP	Adapter Plate for Wall Bracket
VXDC / VXDCB	Deep Case. Additional 1.1" of space. (White or Black)
VXPC	Pendant Cap. Mounts to poles or conduit.
VXDPC	Deep Pendant Cap. Additional 1.1" of space.
VXRM / VXRGB	Recess Mount (White or Black)
VXRW / VXRGB	Rubber Cover (White or Black)

### CERTIFICATIONS:

