

# Manual Stations

The RMS manual pull station is a high quality non toxic die-cast manual pull station manufactured entirely in the U.S.A. Low profile design and smooth edges offer an attractive yet functional design. All components are Powdered coated or have plated surfaces and inhibit corrosion. Electrically the RMS manual pull station is unbeatable with 10 amp snap action switch offered in all possible contact arrangements (including gold contacts). The RMS pull station can be used with or without a break glass rod with replacement requiring no special tools. All stations are Red, unless otherwise indicated.

Other features include

- Lift and pull
- Break glass cover
- Institutional key lock
- Weather and explosion proof versions
- All stations offer hex screw or key lock access
- Private labeling and special options also available
- Brass plated and other color options available



RMS-EXP ( )



RMS ( ) WP



Hex Version



KL Version



Custom Version



RMS-1T-LP/NY



RMS ( ) LP



RMS ( ) KO



RSG / Aames Security 2700 Junipero Ave Signal Hill CA, 90755

P: 562-529-5100 F: 562-529-5102 [www.rsgsecurity.com](http://www.rsgsecurity.com)




# Construction • Material



- Painted Die Cast Housing
- 14 Ga Plated Steel Back Plate
- Corrosion Inhibited Surfaces
- Terminal Block (4 Position)
- Single Gang Mounting
- 10 AMP Snap Action Switch (S.P.S.T., S.P.D.T.)

## ORDERING INFO

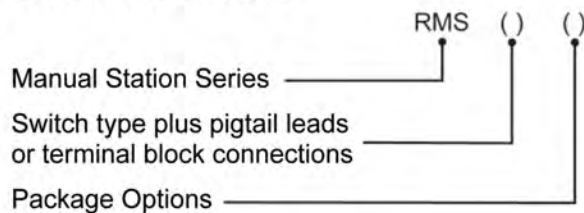

## SPECIFICATIONS

### Electrical

Switch	10 amp @ 120vac
Gold Contact	1.0 amp @ 120vac
Key Switch	0.5 amp @ 30vac
Phone Jack	0.1 amp @ 24vac

### Dimensions

Station	Width	3.200in
	Length	4.750in
	Depth	0.875in
Weight		15.5oz/420 grams
	Mount	Single gang

RMS-DAH	Width	3.325in
	Length	4.750in
	Depth	1.625in
Weight		1lb 9oz/756 grams

RMS-LP and LPH	Width	3.325in
	Length	4.750in
	Depth	1.5in
Weight		1lb 4oz/560 grams

### Options

- 1P S.P.S.T. with pigtails
- 1T S.P.S.T. with terminal block
- 2T D.P.S.T. with terminal block
- 6T D.P.D.T. with terminal block
- PS Presignal key switch 0.5 amp @ 30vdc
- LP Lift and pull dual action adaptor
- LPH Lift and pull dual halon adaptor
- LED Light emitting diode (red/green/yellow)
- GCS S.P.D.T. Gold Contact 1.0amp @ 120vac
- GCD D.P.D.T. Gold Contact 1.0amp @ 120vac
- PJ Phone Jack 0.1 amp @ 24vdc
- KL Key Lock access (specify key type)



Note: Meets UL, FM, CSFM and BSA requirements. Quality pricing/Private labeling available.