



BRANDY

Camera Control Units



POWER -- CONTROL -- VIDEO All Over Two Cat5 Cables

Regulated camera power, remote control, control loop and Y/Pb/Pr or S-Video is carried on dual UTP cable for distances **up to 300'**

BRANDY ONE

Compatible with:

Sony EVI-HD1
BRC-Z330
BRC-H700
BRC-Z700
BRC-H900



BRANDY TWO


Compatible with:

Sony BRC-300
EVI-D70
EVI-D80
EVI-D90
EVI-D100


Signal flow for EVI-HD1 & BRC-300



Sony EVI-HD1 Interface

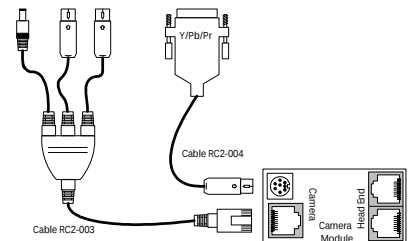

Sony BRC-300 Interface

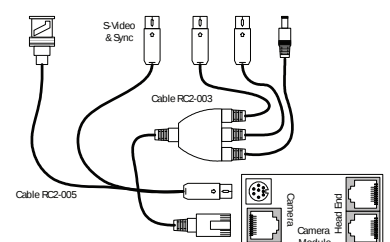

Specs

Dimensions: Head End 1.6"H x 3.5"W x 3.4"D
Camera Module 1.0"H x 1.5"W x 3.5"L

Power Supply: Input 30 VD
Output 12 VDC Regulated for camera power supply

Head End Connections:

Power 5.5mm x 2.5mm
Video Output High density DB-15 Female
Control (main) DB-9 Male
Control Loop 8-Pin mini Din
Remote UTP interface RJ45/8 x2

Camera End Connections:

Remote UTP interface RJ45/8 x2
Video Input 8-Pin mini Din
Power/Control RJ45/10

Rack Mount Option: 4 mounting positions in 1 rack unit