

02iMD1

2.9mm fixed lens, dark grey housing

02iMD1W

2.9mm fixed lens, white housing


Intensifier IP® 1080p Mini-Dome IP Cameras



- Supports up to Full HD resolution @ 30fps
- Built-in standard PoE (IEEE 802.3af)
- No problems caused by objects that reflect or absorb IR light sources
- Presets: Indoor, Outdoor, Elevator, Lobby, Hallway & Low Light
- Supports H.264 and MJPEG codecs
- Sensor input and relay output
- 3-axis lens mount
- IP66 compliant
- Conformant with ONVIF profile S
- 2 year warranty



Optional Accessories

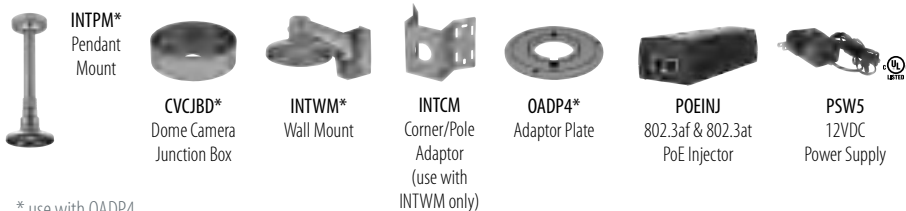

* use with OADP4

02iB3M

2.8-11mm auto iris varifocal motorized lens, dark grey housing

Intensifier IP® 1080p Bullet IP Camera



- See color in low light without IR LEDs
- Motorized lens with auto-focus
- Supports up to Full HD resolution @ 30fps
- Built-in standard PoE (IEEE 802.3af)
- No problems caused by objects that reflect or absorb IR light sources
- Presets: Indoor, Outdoor, Elevator, Lobby, Hallway & Low Light
- Supports H.264 and MJPEG codecs
- Sensor input and relay output
- Built-in heater and anti-fog glass reduces condensation under any weather condition
- IP66 compliant
- Conformant with ONVIF profile S
- 2 year warranty



Optional Accessories



02iB6

2.9mm fixed lens, dark grey housing

Intensifier IP® 1080p Bullet IP Camera



- See color in low light without IR LEDs
- Supports up to Full HD resolution @ 30fps
- Built-in standard PoE (IEEE 802.3af)
- No problems caused by objects that reflect or absorb IR light sources
- Presets: Indoor, Outdoor, Elevator, Lobby, Hallway & Low Light
- Supports H.264 and MJPEG codecs
- Sensor input and relay output
- Built-in heater and anti-fog glass reduces condensation under any weather condition
- IP66 compliant
- Conformant with ONVIF profile S
- 2 year warranty



Optional Accessories



02D7M

3.3-10mm auto iris varifocal motorized lens, dark grey housing

1080p Flush Mount Dome IP Camera with Integrated Junction Box



- Supports up to Full HD 1080p @ 30fps
- Motorized lens with auto focus
- Built-in standard PoE (IEEE 802.3af)
- Flush mount design
- Included junction box integrates with enclosure for wall/ceiling mounting
- Smart IR function provides vivid image with no saturation in darkness
- True Day/Night operation (IR cut filter)
- IR Range: 65' (depending on scene reflection)
- Supports H.264 and MJPEG codecs
- 2-way audio communication
- Micro SD card slot (card not included)
- Sensor input and relay output
- Built-in heater reduces condensation under any weather condition
- IP66 compliant
- Conformant with ONVIF profile S
- 2 year warranty



Optional Accessories

