

HD-TVI 2MP Intensifier® T Traditional Camera

HTINTT5T


Accepts C & CS auto iris & manual type lenses,
dark gray housing

Features

- Full HD resolution over coax (HD-TVI)
- See color in almost complete darkness without IR LEDs
- Supports Full HD 1080p @ 30fps
- No problems caused by objects that reflect or absorb IR light sources
- True WDR operation
- With presets for different scenarios
- Full OSD operation via UTC (TVI output only)
- Additional analog output for 960H
- 12VDC / 24VAC dual voltage operation
- 5 year warranty



lens not included

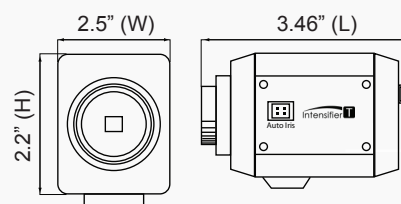

Specifications

Image Sensor	1/3" Progressive Scan CMOS, 2MP
Resolution.....	1080p
Minimum Illumination.....	0.001 lux
Effective Pixels	1984 (H) x 1105 (V)
Total Pixels	2000 (H) x 1121 (V)
TV System.....	NTSC
Scanning Frequency.....	15.734kHz (H) / 59.94Hz (V)
Scanning System.....	Progressive
Synchronization.....	Internal
Communication.....	UTC
S/N Ratio	more than 50dB
Video Output.....	CVBS: 1.0Vp-p / 75 ohms
Electronic Shutter Speed.....	Auto / Manual
OSD.....	Available
DWDR	On / Off (level adjustable)
Backlight Compensation.....	BLC / HLC / Off
Day/Night.....	Color / BW / Auto / Ext

AGC.....	Level adjustable
White Balance	ATW / Push / Manual
Intensify	Auto / Off (selectable x2 - x512)
Motion Detection.....	On / Off (4 programmable zones)
Privacy Masking	On / Off (8 programmable zones)
Speco DNR.....	High / Med / Low / Off
Sharpness	On / Off (level adjustable)
Mirror	On / Off
Power Consumption	12VDC, 150mA / 24VAC, 2W
Power Supply	12VDC / 24VAC dual voltage operation (power supply not included)
Operating Temperature	14° F – 122° F
Storage Temperature.....	-4° F – 140° F
Dimensions.....	2.5" (W) x 2.2" (H) x 3.46" (L)
Weight	1.5 lbs.

Optional Accessories



PSW4
24VAC
Power Supply



PSW5
12VDC
Power Supply



VCH401HBMT
Housing with Heater,
Blower & Bracket



TVIUTPPT
HD Video
Transceiver with
Pigtail (Balun)



TVIUPT
HD Video
Transceiver

Optional Lenses

VFMP2.712DC 2.7-12mm megapixel varifocal lens