


## 2MP Flush Mount Dome IP Camera with Integrated Junction Box

**O2D7M** 3.3-10mm auto iris varifocal motorized lens, dark grey housing

### Features

- Supports up to Full HD 1080p @ 30fps
- Motorized lens with auto focus
- Built-in standard PoE (IEEE 802.3af)
- Adaptive IR LEDs reduce IR saturation
- IR Range: 65' (depending on scene reflection)
- Flush mount design
- Included junction box integrates with enclosure for wall/ceiling mounting
- True Day/Night operation (IR cut filter)
- 2-way audio communication
- Micro SD card slot for edge recording (card not included)
- Sensor input and relay output
- Built-in heater and anti-fog glass reduces condensation
- IP66 compliant, weather resistant
- Conformant with ONVIF profile S
- 5 year warranty\*

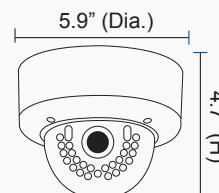

### Camera Specifications

Image Sensor.....Progressive scan 1/2.8" CMOS, 2MP  
 Maximum Resolution .....1920x1080  
 Minimum Illumination .....0 lux (IR LED on)  
 IR Range .....65' (depending on scene reflection)  
 White Balance.....Automatic, Manual  
 Exposure Control .....Yes  
 Digital Slow Shutter.....Yes  
 Backlight.....BLC/HSBLC  
 Day/Night .....IR cut filter  
 DNR.....Yes

### Video Specifications

Supported Resolutions....1920x1080/1280x720/704x480/352x240 @ 30fps  
 Compression .....H.264, MJPEG  
 Bitrate Control .....VBR, CBR  
 Multiple Streaming .....3 streams

### Audio Specifications

Mono Input .....64Kbps G.711  
 Mono Output .....64Kbps G.711

### External Terminal Specifications

Ethernet.....10/100 Mbps  
 Alarm .....1 sensor input, 1 output  
 Video .....BNC out  
 Audio .....1 input, 1 output  
 Power .....DC jack  
 Storage.....Micro SD slot

### Network Specifications

Protocols .....IPv4, TCP, UDP, RTCP, RTP, RTSP, HTTP, HTTPS, SMTP, FTP, DHCP, Bonjour  
 DDNS support.....Speco DDNS (free of charge)

\*Effective on all new purchases as of 2/1/17. Visit [www.specotech.com](http://www.specotech.com) for latest ONVIF® support. ONVIF is a trademark of Onvif, Inc. Apple and the Apple logo are trademarks of Apple Inc., registered in the U.S. and other countries. App Store is a service mark of Apple Inc. Android, Google Play and the Google Play logo are trademarks of Google Inc. Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation. Spec Rev. 3/6/17

### Network Specifications (continued)

Security .....User ID & Password protection, IP address filtering, HTTPS  
 User Access .....10 simultaneous users  
 Performance may vary depending on resolution and number of connections

### System Specifications

PoE.....Standard (IEEE 802.3af)  
 Analytics .....Motion detection (3 regions), tampering alarm, trip zone  
 Alarm Triggers.....Motion, sensor input, tamper detection, trip zone  
 Alarm Events.....FTP video/image file upload, email image upload, micro SD card recording, relay out  
 Video Buffer.....Configurable pre-record & post-record  
 Image Settings .....Privacy mask

### Client Specifications

Web Browser Support.....Windows (Internet Explorer 8 and up)  
 PC Application.....SecureGuard®

### Operating & Unit Specifications

Power Supply .....PoE, 12VDC (power supply not included)  
 Power Consumption.....8W  
 Operating Temperature...-4° F – 122° F  
 Operating Humidity .....8% – 80% RH  
 Unit Dimensions .....4.7" (H) x 5.9" (Dia.)  
 Unit Weight.....2.2 lbs.  
 Certifications .....FCC, RoHS  
 Included in Package.....Unit, CD (manual, software), mounting screws, L wrench

### Optional Accessories



**INTPM**  
Pendant Mount



**INTCM**  
Corner/Pole Adapter (use with INTWM only)



**INTWM**  
Wall Mount



**POEINJ**  
12.95W PoE Injector



**PSW5**  
12VDC Power Supply