

1.1"L×.37"W×.19"H Surface Mount Type W/Center Leads, Side Lead or Terminal Connects



Contact Size: 1.1"L×.37"W×.19"H

(27.8mm×9.5mm×4.75mm)

Standard Magnet Size: 1.1"L×.37"W×.19"H

(27.8mm×9.5mm×4.75mm)

Standard Gap: .5"(12.5mm)

Colors: White, Brown, Tan

12"(305mm) 22 AWG Leads Standard

"TC" Version No Leads

Specifications



Part Number	Gap Inch(mm)	Loop Open/Closed	Reed Form	Max. Contact Rating (W)	Max. Initial Contact Resistance (mΩ)	Max. Switching Voltage (V)	Max. Switching Current (A)
TANE PILL	.5"(12.5)	CLOSED	Normally Open	10	100	AC110/DC100	0.5
TANE PILL SL	.5"(12.5)	CLOSED	Normally Open	10	100	AC110/DC100	0.5
TANE PILL TC	.5"(12.5)	CLOSED	Normally Open	10	100	AC110/DC100	0.5
TANE PILL OL	.43"(11)	OPEN	Normally Closed	3	100	AC30/DC30	0.2

OPERATING TEMPERATURE:-40°C to +60°C

Outline Dimensions

Unit: inch(mm)

TANE PILL/TANE PILL OL

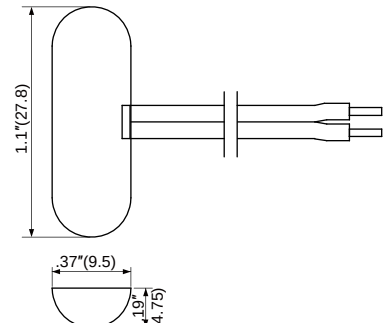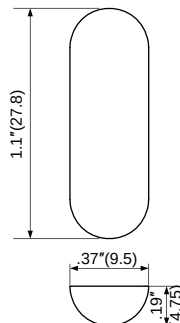

The Best Guarantee Since 1984 : \$50-1

TANE ALARM PRODUCTS

906 JERICHO TURNPIKE, NEW HYDE PARK, NY 11040



 
 
Tel: 800-852-5050 • 516-328-3351 • Fax: 516-326-9125

www.tanealarm.com • E-MAIL: info@tanealarm.com

Outline Dimensions

Unit: inch(mm)

TANE PILL SL

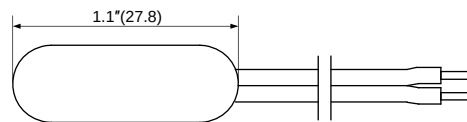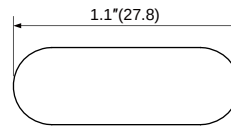

TANE PILL TC

