


Wall and Ceiling Strobes

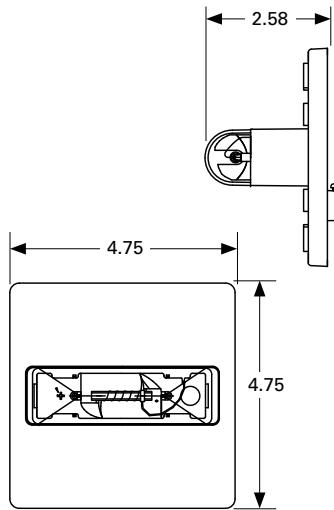

Series **RSS** Wall and Ceiling Strobes

Available features and options:

Finish Color: Red or White

Mounting: Wall or Ceiling

Voltage: 24 VDC

Strobe Candela:

- Wall: 15/30/75/110cd or 135/185 cd (multi-candela models) or 15/75cd (single candela models)
- Ceiling: 15/30/75/95cd or 115/177cd

Backbox Mounting Options: 1 gang, 2 gang, 4" sq., 3.5" octal

Approvals: UL, ULC, CSFM, FM, BFP

Wall Mount Strobes

Model Number	Finish/Ltr	Order Code
15/30/75/110cd		
RSS-24MCW-FR	Red	9400
RSS-24MCW-FW	White	9401
RSS-24MCW-NR	Red, No Ltr	3190
RSS-24MCW-NW	White, No Ltr	8219
RSS-24MCW-ALR	Red, Alert Ltr	4840
RSS-24MCW-ALW	White, Alert Ltr	5842
RSS-24MCW-AR	Red, Agent Ltr	9773
135/185cd		
RSS-24MCWH-FR	Red	3465
RSS-24MCWH-FW	White	3464
1575cd		
RSS-241575W-FR	Red	7471
RSS-241575W-FW	White	7788
RSS-241575W-NW	White, No Ltr	8687

Mounting Options: B, D, E, F, G, H, J, N, O, P, R, X

Ceiling Mount Strobes

Model Number	Finish	Order Code
15/30/75/95cd		
RSS-24MCC-FR	Red	3157
RSS-24MCC-FW	White	3158
RSS-24MCC-NW	White, No Ltr	3183
RSS-24MCC-ALW	White, Alert Ltr	9789
115/177cd		
RSS-24MCCH-FR	Red	3460
RSS-24MCCH-FW	White	3461

Mounting Options: B, D, E, F, G, H, J, N, O, P, R, X

UL Max. Current

16-33 VDC						
Model	15cd	30cd	75cd	110cd	135cd	185cd
RSS - Wall	0.060	0.092	0.165	0.220	0.300	0.420

UL Max. Strobe Current

15/75cd		
Model	16-33 VDC	8-17.5 VDC
RSS - Wall	0.090	0.255

UL Max. Strobe Current

16-33 VDC						
Model	15cd	30cd	75cd	95cd	115cd	177cd
RSS - Ceiling	0.065	0.105	0.189	0.249	0.300	0.420

Note: Reference pages 58-65 for additional mounting information.