

Technical Data – Weatherproof Outlet Boxes

Cooper Crouse-Hinds weatherproof products are manufactured in compliance with U.L. requirements for weatherproof boxes and covers and meet U.L. Standard #514A. Cooper Crouse-Hinds lighting products comply with the U.L. requirements of standard UL 1598 and are suitable for wet locations.

Cooper Crouse-Hinds weatherproof products are rust and corrosion resistant made of rugged die-cast construction. Cooper Crouse-Hinds weatherproof products are provided with necessary gaskets, plugs and screws, making installation trouble free.

All products are powder coat painted and various colors are available.

Cooper Crouse-Hinds weatherproof boxes and covers are individually shrink-wrapped. Cooper Crouse-Hinds weatherproof cast aluminum boxes are lugged except where noted and are provided with plugs. The self-closing weatherproof covers are zinc die-cast. The weatherproof lampholders have porcelain sockets and are rated up to 150 watts and have 8½" wire leads.

Vaporite fixtures are die-cast aluminum and the screw-on guards are die-cast zinc, with Allen-Head set screws for locking in place. The fixtures also have a neoprene gasket and porcelain clip-in socket.


SINGLE GANG WEATHERPROOF OUTLET BOXES – 18.0 CUBIC INCH CAPACITY – 2" DEEP CAST ALUMINUM – UL LISTED FOR WET LOCATIONS




TP7010 – TP7018




TP7026, TP7034

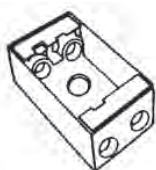

TP7042, TP7050

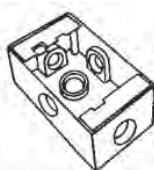


TP7058, TP7066

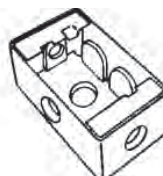

TP7071

Product Number	Description	Outlet Holes	Color	Std. Unit Carton	Wt. Lbs Per 100
TP7010	With Lugs	3-½"	Gray	50	58.3
TP7011	With Lugs	3-½"	White	50	58.3
TP7012	With Lugs	3-½"	Bronze	50	58.3
TP7018	With Lugs	3-¾"	Gray	50	58.3
TP7026	With Lugs	4-½"	Gray	50	58.3
TP7034	With Lugs	4-¾"	Gray	50	58.3
TP7042	With Lugs	5-½"	Gray	50	58.3
TP7050	With Lugs	5-¾"	Gray	50	58.3
TP7058	Side Entry, With Lugs	5-½"	Gray	50	58.3
TP7066	Side Entry, With Lugs	5-¾"	Gray	50	58.3
TP7071	Horiz. Mounting, With Lugs	4-½"	Gray	50	58.3

SINGLE GANG DEEP WEATHERPROOF BOXES – 24.0 CUBIC INCH CAPACITY – 2 ⅝" DEEP CAST ALUMINUM-UL LISTED FOR WET LOCATIONS

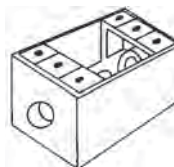


TP7074, TP7078, TP7082

Product Number	Description	Outlet Holes	Color	Std. Unit Carton	Wt. Lbs Per 100
TP7074	With Lugs	3-½"	Gray	25	80
TP7078	With Lugs	3-¾"	Gray	25	80
TP7082	With Lugs	3-1"	Gray	25	80


Weatherproof Outlet Boxes

TWO GANG WEATHERPROOF OUTLET BOXES – 30.5 CUBIC INCH CAPACITY


2" DEEP, ALL TWO GANG BOXES HAVE 2 MOUNTING LUGS AS STANDARD
CAST ALUMINUM-UL LISTED FOR WET LOCATIONS

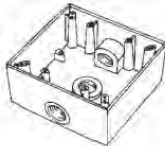


TP7086-TP7090

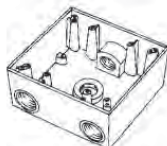


TP7094, TP7098

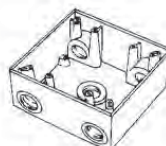

TP7102, TP7106

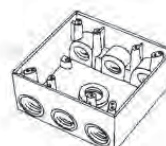


TP7110, TP7114

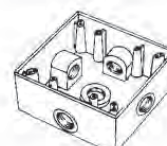


TP7118, TP7122

Product Number	Description	Std. Unit Carton	Color	Wt. Lbs Per 100
TP7086	3-1/2" Holes	10	Gray	83.3
TP7087	3-1/2" Holes	10	White	83.3
TP7088	3-1/2" Holes	10	Bronze	83.3
TP7090	3-3/4" Holes	10	Gray	83.3
TP7094	4-1/2" Holes	10	Gray	83.3
TP7098	4-3/4" Holes	10	Gray	83.3
TP7102	5-1/2" Holes	10	Gray	83.3
TP7106	5-3/4" Holes	10	Gray	83.3
TP7110	7-1/2" Holes	10	Gray	83.3
TP7114	7-3/4" Holes	10	Gray	83.3
TP7118	5-1/2" Holes	10	Gray	83.3
TP7122	5-3/4" Holes	10	Gray	83.3


TWO AND THREE GANG DEEP WEATHERPROOF OUTLET BOXES – 2 5/8" DEEP, ALL BOXES ARE STANDARD WITH MOUNTING LUGS CAST ALUMINUM-UL LISTED FOR WET LOCATIONS

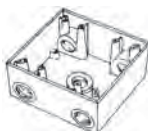

TP7126, TP7130, TP7134

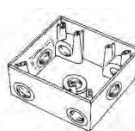

TP7137, TP7138, TP7142

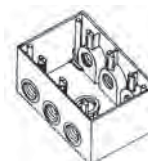

TP7143, TP7144


Product Number	Description	Color	Std. Unit Carton	Capacity Cu. In.	Wt. Lbs Per 100
TWO GANG DEEP WEATHERPROOF OUTLET BOXES					
TP7126	5-1/2" Holes	Gray	6	37	140
TP7130	5-3/4" Holes	Gray	6	37	140
TP7134	5-1" Holes	Gray	6	37	140
TP7137	7-1/2" Holes	Gray	6	37	140
TP7138	7-3/4" Holes	Gray	6	37	140
TP7142	7-1" Holes	Gray	6	37	140
THREE GANG DEEP WEATHERPROOF OUTLET BOXES					
TP7143	7-3/4" Holes	Gray	5	59	159
TP7144	7-1" Holes	Gray	5	59	159

Photoelectric Lighting


PHOTOELECTRIC LIGHTING CONTROLS



TP7920

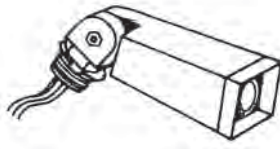

TP7924 – TP7925

 

TP7927 – TP7928

Product Number	Description	Std. Unit Pkg.	Wt. Lbs Per 100
TP7920	300W Photo Cell With Plate 120V	10	50
TP7924	300W Swivel Photo Cell 120V	10	8.3
TP7925	1200W Swivel Photo Cell 120V	10	8.3
TP7927	300W Photo Cell 120V	10	8.3
TP7928	1000W Photo Cell 208-277V	10	8.3


CLOSURE PLUGS – ZINC DIE-CAST†

Product Number	Description	Std. Unit Pkg.	Color	Wt. Lbs Per 100
TP7940	1/2"	100	Gray	1.5
TP7942	1/2"	100	Bronze	1.5
TP7944	3/4"	50	Gray	2.1

† CSA Certified

DIMENSIONAL DATA

Single Gang Boxes

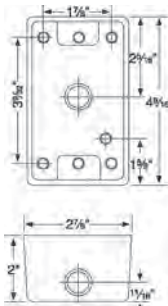


TP7010 – TP7071

Single Gang Deep Boxes



TP7074 – TP7082

Two Gang Boxes

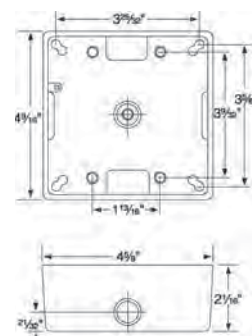

TP7086 – TP7122