

Swifts® SW steel wire cable tray




TRAY LENGTHS									
Width (mm)	28 mm depth electroplated zinc	28 mm depth hot dip galvanised	28 mm depth stainless steel	52 mm depth electroplated zinc	52 mm depth hot dip galvanised	52 mm depth stainless steel	102 mm depth electroplated zinc	102 mm depth hot dip galvanised	102 mm depth stainless steel
50	CM540050	CM542050	CM000014	CM541050	CM543050	CM000064	–	–	–
100	CM540100	CM542100	CM000024	CM541100	CM543100	CM000074	CM746621	CM746623	CM000084
150	CM540150	CM542150	CM000034	CM541150	CM543150	CM000084	–	–	–
200	CM540200	CM542200	CM000044	CM541200	CM543200	CM000094	CM746641	CM746643	CM000094
300	CM540300	CM542300	CM000054	CM541300	CM543300	CM000104	CM746661	CM746663	CM000094
400	–	–	–	CM541400	CM543400	CM000204	CM746681	CM746683	CM000094
450	–	–	–	CM541450	CM543450	CM000254	–	–	–
500	–	–	–	CM541500	CM543500	CM000304	CM746701	CM746703	CM000094
600	–	–	–	CM541600	CM543600	CM000404	CM746721	–	–

	FIXINGS AND FASTENINGS											
Finish	Preclic couplers	EZR couplers	Joint strips 275 mm ⁽¹⁾	Faslock S	Faslock XL	Luminaire support (base coupler)	Nuts and coach bolts	Hold down clamps	Turbo kits (A)	Turbo kits (B)	Fixing kits (A)	Fixing kits (B)
												
Electroplated zinc	–	–	CM558221	–	–	–	CM801011	CM558051	CM558071	CM558061	CM558081	CM558091
Hot dip galvanised	CM558103	CM558123	CM558223	–	–	–	–	–	–	–	–	–
Pre-galvanised	CM558100	CM558120	–	CM558340	CM558320	CM558410	–	–	–	–	–	–
Stainless steel	CM558104	–	CM558224	CM558344	CM558324	CM558414	CM801014	CM558054	–	–	CM558084	CM558094
Dacromet	–	–	–	CM558347	CM558327	CM558417	CM801017	CM558053	CM558077	CM558067	CM558087	CM558097

PROFILE BRACKETS									
For tray widths (mm)	Profile cantilever arms pre-galvanised	Profile cantilever arms hot dip galvanised	Profile cantilever arms stainless steel	Profile roof cantilever arms pre-galvanised	Profile roof cantilever arms hot dip galvanised	Profile roof cantilever arms stainless steel	Profile trapeze hangers pre-galvanised	Profile trapeze hangers hot dip galvanised	Profile trapeze hangers stainless steel
50	–	–	–	–	–	–	CM013150	CM013153	CM013154
100	CM556100	CM556103	CM556104	CM556300	CM556303	CM556304	CM013200	CM013203	CM013204
150	CM556110	CM556113	CM556114	CM556310	CM556313	CM556314	CM013300	CM013303	CM013304
200	CM556120	CM556123	CM556124	CM556320	CM556323	CM556324	CM013300	CM013303	CM013304
300	CM556130	CM556133	CM556134	CM556330	CM556333	–	CM013400	CM013403	CM013404
400	CM556140	CM556143	–	CM556340	CM556343	–	CM013500	CM013503	CM013504
450	CM556150	CM556153	–	CM556350	CM556353	–	CM013600	CM013603	CM013604
500	–	–	–	–	–	–	CM013600	CM013603	CM013604
1 000 ⁽²⁾	–	–	–	–	–	–	CM013010	CM013013	CM013014
3 000 ⁽²⁾	–	–	–	–	–	–	CM013030	CM013033	CM013034


ANCILLARY ITEMS									
Finish	Earth terminal supports	Profile strut back plates	Universal conduit take-off plates	Conduit take-off plate – side	Switch box take-off plates	Terminal box fixing plate	Universal mounting plate – large	Universal mounting plate – small	Cable dropout plates
Hot dip galvanised	CM585093	CM557803	–	–	–	–	CM586133	CM586063	–
Pre-galvanised	CM585090	CM557800	CM585410	CM585110	CM585130	CM585120	CM586130	CM586060	CM585160
Stainless steel	CM585094	CM557804	–	CM585114	CM585134	–	CM586134	CM586064	CM585164
Dacromet	–	–	CM585417	–	–	–	–	–	CM585167

Swifts® SW steel wire cable tray profile brackets

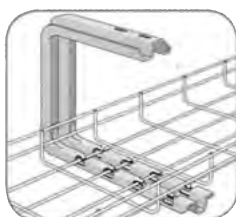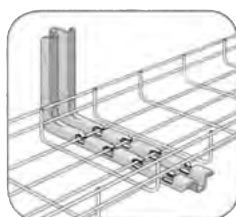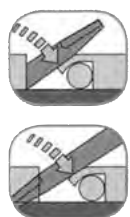


CM556120


CM556320

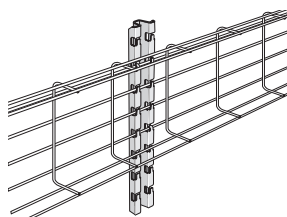

CM013300

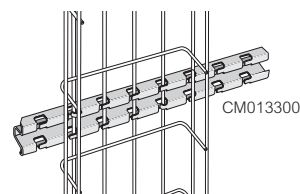

CM013300



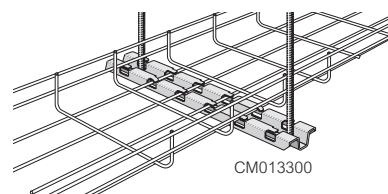


CM013300







Selection chart (p. 68-69)
Dimensions and technical information (p. 85)

Pack	Cat. Nos.	Brackets	
Profile cantilever arms			
	GS	For tray width (mm)	Actual width (W) (mm)
1	CM556100	100	178
1	CM556110	150	228
1	CM556120	200	278
1	CM556130	300	378
1	CM556140	400	478
1	CM556150	450	528
GC			
1	CM556103	100	178
1	CM556113	150	228
1	CM556123	200	278
1	CM556133	300	378
1	CM556143	400	478
1	CM556153	450	528
SS			
1	CM556104	100	178
1	CM556114	150	228
1	CM556124	200	278
1	CM556134	300	378
Profile roof cantilever arms			
	GS	For tray width (mm)	Actual width (W) (mm)
1	CM556300	100	178
1	CM556310	150	228
1	CM556320	200	278
1	CM556330	300	378
1	CM556340	400	478
1	CM556350	450	528
GC			
1	CM556303	100	178
1	CM556313	150	228
1	CM556323	200	278
1	CM556333	300	378
1	CM556343	400	478
1	CM556353	450	528
SS			
1	CM556304	100	178
1	CM556314	150	228
1	CM556324	200	278
Profile pendants			
	GS	Pendant depth (D) (mm)	
1	CM556630	300	
1	CM556600	400	
1	CM556610	500	
GC			
1	CM556633	300	
1	CM556603	400	
1	CM556613	500	

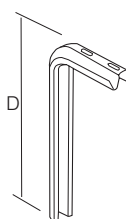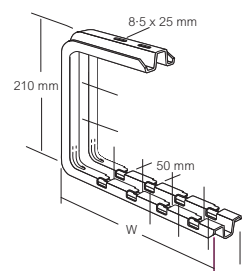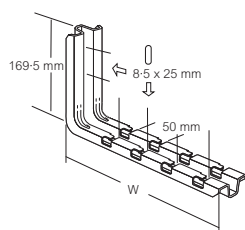


Pack	Cat. Nos.	Brackets (continued)	
Profile trapeze hangers			
Can also be used for wall and floor mounting			
	GS	For tray width (mm)	Actual width (W) (mm)
1	CM013150	50	150
1	CM013200	100	200
1	CM013300	150 and 200	300
1	CM013400	300	400
1	CM013500	400	500
1	CM013600	450 and 500	600
1	CM013010	Cut to length	1 000
1	CM013030	Cut to length	3 000
	GC		
1	CM013153	50	150
1	CM013203	100	200
1	CM013303	150 and 200	300
1	CM013403	300	400
1	CM013503	400	500
1	CM013603	450 and 500	600
1	CM013013	Cut to length	1 000
1	CM013033	Cut to length	3 000
	SS		
1	CM013154	50	150
1	CM013204	100	200
1	CM013304	150 and 200	300
1	CM013404	300	400
1	CM013504	400	500
1	CM013604	450 and 500	600
1	CM013014	Cut to length	1 000
1	CM013034	Cut to length	3 000
Profile strut back plates			
Used to fit profile supports to Swiftrack channel with M8 bolts and channel nuts			
	GS		
1	CM557800		
	GC		
1	CM557803		
	SS		
1	CM557804		

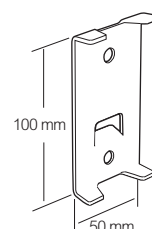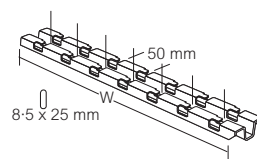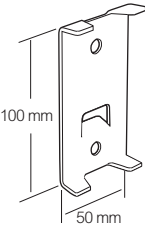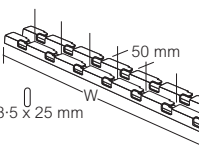


Swifts® SW steel wire cable tray profile brackets

■ Installation example

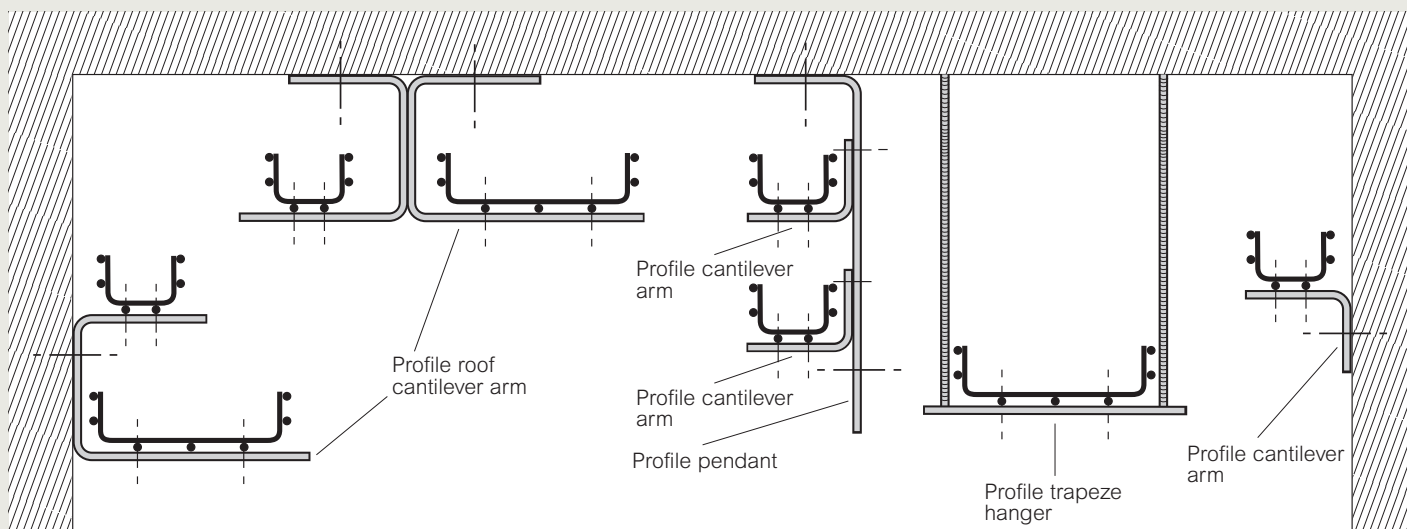


■ Profile cantilever arms

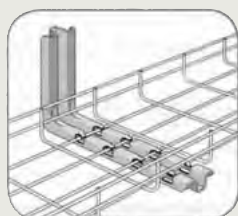

Cat. Nos. ⁽¹⁾ GS	For tray widths (mm)	Actual width (mm)	Max load (kg)
CM556100	100	178	130
CM556110	150	228	110
CM556120	200	278	85
CM556130	300	378	73
CM556140	400	478	56
CM556150	450	528	50

(1) See p. 74 for other finishes


■ Profile roof cantilever arms

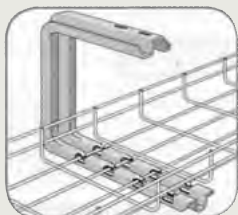


Cat. Nos. ⁽¹⁾ GS	For tray widths (mm)	Actual width (mm)	Max load (kg)
CM556300	100	178	120
CM556310	150	228	100
CM556320	200	278	80
CM556330	300	378	70
CM556340	400	478	48
CM556350	450	528	44

(1) See p. 74 for other finishes


■ Profile trapeze hangers

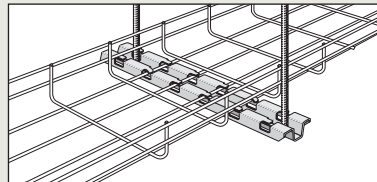

Use with 6 or 8 mm threaded rod

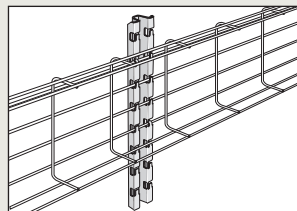



Can also be used to horizontally mount SW tray on walls (15 mm stand-off)

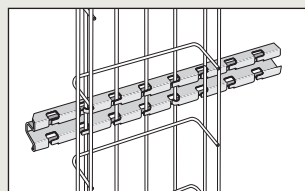

Can also be used to vertically mount SW tray on walls (15 mm stand-off)

NOTE : Can also be used to mount SW tray on floors (15 mm stand-off)

■ Profile strut back plates

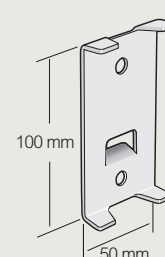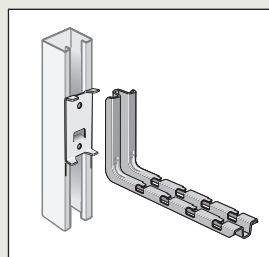

Used to fit profile supports to Swifttrack channel with M8 bolts and channel nuts

All dimensions (mm) are nominal