
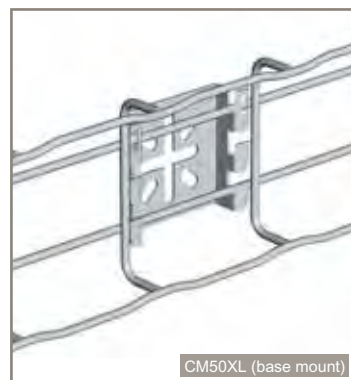
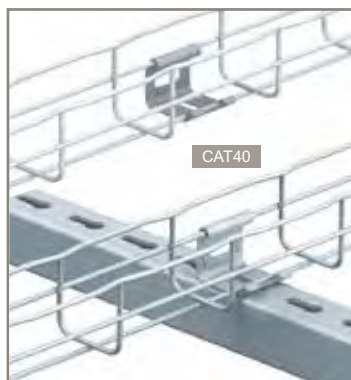
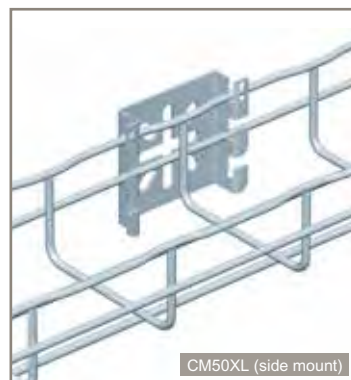
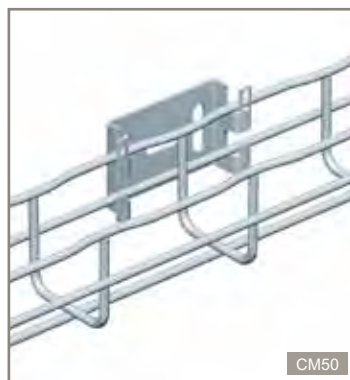
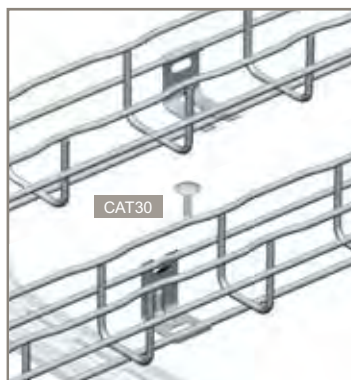
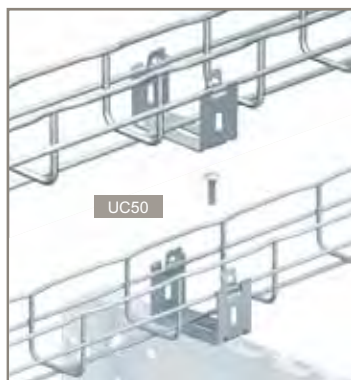


wall mounting – UC50 - CAT30 - CAT40 - CM50 - CM50XL

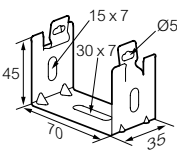



Dimensions and technical information p. 52-55

 
NOTE : please use Cat. No. when placing your order


Pack	Cat. Nos.		UC50 – support cradles
	GS	GC	
1	CM586040	CM586043	⬆️ 30 → 54 mm ⬅️ 50 mm For technical information, see p. 52 ⬇️ daN 12 
1	304L	316L	
	CM586048	CM586044	12

NOTE : please use Cat. No. when placing your order

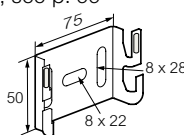Pack	Cat. Nos.		CM50 – universal mounting plates (small)
	GS	GC	
1	CM586060	CM586063	⬆️ 54 mm ⬅️ 50 mm For technical information, see p. 55 
1	304L	316L	
	CM586068	CM586064	

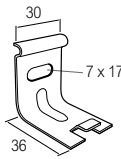		CAT30 – cantilever arm fixing plates	
		GS	GC
1	CM586050	CM586057	⬆️ 30 → 54 mm ⬅️ 50 mm For technical information, see p. 53 ⬇️ daN 20 
1	304L	316L	
	CM586058	CM586054	20



		CAT40 – channel fixing plates	
		GS	GC
1	CM586190	CM586197	⬆️ 30 → 54 mm ⬅️ 50 mm For technical information, see p. 54 ⬇️ daN 20 
1	304L	316L	
	–	CM586194	20

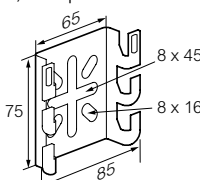		CM50XL – universal mounting plates (large)	
		GS	GC
1	CM586130	CM586133	⬆️ 54 → 80 mm ⬅️ 50 → 100 mm (side wire mounting) ⬆️ 30 → 105 mm ⬅️ 100 → 600 mm (base wire mounting) For technical information, see p. 55 
1	304L	316L	
	CM586138	CM586134	

Key :		304L	Stainless steel 304L
GS	Pre-galvanised	316L	Stainless steel 316L
GC	Hot dip galvanised after manufacture	For detailed information related to finishes, refer to p. 116-117	
DC	Geomet		

All dimensions (mm) are nominal

other mounting - universal mounting plates - CM50 – CM50XL – CAT40 – CM50XXL – CM50WL

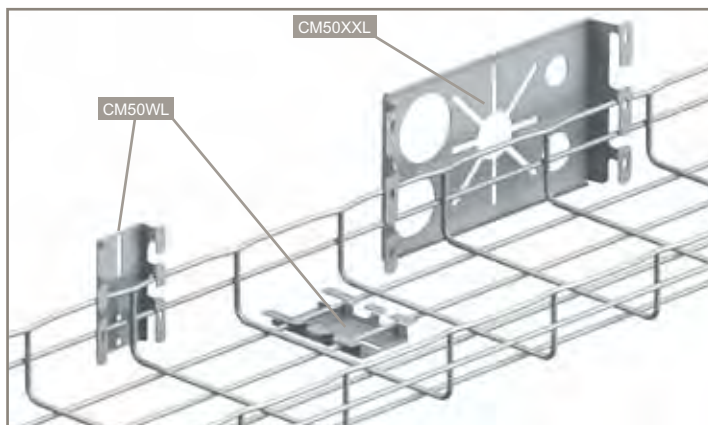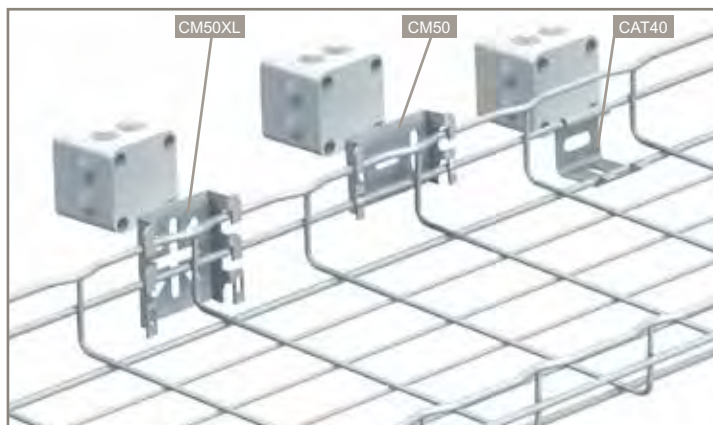

Dimensions and technical information p. 87-88

NOTE : please use Cat. No. when placing your order

Pack	Cat. Nos.	Universal mounting plates
		CM50 – universal mounting plates (small) $\updownarrow$ 30 / 54 / 105 mm $\rightarrow$ 50 $\rightarrow$ 600 mm For technical information see p. 87
1	GS CM586060 304L CM586068	GC CM586063 316L CM586064
1		
		CM50XL – universal mounting plates (large) $\updownarrow$ 30 / 54 / 105 mm $\rightarrow$ 50 $\rightarrow$ 600 mm For technical information see p. 87
1	GS CM586130 304L CM586138	GC CM586133 316L CM586134
1		
		CAT40 – universal mounting plates $\updownarrow$ 30 / 54 / 105 mm $\rightarrow$ 50 $\rightarrow$ 600 mm For technical information see p. 87
1	GS CM586190	DC CM586197 316L CM586194

NOTE : please use Cat. No. when placing your order

Pack	Cat. Nos.	Universal mounting plates (continued)
		CM50XXL – universal mounting plates (extra large) $\updownarrow$ 30 $\rightarrow$ 105 $\rightarrow$ 50 $\rightarrow$ 600 mm For technical information see p. 88
1	GS CM586250	DC CM586257
		CM50WL – universal Wieland mounting plates $\updownarrow$ 30 $\rightarrow$ 105 $\rightarrow$ 50 $\rightarrow$ 600 mm For technical information see p. 88
1	GS CM586230	Z+ CM586237

Key :

GS Pre-galvanised

GC Hot dip galvanised after manufacture

Z+ Continuous galvanisation before manufacture

DC Geomet

304L Stainless steel 304L

316L Stainless steel 316L

All dimensions (mm) are nominal

For detailed information related to finishes, refer to p. 116-117