



Electronic Ignitors for HID lamp circuits (India)

SN57

Electronic ignitors for HID lamps


Product data

General Information	
Application Code	57/02
Lamp Type	SON
Operating and Electrical	
Input Voltage	220/240 V
Input Frequency	50 to 60 Hz
Igniton Type	Semi-Parallel
Temperature	
T-Ambient (Max)	90 °C
T-Ambient (Min)	-20 °C
T-Case Maximum (Max)	80 °C

Product Data	
Full product code	871150099636700
Order product name	SN57
EAN/UPC - Product	8711500996367
Order code	913702261112
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	50
Material Nr. (12NC)	913702261112
Net Weight (Piece)	0.051 kg

Electronic Ignitors for HID lamp circuits (India)

Dimensional drawing

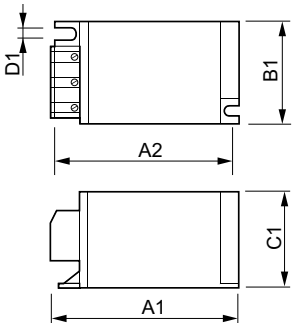

SN 57/02

Product	D1	C1	A1
SN57	4.3 mm	37.5 mm	76.0 mm

