

Streamlined Design Uncompromising Sound



D 10 USB



D 10 USB

Made for office professionals working in Unified Communications environments, the Sennheiser D 10 USB is a single-sided wireless DECT headset for connecting directly to the softphone/PC. Designed for all-day use, its streamlined design makes no compromises when it comes to exceptional sound and brings the freedom of a wireless solution within reach of even more everyday users.

Sound leadership

Sennheiser Voice Clarity delivers wideband sound for a natural listening experience, while a noise-cancelling microphone gives perfect speech transmission. Digital Signal Processing (DSP) gives a clearer sound with echo canceling and audio equalization.

Quality design

With plug and play UC compatibility, the D 10 USB has a streamlined design featuring built-in cable management, magnetic charge interface for secure placement and status indicators to show available talk time. Its lightweight headset offers 2-in-1 wearing styles with headband or ear hook.

User focus

The D 10 USB has a built-in ringer and is UC optimized for maximum productivity

with leading UC platforms. With a range of up to 55 m (180 ft) in a typical office environment, it provides a full workday of talk time with fast charging of up to 50% in just 20 minutes. DECT spectrum wireless connectivity does not interfere with nearby WIFI devices and gives a cleaner, more stable sound. Use up to 4 headsets per conference call from the same base station and take advantage of convenient hot desking. Easy one-touch call management* for control on the go. Sennheiser patented ActiveGard® technology provides hearing protection against acoustic shock.

Features and Benefits:

- UC optimized – for maximum productivity with leading UC platforms
- Sennheiser Voice Clarity – wideband sound for natural listening experiences
- Advanced wideband audio using CAT-iq technology
- Single connectivity – Connects directly to your softphone/PC
- Noise-cancelling microphone – for perfect speech transmission
- DSP (Digital Signal Processing) – for echo canceling and audio equalization
- Secure base station with solid metal plate for stability


- Built-in cable management keeps your desk tidy
- Magnetic charge interface for secure placement when charging
- Status indicators show available talk time
- 2-in-1 wearing style (headband or ear hook) for all-day use
- Built-in ringer with choice of three ring-tones and adjustable ring volume
- Energy saving DECT technology delivers a full workday of talk time
- Fast charging delivers 50% in just 20 minutes
- Long distance wireless range – up to 180 m (590 ft) with line of sight – 55 m (180 ft) in typical office environment
- Convenient phone conferencing with up to 4 headsets per call and simple hot desking
- One-touch call management – answer/end, vol. +/-, mute for control on the go
- DIP switches for easy product setup
- DECT protected frequency band without interference with WIFI networks
- Efficient encryption for secure conversations
- Full workday of talk time – 8 hours wideband and 12 hours narrowband
- Sennheiser Updater – for convenient and instant software upgrade
- ActiveGard® technology – hearing protection against acoustic shock
- Two years warranty for peace of mind

Product Information

Product name	D 10 USB - EU	D 10 USB - US	D 10 USB - AUS
Order name	D 10 USB - EU	D 10 USB - US	D 10 USB - AUS
Art. No.	506412	506414	506415
EAN No.	40 44155 09706 1	40 44155 09708 5	40 44155 09709 2
UPC No.	6 15104 26131 0	6 15104 26136 5	6 15104 26137 2
Product description	Wireless DECT headset (monaural) with base station, for softphones, convertible (headband or ear hook)		
Technical Data			
DECT for EU, AUS	DECT CAT-iq (1.880 to 1.900 MHz)		
DECT for US	DECT 6.0 (1.920 to 1.930 MHz)		
GAP compatible	Yes (Headset)		
Headset	Connects to Base Station/Base set		
Base Station	Connects to softphone/PC		
Headset Auto Link to Base	Yes, can be activated on the base station		
Firmware requirement	For newest version please check Sennheiser Updater at sennheiser.com/cco/software		
Softphone call control software	For PC software enabling call control please check sennheiser.com/cco/software		
UC compatible	Yes. For further information, please refer to: sennheiser.com/headsetcompatibility		
Microphone			
Frequency response Wideband Mode	150 Hz – 6.8 KHz		
Frequency response Narrowband Mode	300 Hz – 3.5 KHz		
Mute Microphone	Yes		
Speaker			
Speaker type	Neodymium Magnet Speaker		
Frequency response Wideband Mode	150 Hz – 6.8 KHz		
Frequency response Narrowband Mode	300 Hz – 3.5 KHz		
General Data			
Operational temperature range	+5 °C to + 45 °C (+41 °F to +113 °F)		
Storage temperature range	-20 °C to + 70 °C (-4 °F to +158 °F)		
Weight, ear hook version	22 g / 0.78 oz		
Weight, headband version	50 g / 1.76 oz		
Ear pad size	ø 50 mm / 1.96 in		
Battery (Lithium Polymer)	Exchangeable for service (see user manual)		
Range – line of sight	180 m / 590 ft		
Range – in typical office building	55 m / 180 ft		
Automatic power adjustment	Yes (distance between headset and base)		
Talk time in Wideband Mode	Up to 8 hours		
Talk time in Narrowband Mode	Up to 12 hours		
Stand by time	Up to 100 Hours		
Auto – headset OFF when out of range	Yes ➡ after 30 minutes		
Charge time 0 – 50%	20 minutes		
Charge time 0 – 100%	1 hour		
Packaging			
Dimension of product packaging (H x W x D)	6.0 x 15 x 20.5 cm / 2.36 x 5.91 x 8.07 in		
Package weight (incl. complete product and packaging)	585 g / 20.64 oz		
Units in distributor master carton	10		
Master carton weight incl. products	7.26 kg / 16 lbs		
Dimension of master carton (H x W x D)	20 x 38.5 x 52 cm / 7.87 x 15.16 x 20.47 in		
Safety			
Automatic Acoustic Shock Protection	YES ➡ ActiveGard®		
EU/AUS Limiter depending on regional variant	YES ➡ Activation by dip switch		
Delivery content			
<div><div></div><div><div>■ Headset</div><div>■ Base station</div><div>■ USB cable</div><div>■ Headband (detachable)</div><div>■ 1 bendable ear hook (mounted on headset)</div><div>■ Printed Quick Guide</div><div>■ Printed Safety Guide</div></div></div>			

Product Information

Accessories				
	Order name	Art. No.	EAN No.	UPC No.
Ear hook with leatherette sleeve	EH 10 B with sleeve	506454	40 44155 098143	6 15104 26278 2
Ear hook fixed (S, M and L size)	EH set DW 10 F	504352	40 44155 050868	6 15104 18035 2
Power supply EU	UNI PS EU 01	94707	40 12418 947071	6 15104 94707 8
Power supply UK	UNI PS UK 01	92892	40 12418 928926	6 15104 92892 3
Power supply US	UNI PS US 01	92893	40 12418 928933	6 15104 92893 0
Power supply AUS	UNI PS AUS 01	520334	40 44156 023083	6 15104 13459 1
Single components				
	Order name	Art. No.	EAN No.	UPC No.
Single headset of D 10	D 10 HS	506420	40 44155 097146	6 15104 26146 4
D 10 Base set for D 10 series (EU)	D 10 BS USB - EU	506432	40 44155 097276	6 15104 26160 0
D 10 Base set for D 10 series (US)	D 10 BS USB - US	506434	40 44155 097290	6 15104 26162 4
D 10 Base set for D 10 series (AUS)	D 10 BS USB - AUS	506435	40 44155 097306	6 15104 26163 1
NOTE: Headset and base station can be purchased separately. This allows a 2nd headset to be added to any D 10 Series base station or used as a spare. Base including USB cable.				
Spare parts				
	Order name	Art. No.	EAN No.	UPC No.
Spare black headband with earpad	SHS 06 D 10 Black	506520	40 44155 207859	6 15104 27131 9
Spare headband with earpad	SHS 05 D 10	506443	40 44155 097382	6 15104 26171 6
Ear pad	HZP 25 DW 10	504349	40 44155 050837	6 15104 18031 4
Base station foot D 10	Spare foot D 10	506444	40 44155 097399	6 15104 26172 3
Ear hook bendable	EH DW 10 B	504370	40 44155 051049	6 15104 18062 8
Spare battery	DW BATT 03	504374	40 44155 051087	6 15104 18067 3
USB cable	USB cable - DW	504363	40 44155 050974	6 15104 18051 2

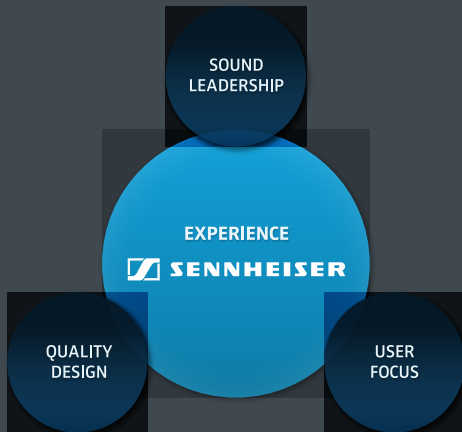

Experience Sennheiser

Perfection is always relative: Users have different expectations from their headsets and speakerphones depending on their needs. For professional users, that need is to communicate as effectively as possible.

With Sennheiser's range of headsets and speakerphones, the combination of exceptional HD sound, quality design and build – and a focus on real life usability – give the best performance possible in busy offices, call centers and Unified Communications environments.

Please visit us at: www.sennheiser.com/cco



Sennheiser is one of the world's leading manufacturers of headphones, microphones, wireless transmission systems and high-quality headsets for both business and entertainment.

Drawing on the electro acoustics expertise of Sennheiser and the leading hearing healthcare specialist William Demant, Sennheiser Communications' wireless and wired headsets and speakerphones for contact centers, offices and Unified Communications professionals are the result of Sennheiser's and William Demant's joint leadership in sound quality, design, wearing comfort and hearing protection.

For further information, please visit:
www.sennheiser.com/cco

Sennheiser Communications A/S

Industriparken 27 · DK-2750 Ballerup · Denmark