



All measurements are approximate and are provided for informational purposes only. Refer to the product Installation Instructions.

Dimensions

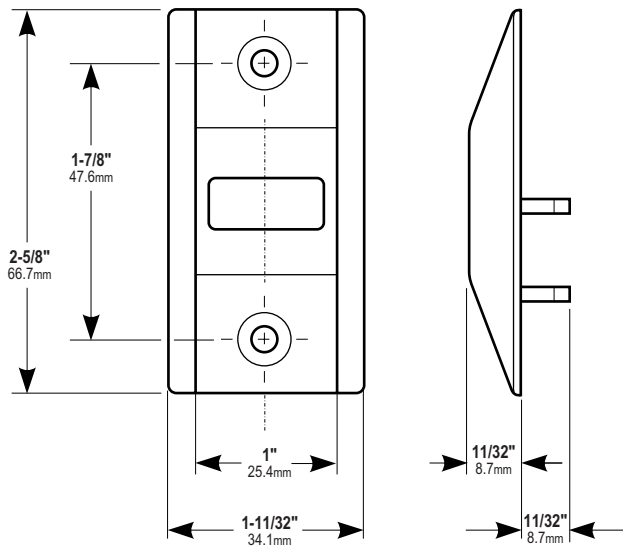


HEADER SIGN - IN TWO PIECES*

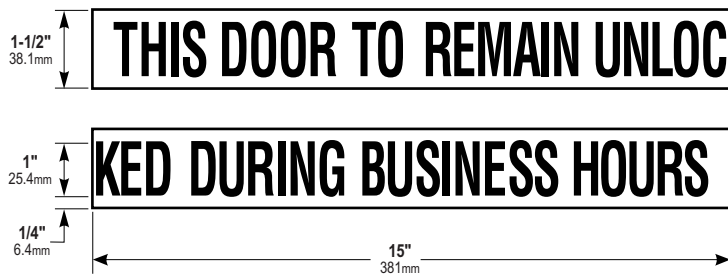

*THIS SIGN CORRECT UNDER UNIFORM BUILDING CODE. ALSO INCLUDES NFPA WORDING
"THIS DOOR TO REMAIN UNLOCKED WHEN THE BUILDING IS OCCUPIED".


Aluminium Stile Preparation

FOR 31/32" OR 1-1/8" BACKSET

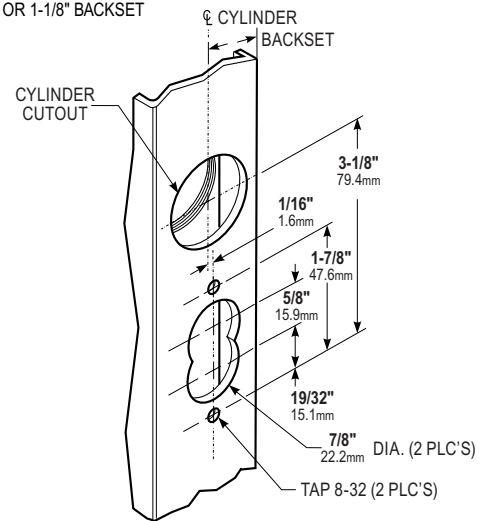

Wood and Hollow Metal Stile Preparation

FOR 1-1/2" BACKSET

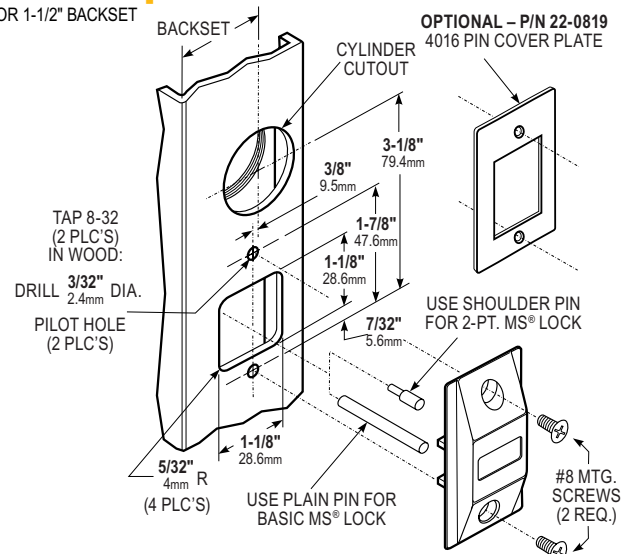

4089 EXIT INDICATOR

Specify quantity and the following information. Order related products separately.

	OPTIONS	FINISH
4089	-01	-130
	00 Standard 1-3/4" Door	119 To match 335 Black Anodized
	01 For Inverted Lock	121 To match 313 Dark Bronze Anodized
	20 For Doors up to 2-1/2"	130 To match 628 Clear Anodized

Standard unit fits 1-3/4" doors

RELATED PRODUCTS

When purchasing this product, please consider the following related products, available separately:

Accessories

91-0912 Adapter Plate, 20-0255-IP Header Sign,
20-0256-IP IBC Header Sign, 22-0819 Pin Cover
Plate for 4016.

COMPATIBLE PRODUCTS

This product is compatible with the following products:

Deadlocks

MS1830, MS1837, MS1850S(-050), SCH1850S,
MS1850SN(-050), SCH1850SN, MS1950(-050), MS+1890.

Flushbolts

1870 Cylinder-Operated Flushbolt.