

**DESCRIPTION:**

The IX-MV is an IP addressable video master station with a 3.5" color LCD monitor. It can be wall or desk mounted (desk stand included). The IX-MV offers handset (duplex) and hands-free (VOX/PTT) communication and can page up to 5 zones simultaneously. The station is equipped with a door release button to unlock doors remotely. The IX-MV is equipped with brightness adjustment, giving the user control for camera lighting to better see the visitor requesting entry. Six programmable speed buttons provide quick and easy access to frequently called stations or groups. The IX-MV connects directly to a network using CAT-5e/6 cable and can communicate with any other IX Series station on its network. The station utilizes 802.3af compliant PoE.


IX-MV FEATURES:

- 3.5" LCD color monitor
- Handset for privacy or hands-free VOX / PTT communication
- Door release button
- Brightness control
- 6 programmable speed dial buttons for calling stations or accessing paging zones
- Wall or desk mount (stand included)
- Connects using CAT-5e/6 cable
- 802.3af PoE compliant

IX-MV

IP Addressable Master Station for the IX Series

FEATURE CALL-OUT:

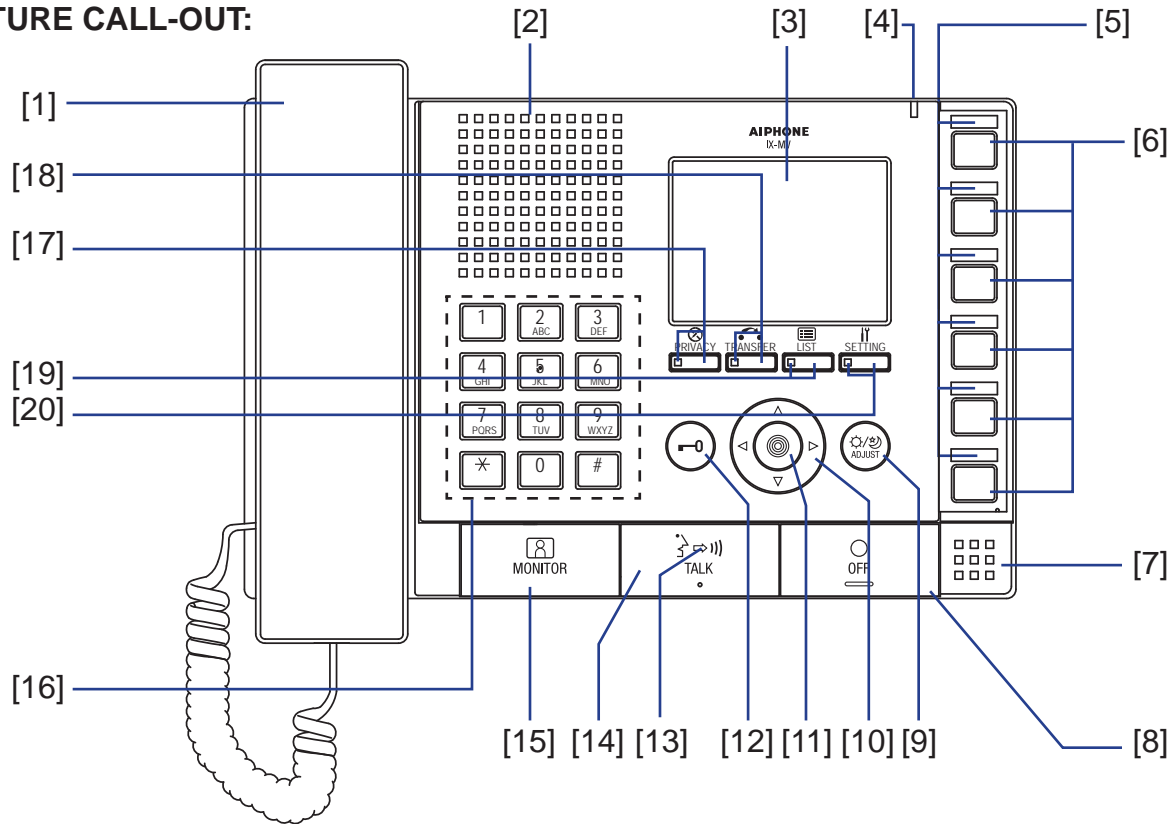

FEATURE CALL-OUT DEFINITIONS:

- [1] Handset
- [2] Speaker
- [3] Color LCD Monitor
- [4] Status LED (orange / blue)
- [5] Directory cards and covers
- [6] Speed dial buttons (6)
- [7] Microphone
- [8] OFF button
- [9] ADJUST button
- [10] Menu navigation control button
- [11] Select button
- [12] Door release button
- [13] Transmit LED (blue)
- [14] TALK button
- [15] MONITOR button
- [16] Dial keys
- [17] PRIVACY button and LED (blue)
- [18] TRANSFER button and LED (orange)
- [19] LIST button and LED (blue)
- [20] SETTING button and LED (blue)

SPECIFICATIONS:

- Power Source: 802.3af PoE
- Communication: Handset Simultaneous Communication
Hands-free Auto-voice actuation or PTT (push-to-talk)
- Monitor: 3.5 inch color LCD
- Paging capacity: Simultaneous to max. 5 zones and/or stations
- Mounting: Desktop w/ stand or wall mount
- Wiring: CAT-5e or CAT-6
- Wiring distance: 330'
- Temperature: 32-104°F (0-40°C)
- Dimensions: 7-7/16" H x 9-13/16" W x 2-5/16" D
- Weight: Approx. 1.81 lbs (820g)