

American Lock Series A1000, A5000 & A6000 (Continued)

MODEL	SHACKLE DIAMETER	LENGTH	PART NO.	SHACKLE SPRING	ACTUATOR		BALL BEARINGS
					NKR	NRK	
A1105, A1105WO, A1165	1/4"	1"	APKG1582980	APKG1613010	APKG1188270	APKG2081160	APKG1806010
A1106, A1106WO, A1166	1/4"	1-1/2"	APKG1583180	APKG1613010	APKG1188270	APKG2081160	APKG1806010
A1107, A1107WO, A1167	1/4"	3"	APKG1583210	APKG1613010	APKG1188270	APKG2081160	APKG1806010
A1205, A1205WO, A1265	5/16"	1-1/8"	APKG1582240	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A1205B, A1205BWO, A1265B	5/16"	3/4"	APKG1584030	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A1205SS, A1205SSWO, A1265SS	5/16"	1-1/8"	APKG0065435	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A1206, A1206WO, A1266	5/16"	2"	APKG1582290	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A1206B, A1206BWO, A1266	5/16"	2"	APKG0056794	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A1206SS, A1206SSWO, A1266SS	5/16"	2"	APKG0065436	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A1207, A1207WO, A1267	5/16"	3"	APKG1582310	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A1207SS, A1207SSWO, A1267SS	5/16"	3"	APKG0065437	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A1209, A1209WO, A1269	5/16"	5"	APKG0000954	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A1209SS, A1209SSWO, A1269SS	5/16"	5"	APKG0065438	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A1305, A1305WO, A1365	3/8"	1-1/8"	APKG1581550	APKG1611010	APKG1188270	APKG2081160	APKG1806010
A1305B, A1305BWO, A1365B	3/8"	1-1/8"	APKG0056760	APKG1611010	APKG1188270	APKG2081160	APKG1806010
A1305SS, A1305SSWO, A1365SS	3/8"	1-1/8"	APKG0065432	APKG0500023	APKG1188270	APKG2081160	APKG1806010
A1306, A1306WO, A1366	3/8"	2"	APKG1581570	APKG1611010	APKG1188270	APKG2081160	APKG1806010
A1306SS, A1306SSWO, A1366SS	3/8"	2"	APKG0065433	APKG0500023	APKG1188270	APKG2081160	APKG1806010
A1307, A1307WO, A1367	3/8"	3"	APKG1581590	APKG1611010	APKG1188270	APKG2081160	APKG1806010
A1307SS, A1307SSWO, A1367SS	3/8"	3"	APKG0065434	APKG0500023	APKG1188270	APKG2081160	APKG1806010
A5100, A5100WO, A6100	1/4"	1"	APKG1582980	APKG1613010	APKG1188270	APKG2081160	APKG1806010
A5101, A5101WO, A6101	1/4"	1-1/2"	APKG1583180	APKG1613010	APKG1188270	APKG2081160	APKG1806010
A5102, A5102WO, A6102	1/4"	3"	APKG1583210	APKG1613010	APKG1188270	APKG2081160	APKG1806010
A5200, A5200WO, A6200	5/16"	1-1/8"	APKG1582240	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5200SS, A5200SSWO, A6200SS	5/16"	1-1/8"	APKG0065435	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A5201, A5201WO, A6201	5/16"	2"	APKG1582290	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5201SS, A5201SSWO, A6201SS	5/16"	2"	APKG0065436	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A5202, A5202WO, A6202	5/16"	3"	APKG1582310	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5202SS, A5202SSWO, A6202SS	5/16"	3"	APKG0065437	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A5205, A5205WO, A6205	5/16"	5"	APKG0000954	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5205SS, A5205SSWO, A6205SS	5/16"	5"	APKG0065438	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A5260, A5260WO, A6260	3/8"	1-1/8"	APKG1581550	APKG1611010	APKG1188270	APKG2081160	APKG1806010
A5260SS, A5260SSWO, A6260SS	3/8"	1-1/8"	APKG0065432	APKG0500023	APKG1188270	APKG2081160	APKG1806010
A5261, A5261WO, A6261	3/8"	2"	APKG1581570	APKG1611010	APKG1188270	APKG2081160	APKG1806010
A5261SS, A5261SSWO, A6261SS	3/8"	2"	APKG0065433	APKG0500023	APKG1188270	APKG2081160	APKG1806010
A5262, A5262WO, A6262	3/8"	3"	APKG1581590	APKG1611010	APKG1188270	APKG2081160	APKG1806010
A5262SS, A5262SSWO, A6262SS	3/8"	3"	APKG0065434	APKG0500023	APKG1188270	APKG2081160	APKG1806010
A5300, A5300WO, A6300	5/16"	1-1/8"	APKG1582240	APKG1611010	APKG1188270	APKG2081160	APKG1806010
A5360, A5360WO, A6360	3/8"	1-1/8"	APKG1581550	APKG1611010	APKG1188270	APKG2081160	APKG1806010
A5530, A5530WO, A6530	1/4"	1"	APKG1582980	APKG1613010	APKG1188270	APKG2081160	APKG1806010
A5530B, A5530BWO, A6530B	1/4"	1"	APKG1583240	APKG1613010	APKG1188270	APKG2081160	APKG1806010
A5530, A5530WO, A6531	1/4"	1-1/2"	APKG1583180	APKG1613010	APKG1188270	APKG2081160	APKG1806010
A5530, A5530WO, A6532	1/4"	3"	APKG1583210	APKG1613010	APKG1188270	APKG2081160	APKG1806010
A5560, A5560WO, A6560	5/16"	1-1/8"	APKG1582240	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5560B, A5560BWO, A6560B	5/16"	3/4"	APKG0056792	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5560SS, A5560SSWO, A6560SS	5/16"	1-1/8"	APKG0065435	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A5561, A5561WO, A6561	5/16"	2"	APKG1582290	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5561B, A5561BWO, A6561B	5/16"	2"	APKG0056794	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5561SS, A5561SSWO, A6561SS	5/16"	2"	APKG0065436	APKH0210031	APKG1188270	APKG2081160	APKG1806010
A5562, A5562WO, A6562	5/16"	3"	APKG1582310	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5562SS, A5562SSWO, A6562SS	5/16"	3"	APKG0065437	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A5565, A5565WO, A6565	5/16"	5"	APKG0000954	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5565SS, A5565SSWO, A6565SS	5/16"	5"	APKG0065438	APKG0210031	APKG1188270	APKG2081160	APKG1806010
A5570, A5570WO, A6570	3/8"	1-1/8"	APKG1581550	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5570B, A5570BWO, A6570B	3/8"	1-1/8"	APKG0056760	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5570SS, A5570SSWO, A6570SS	3/8"	1-1/8"	APKG0065432	APKG0500023	APKG1188270	APKG2081160	APKG1806010
A5571, A5571WO, A6571	3/8"	2"	APKG1581570	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5571SS, A5571SSWO, A6571SS	3/8"	2"	APKG0065433	APKG0500023	APKG1188270	APKG2081160	APKG1806010
A5572, A5572WO, A6572	3/8"	3"	APKG1581590	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5572SS, A5572SSWO, A6572SS	3/8"	3"	APKG0065434	APKG0500023	APKG1188270	APKG2081160	APKG1806010
A5400, A5400WO, A6400	5/16"	1-1/8"	APKG0110032	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5401, A5401WO, A6401	5/16"	2"	APKG0110033	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A5460, A5460WO, A6460	3/8"	1-1/8"	APKG0110029	APKG1611010	APKG1188270	APKG2081160	APKG1806010
A5461, A5461WO, A6461	3/8"	2"	APKG0110030	APKG1611010	APKG1188270	APKG2081160	APKG1806010

For Quantity Content and Ordering Information, See the Price Book
For Trap Door Part Numbers, see page 32


American Lock Series A1405 (for Yale LFIC 1220)

Disassembly

- Unlock shackle
- Use control key to remove LFIC
- Remove driver
- Place lock on flat surface and close shackle
- Actuator and ball bearings should fall out, if not, see page 20
- Remove shackle and spring

Assembly

- Insert shackle spring and shackle
- Insert ball bearings
- Insert actuator as shown
- Check operation with follower tool
- Insert driver
- Insert LFIC with control key
- Check operation

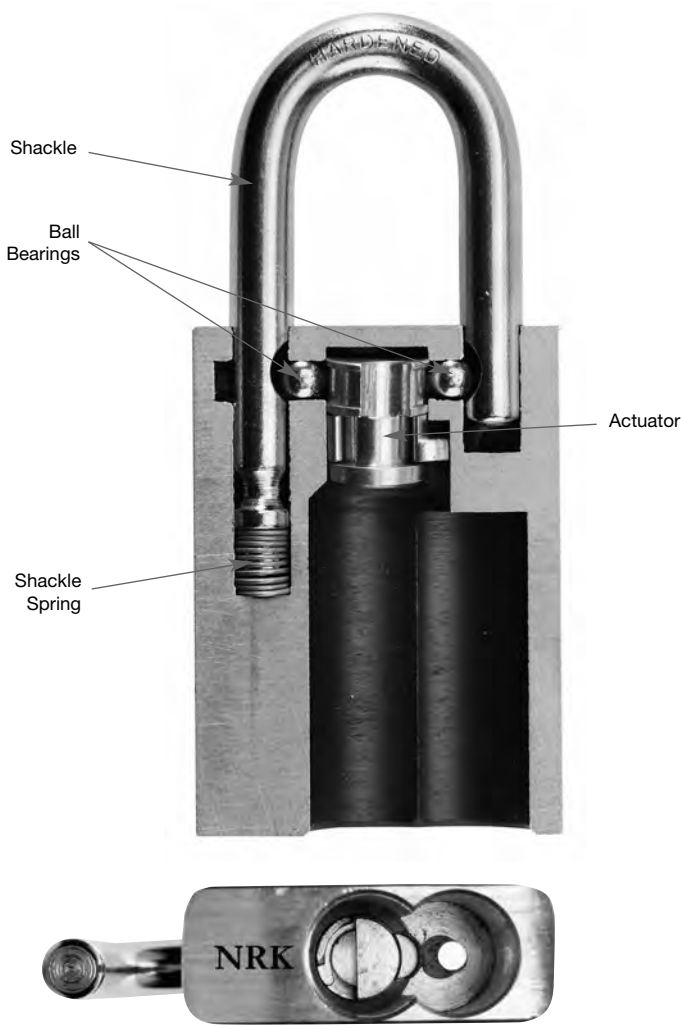

Model	Shackle			Shackle Spring	Actuator		Ball Bearings
	Diameter	Length	Part No.		NKR	NRK	
A1405	5/16"	1-1/8"	APKG1582240	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A1406	5/16"	2"	APKG1582290	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A1407	5/16"	3"	APKG1582310	APKG1606010	APKG1188270	APKG2081160	APKG1806010
A1409	5/16"	5"	APKG0000954	APKG1606010	APKG1188270	APKG2081160	APKG1806010

For Quantity Content and Ordering Information, See the Price Book