


WMA10-23

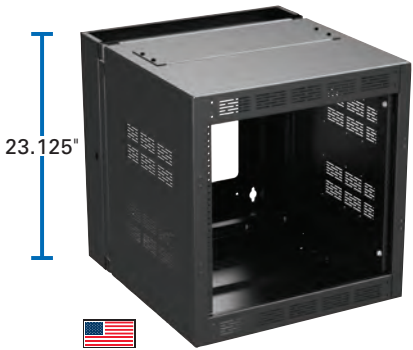


Specifications

Width (Outside)	21.875" (555.63mm)
Height (Outside)	23.125" (587.38mm)
Depth (Outside)	23.53" (597.66mm)
Panel Space	10RU, 17.5" (444.5mm)
Total Usable Depth	22.5" (571.5mm)
-Rack Usable Depth	18" (457.2mm)
-Rear Door Usable Depth	4.5" (114mm)
Usable Depth	18" (457.2mm)
Top Panel Opening	3RU, 5.25" (89mm)
UL Listed	1678

Optional Accessories

1" Deep Plexiglass Front Door	PFD10
1" Deep Solid Front Door	MPFD10
1" Deep Perforated Front Door	SFD10
3" Deep Perforated Front Door	MPFD10-3
Solid Top Panel	SPR3
Perforated Top Panel	PPR3
Fan Panel Top	EFP3-1, EFP3-2
Additional Rack Rails	WMA-RR10

WMA12-23

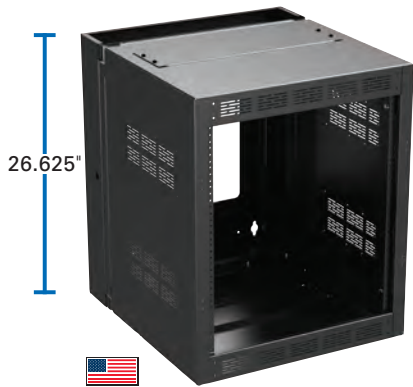

Specifications

Width (Outside)	21.875" (555.63mm)
Height (Outside)	26.625" (676.28mm)
Depth (Outside)	23.53" (597.66mm)
Panel Space	12RU, 21" (533mm)
Total Usable Depth	22.5" (571.5mm)
-Rack Usable Depth	18" (457.2mm)
-Rear Door Usable Depth	4.5" (114mm)
Top Panel Opening	3RU, 5.25" (89mm)
UL Listed	1678

Optional Accessories

1" Deep Plexiglass Front Door	PFD12
1" Deep Solid Front Door	MPFD12
1" Deep Perforated Front Door	SFD12
3" Deep Perforated Front Door	MPFD12-3
Solid Top Panel	SPR3
Perforated Top Panel	PPR3
Fan Panel Top	EFP3-1, EFP3-2
Additional Rack Rails	WMA-RR12

WMA16-23



Specifications

Width (Outside)	21.875" (555.63mm)
Height (Outside)	33.75" (857.25mm)
Depth (Outside)	23.53" (597.66mm)
Panel Space	16RU, 28.125" (714.4mm)
Total Usable Depth	22.5" (571.5mm)
-Rack Usable Depth	18" (457.2mm)
-Rear Door Usable Depth	4.5" (114mm)
Top Panel Opening	3RU, 5.25" (89mm)
UL Listed	1678

Optional Accessories

1" Deep Plexiglass Front Door	PFD16
1" Deep Solid Front Door	MPFD16
1" Deep Perforated Front Door	SFD16
3" Deep Perforated Front Door	MPFD16-3
Solid Top Panel	SPR3
Perforated Top Panel	PPR3
Fan Panel Top	EFP3-1, EFP3-2
Additional Rack Rails	WMA-RR14