


©2011 Atlas Sound L.P. All rights reserved. Atlas Sound and Strategy Series are trademarks of Atlas Sound L.P. All other trademarks are the property of their respective owners. AT5001312 RevC 7/11

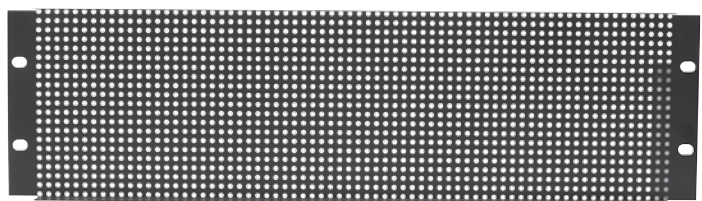

*PPR Series*

**Perforated Vent Panels**

PPR/PPF Series. These 22-gauge CRS perforated panels provide for natural air circulation and dissipation of equipment-generated heat in 19" wide equipment cabinets. The PPR Series is formed on panel top and bottom for recessed installation. The PPF Series is formed on four sides to achieve flush appearance.

**Recessed**

Models For 19" W Cabinets	Rack Unit	Panel Space	Depth
PPR1	1RU	1¾" (44mm)	.625" (15.88mm)
PPR2	2RU	3½" (89mm)	.625" (15.88mm)
PPR3	3RU	5¼" (133mm)	.625" (15.88mm)
PPR4	4RU	7" (178mm)	.625" (15.88mm)
PPR5	5RU	8¾" (222mm)	.625" (15.88mm)
PPR6	6RU	10½" (267mm)	.625" (15.88mm)
PPR7	7RU	12¼" (311mm)	.625" (15.88mm)
PPR8	8RU	14" (356mm)	.625" (15.88mm)

**Flushed**

Models For 19" W Cabinets	Rack Unit	Panel Space	Depth
PPF2	2RU	3½" (89mm)	.625" (15.88mm)



*ATPLATE-052*

**ATPLATE-052**

ATPLATE-052 is perfect for rack mount applications where attenuators are required. The Atlas Sound ATPLATE-052 is a 2RU high #14 gauge plate pre-punched to accommodate up to (6) Atlas Sound RM attenuators. Attractive black filler plugs are provided for applications where the ATPLATE-052 will not be fully loaded. Please note that dial scales are included with Atlas Sound RM series attenuators, however for convenience, (6) additional dial scales are included with the ATPLATE-052. This allows the contractor to stock only standard single gang plate Atlas Sound attenuators which can be modified for use with the ATPLATE-052 by simply removing the single gang stainless steel plate. The ATPLATE-052 is finished in flat black epoxy to better blend in with other rack mount equipment.

**Rack Mount Attenuators**

Model	Power
AT10-RM	10 Watts
AT35-RM	35 Watts
AT100-RM	100 Watts