

Alarm Exit Hardware



Rim Type Exit Devices

NALRM770036	Alarm Rim Type 36" Door (Panic Grade)
NALRM772048	Alarm Rim Type 48" Door (Panic Grade)
FNALRM770036	Alarm Rim Type 36" Door (Fire Grade)
FNALRM772048	Alarm Rim Type 48" Door (Fire Grade)

Vertical Rod Type Exit Devices

Prefix "**NALRM**" before PART #

Features

- 1, 3, 5-minute and continuous alarm type settings available
- ON and OFF power switch
- Alarm sound frequency is 120 db
- Alarm unit has internal horn. When the push rail is depressed, the horn sounds to provide an audible means of signaling that the door has been opened and breached.
- The key switch to turn alarm off is a standard 1 ¼" cylinder with "C" keyway. The alarm operates on one standard 9-volt transistor battery. When battery is weak the horn will emit an intermittent signal.
- Alarmed units are supplied with a micro switch, which monitors the push rail and the latch bolt for foolproof security on rim devices.
- Alarm unit has a signal OC output that can be linked to external alarm control systems.
- Unit includes "EMERGENCY EXIT ONLY • ALARM WILL SOUND" decal for application on door or unit.

Cylinder Dogging Kit

TO ORDER: Prefix "CD" before PART #. Available for all 7700 Series devices except fire exit hardware. To order **KIT ONLY:** use PART # 36CD7700 for 36" and 48CD7700 for 48" devices. Specify finish.



Finishes (Refer to Price List for Stock Finishes)

Cal-Royal	Description	BHMA	US Finish	Material
10B	Oil Rubbed Bronze	613	US10B	Bronze
32D	Satin Stainless	630	US32D	Stainless Steel

- ⚙️ **(IC) INTERCHANGEABLE CORE:** Interchangeable Core locks will accept compatible 6 or 7-Pin cores with BEST, FALCON and ARROW
- ⚙️ **(ICSC) INTERCHANGEABLE CORE:** Indicates function available with **Schlage Full Size Format** Interchangeable Core. Corbin, Sargent and Yale format also available.

Trim Selection

CLUTCH CYLINDRICAL LEVER





Non-handed Grade 1 (Clutch Style)

Cylindrical body hardened steel heavy duty tailpiece. For 1 3/4" and 2 1/4" doors. Prefix "THI" before Part # for 2 1/4" door thickness. Available for fire and non-fire rated rim and vertical rod exit devices.

Rose diameter 3 1/2", lever length 4 3/4". Fits and covers 161 cutout.

Finishes: Architectural plated finishes.

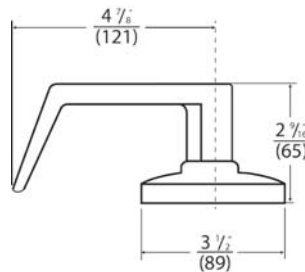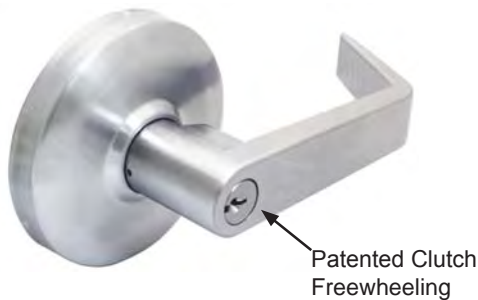

Patented Clutch Freewheeling

ENT00L or
ICENT00L or
ICSCENT00L4
SARICENT00L (Sargent)
RUSICENT00L (Corbin / Russwin)
YALICENT00L (Yale)
8000K

ENTRANCE
 Key locks and unlocks lever.
 Operates as CLASSROOM
 FUNCTION.
 ANSI Function – 08

Ball Knob Keylock

STR05L or
ICSTR05L or
ICSCSTR05L4
SARICSTR05L (Sargent)
RUSICSTR05L (Corbin / Russwin)
YALICSTR05L (Yale)

STOREROOM
 Key operates lever,
 otherwise always locked.
 ANSI Function – 04

PAS30L

PASSAGE
 Trim always operable and free.
 ANSI Function - 15

DUM40L

DUMMY
 Dummy trim. One sided
 ANSI Function – 10

When ordering "AT" and "SPA" designs, prefix design name before Part #.
 Example: ENT00L in "AT" is **ATENT00L**.


KEYWAY: 6-Pin solid brass "C" keyway standard. Optional: Schlage E, Schlage C-K, Russwin D1-2-3-4, Corbin 59/60, Sargent LA-LB-LC, Falcon/Weiser E, Arrow A, Yale 8, Yale GA and Kwikset. Can also accept Medeco, Assa, Kaba and **Cal-Royal HSK** High Security Cylinders.

- ⚙️ **(IC) INTERCHANGEABLE CORE:** Interchangeable Core locks will accept compatible 6 or 7-Pin cores with BEST, FALCON and ARROW
- (ICSC) INTERCHANGEABLE CORE:** Indicates function available with
- ⚙️ **Schlage Full Size Format Interchangeable Core.** Corbin, Sargent and Yale format also available.


Other Lever Trim Designs




TUB DESIGN

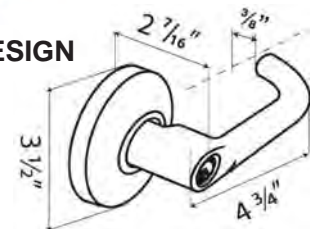

AT DESIGN

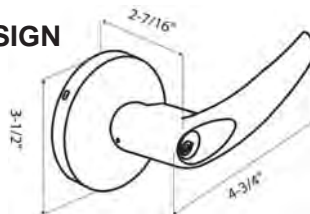

SPA DESIGN

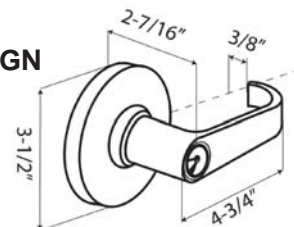

8000K

