


900 Series

GRADE 1 • ANSI A.156.4 • UL LISTED
BHMA CERTIFIED • LIFETIME WARRANTY

- Universal application, non-handed for standard, top-jamb or parallel arm installation, optional heavy duty arms
- Non-sized, size 1 thru 6 adjustable power range, FACTORY PRESET SIZE 3
- UL-approved for fire doors, up to 3-hour rating
- Conforms to UL standards UL10C and UBC7-2-1997
- Cast aluminum body with standard full plastic cover
- Barrier-free meets ADA regulation, Sizes 1 thru 6, with reduced spring power to provide easier opening for handicapped or elderly
- Standard adjustable back check function
- Adjustable closing and latching speed by two separate regulating valves
- Spring tension gauge for easy adjustment
- Self-tapping screws and sex bolts standard package
- Extended long arm for top jamb mount with deep reveals
- Optional adjustable Delayed Action (DA) Preset at the factory for approximately 20 seconds, between 70° and 0°, Delay time easily adjusted up to 1 minute
- Optional Slide Track Arm, Parallel Hold Open Adjustable Arm, Extra Heavy Duty Arm/ Hold Open Arm for potentially abusive installation
- Alum, Duro, Gold and Stainless Steel. Architectural finishes available

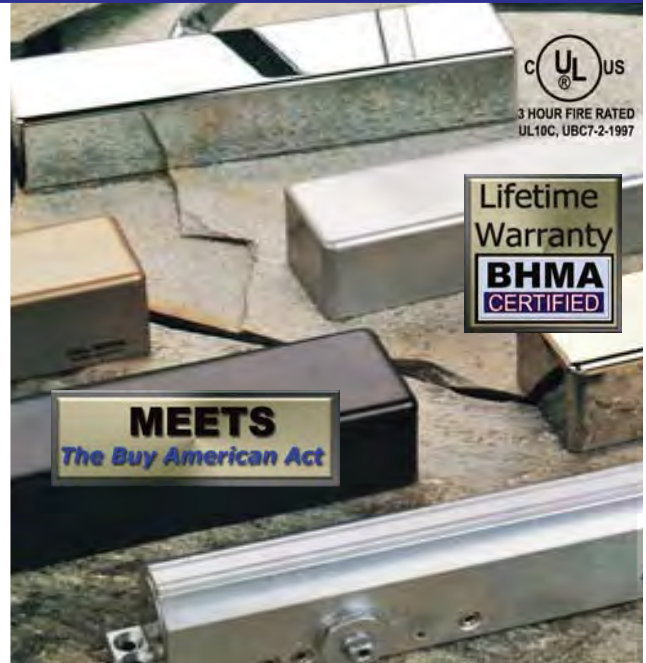

ITEM#	SIZE	DOOR WEIGHTS	BACK CHECK	FULL COVER	BARRIER FREE	HOLD OPEN	DELAYED ACTION
N900-PBF	1-6	30 – 260 lbs	STANDARD	YES	YES	OPTIONAL	N/A
N900-PBFDA	1-6		STANDARD	YES	YES	OPTIONAL	YES

CR441 Series

GRADE 1 • ANSI A.156.4 • UL LISTED
BHMA CERTIFIED • LIFETIME WARRANTY

- Universal application, non-handed for standard, top-jamb or parallel arm installation, optional heavy duty arms
- Non-sized, size 1 thru 6 adjustable power range, FACTORY PRESET SIZE 3
- UL-approved for fire doors, up to 3-hour rating
- Conforms to UL standards UL10C and UBC7-2-1997
- Cast iron body with standard full plastic cover (optional metal)
- Barrier-free meets ADA regulation, engineered with reduced spring power to provide easier opening for handicapped or elderly
- Standard adjustable back check function
- Adjustable closing and latching speed by two separate regulating valves
- Spring tension gauge for easy adjustment
- Self-tapping screws and sex bolts standard package
- Optional adjustable Delayed Action (DA) Preset at the factory for approximately 20 seconds, between 70° and 0°, Delay time easily adjusted up to 1 minute (CR441DA)
- Optional Parallel Hold Open Arm, Extra Heavy Duty Arm / Hold Open Arm for potentially abusive installation
- Alum, Duro, Gold, Stainless Steel and Architectural finishes available



ITEM#	SIZE	DOOR WEIGHTS	BACK CHECK	FULL COVER	BARRIER FREE	HOLD OPEN	DELAYED ACTION
CR441	1-6	60 – 260 lbs	STANDARD	YES	YES	OPTIONAL	N/A
CR441DA	1-6		N/A	YES	YES	OPTIONAL	YES