


PIONEER RL & AG Series

HEAVY DUTY CYLINDRICAL LEVERSETS

ANSI - A156.2, Series 4000, Grade 2


Optional Interchangeable Core, Best, Falcon and Arrow

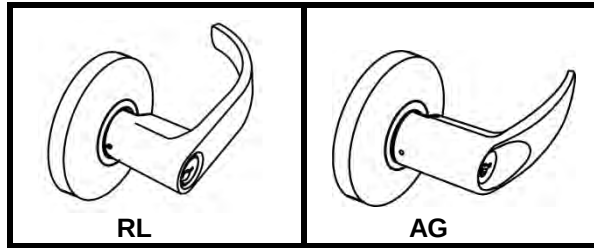

FUNCTIONS	ANSI	ITEM #		FINISHES	PCS /MC
				(Finishes in bold are stock items)	
Entrance	F109	RL00 ● ICRL00	AG00 ● ICAG00	US26D, US3, US10B, US10, US26, US4, US15	10
Storeroom	F91	RL05 ● ICRL05	AG05 ● ICAG05	US26D, US3, US10B, US10, US26, US4, US15	
Classroom	F84	RL03 ● ICRL03	AG03 ● ICAG03	US26D, US3, US10B, US10, US26, US4, US15	
Entrance Push Button Lock	F82	RL01 ● ICRL01	AG01 ● ICAG01	US26D, US3, US10B, US10, US26, US4, US15	
Exit Lock / Connecting Room with key	----	RL80 ● ICRL80	AG80 ● ICAG80	US26D, US3, US10B, US10, US26, US4, US15	
Dormitory / Assisted Living	F90	RL101 ● ICRL101	AG101 ● ICAG101	US26D, US3, US10B, US10, US26, US4, US15	
Privacy(see below for split finishes)	F76	RL20	AG20	US26D, US3, US10B, US10, US26, US4, US15	
Patio	F77	RL10	AG10	US26D, US3, US10B, US10, US26, US4, US15	
Passage	F75	RL30	AG30	US26D, US3, US10B, US10, US26, US4, US15	
Exit	F89	RL50	AG50	US26D, US3, US10B, US10, US26, US4, US15	
Single Dummy	----	RL40	AG40		20

● (IC) Indicates function available with Best, Falcon and Arrow Interchangeable Core.

► SPLIT FINISHES FOR PRIVACY FUNCTION

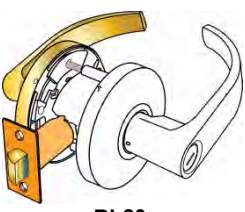ILLUSTRATION	ITEM #	FUNCTIONS	ANSI	PCS /MC	UNIT
 RL20	RL20 or AG20 US3/26(Inside)	Privacy	F76	10	Ea.
	RL20 or AG20 US10B/26(Inside)				
	RL20 or AG20 US4/26D(Inside)				
	RL20 or AG20 US4/26(Inside)				
	RL20 or AG20 US4/3(Inside)				
	RL20 or AG20 US3/26D(Inside)				
	RL20 or AG20 US10B/26D(Inside)				

