



PRESTOLOCK® • Combination Padlocks

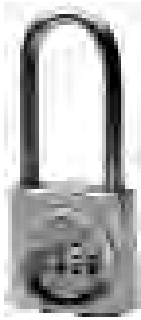

2621 HEAVY DUTY COMBINATION PADLOCK

Material: Die cast housing with case hardened steel shackle

Combination: 4 dials, 10,000 possible combinations
Toe and Heel locking

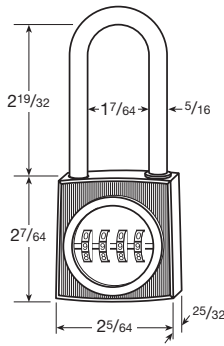

Part No/Cyl Length	Stock ID No.	Nickel	Shelf Pack	Master Pack	Approx. Boxed Wt. (lbs./oz.)
2621 Carded	K2621*	•	6	36	3/12
2621 Bulk	B2621*	•	-	25	14/2

COMBINATION LOCKS for Cabinet Doors



D900 x US26D



D901 x US26D



D901 x US4

D900 and D901 COMBINATION LOCKS for Cabinet Doors

Available for Wood or Metal Applications.

They easily retrofit existing locks of similar design and feature re-settable combinations with easy to use instructions. Available in US26D or US4.

Full templates for new installations!
Mechanical, no batteries needed.

Latex Free for Hospital, Medical Center and Nursing Care facilities.

Part No/Cyl Length	Stock ID No.	Description	Qty.	Approx. Boxed Wt. (lbs./ oz.)
D900 x US26D	90000	Combination Lock Push Button US26D, Sheet Metal Door .075-.105	ea.	
D901 x US26D	90100	Combination Lock Push Button US26D, Wood Door 5/8"-7/8"	ea.	
D901 x US4	90101	Combination Lock Push Button US4, Wood Door 5/8"-7/8"	ea.	

*NOTES:

For carded items, use "K" prefix (e.g., K2620). For bulk items, use "B" prefix (e.g., B2620).
For finishes, specify one suffix from below (e.g., K3470BN):

Bright Nickel	BN
Polished Chrome	PC