





# pin tumbler door & drawer locks

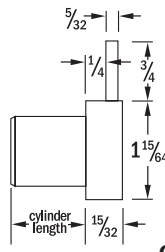

For more information about  
BHMA certified locks, visit  
[compX.com/csp\\_bhma.html](http://compX.com/csp_bhma.html)

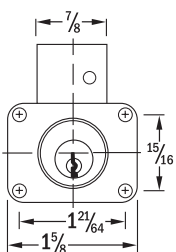


**C8177, C8178, C8179, C8180**

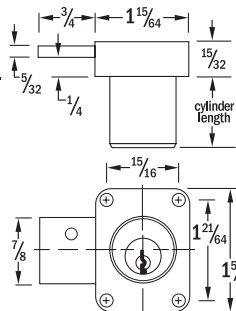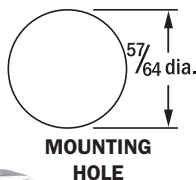

**C8173, C8174, C8175**

Re-Keying Made Easy  
**ADVANTAGE<sup>™</sup> PLUS**

To see a video of  
**Advantage PLUS+**  
visit CompX online:  
[compX.com/advplus](http://compX.com/advplus)

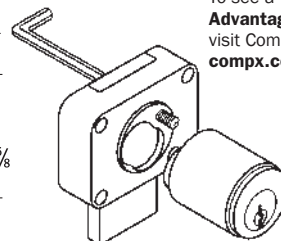

The PLUS feature allows you to remove the cylinder from our pin tumbler box locks while the lock remains in place. No mounting screws need to be removed. Simply use a 5/64" allen wrench from the back to remove the cylinder and plug for re-keying.

**APPLICATION** – For drawers, R.H. or L.H. doors. Surface mounted. Requires 57/64" diameter hole for cylinder.

**OPERATION** – Key removable in both locked and unlocked positions.

**KEYING** – Will key together with all other pin tumbler locks using D4291 key blank except locks shown on pages 8 and 9. See table for available keying. Master keying to GM1.

**PACKAGING** – Supplied with two keys, strike and mounting screws. If trim ring is required, order C2017 separately. See page 22.

Part No.	Installation	Bolt Type	Cylinder Length	Bolt Travel	KA Codes	Key Changes		Case Quantity	Reference Number	Key Blank
						KD	MKKD			
C8173-26D	Door	Dead	7/8"	3/4"	4	850	650	10	M2-3713-301	D4291
C8173-4	Door	Dead	7/8"	3/4"	2	850	650	10	M2-3713-301	D4291
C8173-4G	Door	Dead	7/8"	3/4"	2	850	—	10	M2-3713-301	D4291
C8174-26D	Door	Dead	1-1/8"	3/4"	4	850	650	10	M2-3713-311	D4291
C8175-26D	Door	Dead	1-3/8"	3/4"	4	850	650	10	M2-3713-321	D4291
C8178-26D	Drawer	Dead	7/8"	3/4"	4	850	650	10	M2-3718-301	D4291
C8178-4	Drawer	Dead	7/8"	3/4"	2	850	—	10	M2-3718-301	D4291
C8178-4G	Drawer	Dead	7/8"	3/4"	2	850	—	10	M2-3718-301	D4291
C8177-26D	Drawer	Dead	1-1/8"	3/4"	4	850	—	10	M2-3718-311	D4291
C8179-26D	Drawer	Dead	1-3/8"	3/4"	4	850	650	10	M2-3718-321	D4291
C8179-4	Drawer	Dead	1-3/8"	3/4"	2	850	—	10	M2-3718-321	D4291
C8180-26D	Drawer	Dead	1-5/8"	3/4"	4	850	650	10	M2-3718-331	D4291

**NEW!**



**C2073**



1/8" black plastic spacer for pin tumbler door and drawer locks. 25 pcs. per bag.

**Certified Grade 2 locks also available for MRI applications — non-ferrous or non-magnetic versions. Made to order.**

All locks above are ANSI/BHMA **certified** Grade 2 A156.11. Grade 1 locks are available as special order.



**C8133, C8135**

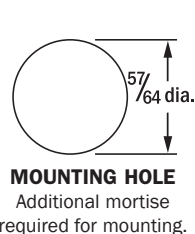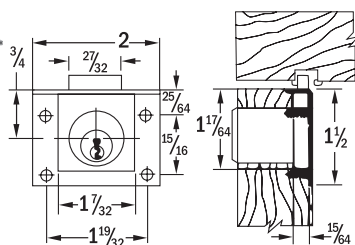

**C8131**




**C8139**

**APPLICATION** – For drawers. Half mortise type requires mortise for housing and 57/64" diameter hole for cylinder. C8139 is surface mounted.

**OPERATION** – Key removable in both locked and unlocked positions except C8131 and C8139.

**KEYING** – Will key together with all other pin tumbler locks using D4291 key blank except locks shown on pages 8 and 9. See table for available keying. Master keying to GM1.

**PACKAGING** – Supplied with two keys, strike and mounting screws. If trim ring is required, order C2017 separately. See page 22.

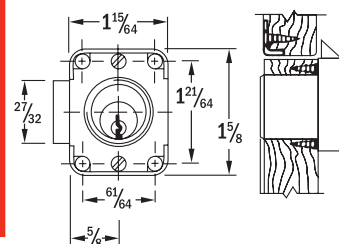

Part No.	Installation	Bolt Type	Cylinder Length	Bolt Travel	KA Codes	Key Changes		Case Quantity	Reference Number	Key Blank
						KD	MKKD			
C8131-26D**	Drawer	Spring	7/8"	7/32"	4	850	650	10	M2-3701-121	D4291
C8131-4**	Drawer	Spring	7/8"	7/32"	2	850	—	10	M2-3701-121	D4291
C8133-26D	Drawer	Dead	7/8"	1/4"	4	850	—	10	M2-3700-111	D4291
C8133-4	Drawer	Dead	7/8"	1/4"	2	850	—	10	M2-3700-111	D4291
C8135-26D	Drawer	Dead	1-1/8"	1/4"	4	850	—	10	M2-3700-159	D4291
C8139-26D**	Door	Spring	3/4"	7/32"	4	850	650	10	M2-3719-092	D4291

\*Key Codes used: 2 Codes – 107 and 915.

4 Codes – 101, 103, 107 and 915.

\*\*Key removable in locked position only.