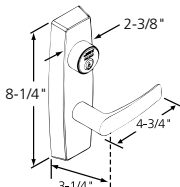
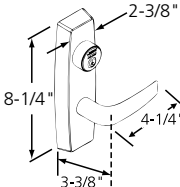
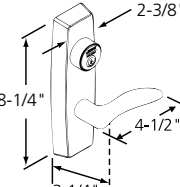
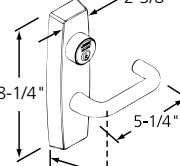
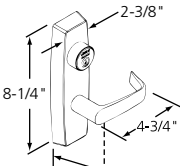
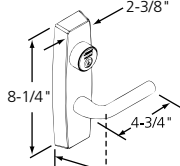
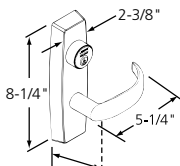


Lever Trim Design																	
	Armstrong A33 Lever: Cast Escutcheon: Cast		<table><tr><th>Trim Designation</th><th>ANSI #</th></tr><tr><td>A3310 - Passage</td><td>14</td></tr><tr><td>A3350 - Dummy</td><td>02</td></tr><tr><td>A3355 - Classroom</td><td>08</td></tr><tr><td>A3357 - Nightlatch (Rim)</td><td>03</td></tr><tr><td>A33V57 - Nightlatch (SVR)</td><td>09</td></tr><tr><td>A33M57 - Nightlatch (Mortise)</td><td>03</td></tr></table>	Trim Designation	ANSI #	A3310 - Passage	14	A3350 - Dummy	02	A3355 - Classroom	08	A3357 - Nightlatch (Rim)	03	A33V57 - Nightlatch (SVR)	09	A33M57 - Nightlatch (Mortise)	03
Trim Designation	ANSI #																
A3310 - Passage	14																
A3350 - Dummy	02																
A3355 - Classroom	08																
A3357 - Nightlatch (Rim)	03																
A33V57 - Nightlatch (SVR)	09																
A33M57 - Nightlatch (Mortise)	03																
	Citation C33 Lever: Cast Escutcheon: Cast		<table><tr><th>Trim Designation</th><th>ANSI #</th></tr><tr><td>C3310 - Passage</td><td>14</td></tr><tr><td>C3350 - Dummy</td><td>02</td></tr><tr><td>C3355 - Classroom</td><td>08</td></tr><tr><td>C3357 - Nightlatch (Rim)</td><td>03</td></tr><tr><td>C33V57 - Nightlatch (SVR)</td><td>09</td></tr><tr><td>C33M57 - Nightlatch (Mortise)</td><td>03</td></tr></table>	Trim Designation	ANSI #	C3310 - Passage	14	C3350 - Dummy	02	C3355 - Classroom	08	C3357 - Nightlatch (Rim)	03	C33V57 - Nightlatch (SVR)	09	C33M57 - Nightlatch (Mortise)	03
Trim Designation	ANSI #																
C3310 - Passage	14																
C3350 - Dummy	02																
C3355 - Classroom	08																
C3357 - Nightlatch (Rim)	03																
C33V57 - Nightlatch (SVR)	09																
C33M57 - Nightlatch (Mortise)	03																
	Dirke D33 Lever: Cast Escutcheon: Cast		<table><tr><th>Trim Designation</th><th>ANSI #</th></tr><tr><td>D3310 - Passage</td><td>14</td></tr><tr><td>D3350 - Dummy</td><td>02</td></tr><tr><td>D3355 - Classroom</td><td>08</td></tr><tr><td>D3357 - Nightlatch (Rim)</td><td>03</td></tr><tr><td>D33V57 - Nightlatch (SVR)</td><td>09</td></tr><tr><td>D33M57 - Nightlatch (Mortise)</td><td>03</td></tr></table>	Trim Designation	ANSI #	D3310 - Passage	14	D3350 - Dummy	02	D3355 - Classroom	08	D3357 - Nightlatch (Rim)	03	D33V57 - Nightlatch (SVR)	09	D33M57 - Nightlatch (Mortise)	03
Trim Designation	ANSI #																
D3310 - Passage	14																
D3350 - Dummy	02																
D3355 - Classroom	08																
D3357 - Nightlatch (Rim)	03																
D33V57 - Nightlatch (SVR)	09																
D33M57 - Nightlatch (Mortise)	03																
	Lustra L33 Lever: Cast Escutcheon: Cast		<table><tr><th>Trim Designation</th><th>ANSI #</th></tr><tr><td>L3310 - Passage</td><td>14</td></tr><tr><td>L3350 - Dummy</td><td>02</td></tr><tr><td>L3355 - Classroom</td><td>08</td></tr><tr><td>L3357 - Nightlatch (Rim)</td><td>03</td></tr><tr><td>L33V57 - Nightlatch (SVR)</td><td>09</td></tr><tr><td>L33M57 - Nightlatch (Mortise)</td><td>03</td></tr></table>	Trim Designation	ANSI #	L3310 - Passage	14	L3350 - Dummy	02	L3355 - Classroom	08	L3357 - Nightlatch (Rim)	03	L33V57 - Nightlatch (SVR)	09	L33M57 - Nightlatch (Mortise)	03
Trim Designation	ANSI #																
L3310 - Passage	14																
L3350 - Dummy	02																
L3355 - Classroom	08																
L3357 - Nightlatch (Rim)	03																
L33V57 - Nightlatch (SVR)	09																
L33M57 - Nightlatch (Mortise)	03																
	Newport N33 Lever: Cast Escutcheon: Cast		<table><tr><th>Trim Designation</th><th>ANSI #</th></tr><tr><td>N3310 - Passage</td><td>14</td></tr><tr><td>N3350 - Dummy</td><td>02</td></tr><tr><td>N3355 - Classroom</td><td>08</td></tr><tr><td>N3357 - Nightlatch (Rim)</td><td>03</td></tr><tr><td>N33V57 - Nightlatch (SVR)</td><td>09</td></tr><tr><td>N33M57 - Nightlatch (Mortise)</td><td>03</td></tr></table>	Trim Designation	ANSI #	N3310 - Passage	14	N3350 - Dummy	02	N3355 - Classroom	08	N3357 - Nightlatch (Rim)	03	N33V57 - Nightlatch (SVR)	09	N33M57 - Nightlatch (Mortise)	03
Trim Designation	ANSI #																
N3310 - Passage	14																
N3350 - Dummy	02																
N3355 - Classroom	08																
N3357 - Nightlatch (Rim)	03																
N33V57 - Nightlatch (SVR)	09																
N33M57 - Nightlatch (Mortise)	03																
	Regis R33 Lever: Cast Escutcheon: Cast		<table><tr><th>Trim Designation</th><th>ANSI #</th></tr><tr><td>R3310 - Passage</td><td>14</td></tr><tr><td>R3350 - Dummy</td><td>02</td></tr><tr><td>R3355 - Classroom</td><td>08</td></tr><tr><td>R3357 - Nightlatch (Rim)</td><td>03</td></tr><tr><td>R33V57 - Nightlatch (SVR)</td><td>09</td></tr><tr><td>R33M57 - Nightlatch (Mortise)</td><td>03</td></tr></table>	Trim Designation	ANSI #	R3310 - Passage	14	R3350 - Dummy	02	R3355 - Classroom	08	R3357 - Nightlatch (Rim)	03	R33V57 - Nightlatch (SVR)	09	R33M57 - Nightlatch (Mortise)	03
Trim Designation	ANSI #																
R3310 - Passage	14																
R3350 - Dummy	02																
R3355 - Classroom	08																
R3357 - Nightlatch (Rim)	03																
R33V57 - Nightlatch (SVR)	09																
R33M57 - Nightlatch (Mortise)	03																
	Princeton PR33 Lever: Cast Escutcheon: Cast		<table><tr><th>Trim Designation</th><th>ANSI #</th></tr><tr><td>PR3310 - Passage</td><td>14</td></tr><tr><td>PR3350 - Dummy</td><td>02</td></tr><tr><td>PR3355 - Classroom</td><td>08</td></tr><tr><td>PR3357 - Nightlatch (Rim)</td><td>03</td></tr><tr><td>PR33V57 - Nightlatch (SVR)</td><td>09</td></tr><tr><td>PR33M57 - Nightlatch (Mortise)</td><td>03</td></tr></table>	Trim Designation	ANSI #	PR3310 - Passage	14	PR3350 - Dummy	02	PR3355 - Classroom	08	PR3357 - Nightlatch (Rim)	03	PR33V57 - Nightlatch (SVR)	09	PR33M57 - Nightlatch (Mortise)	03
Trim Designation	ANSI #																
PR3310 - Passage	14																
PR3350 - Dummy	02																
PR3355 - Classroom	08																
PR3357 - Nightlatch (Rim)	03																
PR33V57 - Nightlatch (SVR)	09																
PR33M57 - Nightlatch (Mortise)	03																

See Page 21 for available finishes

Quick Codes

ED3000 Series

Strike

Description	Specify
Rim	
Mortised adjustable	S04
Rim x Vertical Rod	S02
Vertical Rod	
Flush bottom (ED3400 devices only)	S03
3-hour fire-rated bottom for use with threshold	S06
Flush Transom Strike	M67
Mortise	
Open back strike	
1-3/4" door thickness	SB134
2" door thickness	SB200
2-1/4" door thickness	SB214
Straight Lip ANSI Strike	
1-3/4" door thickness	SS118
2" door thickness	SS138
2-1/4" door thickness	SS158
Curved Lip ANSI Strike	
1-3/4" door thickness	SA114 (standard)
2" door thickness	SA138
2-1/4" door thickness	SA158

Finish

Description	Specify
US3 Bright Brass	605
US4 Satin Brass	606
US9 Bright Bronze	611
US10 Satin Bronze	612
US10B Dark Oxidized Satin Bronze, oil rubbed	613
US10BE Dark Oxidized Satin Bronze - Equivalent	613E
US14 Bright Nickel Plated	618 ¹
US15 Satin Nickel Plated	619 ¹
US26 Bright Chromium Plated	625 ¹
US26D Satin Chromium Plated	626 ¹
Satin Chromium Plated with MicroShield 	626C ¹
US32 Bright Stainless Steel	629 ²
US32D Satin Stainless Steel	630 ²
— Satin Stainless Steel with MicroShield® 	630C ²

1. Outside trim only

2. Not available on lever trim or T34 trim

Door Height (SVR Only)

Door	Specify
7'0"	H0700
7'2"	H0702
7'6"	H0706
8'	(standard)
8'6"	H0806 (ED3400 device only)
9'	H0900 (ED3400 device only)
10'	H1000 (ED3400 device only)

Handing

Hand	Specify
Right Hand Reverse	RHR
Left Hand Reverse	LHR

Door Width

Door	Specify
36" (914mm)	(standard)
48" (1219mm)	W048

Door Thickness

Door	Specify
1-3/4" (44mm)	(standard)
2" (51mm)	D200
2-1/4" (57mm)	D214