




PUSH PLATES & PULL PLATES WITH HOLES

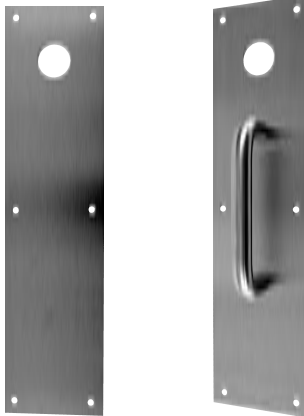

NUMBER	PULL	DIMENSIONS	MATERIAL
*70	-	3 1/2" x 15"	Aluminum, Brass, Bronze, Stainless Steel
*71	-	4" x 16"	
*7015	15	3 1/2" x 15"	
*7115	15	4" x 16"	

SHELF PACK: (70, 71) 10

Box Pack

(7015, 7115) 1

FASTENERS: 1/4-20 thru bolt for handles, #6 x 5/8" OH SMS

FEATURE: All holes are 2 1/2" on center from the end of the plate.

FINISHES: 605, 606, 612, 613, 628, 629, 630

OPTIONS:

- Hole location can be varied
- Other plate sizes & pulls can be specified

HOW TO ORDER:

Hole Size, Number, Finish e.g.: CFC70 - 605

HOLE SIZE: CFC 1 1/4" - CFD 1 1/2" - CFK 2 1/8" - CFL
2 1/8" with lever prep

FLUSH CUP PULLS



1848

1850

NUMBER	DIMENSIONS	OPENING SIZE	DEPTH	ANSI A156.6	MATERIAL
1846	5" x 5"	3 1/2" x 3 1/2"	7/8"	J403	Stainless Steel
1848	3 1/2" x 4 3/4"	2" x 3 1/2"	3/4"	J403	
1850	3 1/2" x 4 3/4"	2" x 3 1/2"	3/4"	J403	
1858	4" x 10"	2" x 3 1/2"	3/4"	J403	
1860	4" x 16"	2" x 3 1/2"	3/4"	J403	

SHELF PACK: (1846) 1

Box Pack

(1848, 1850, 1858, 1860) 10

GAUGE: 16 (.062)

FASTENERS: (1846) 4 ea. #10-24 x 5/8" Pin in head Torx MS,
4 ea. one way x 5/8" sex nut

(1850, 1858) 4 ea. #8 x 3/4" SMS

(1860) 6 ea. #8 x 3/4" SMS

FEATURES: (1846) ADA Compliant

 
FINISH: 630

OPTIONS:


- Back to back Mounting for 1848 & 1850 only
- Torx screws



1858



1860

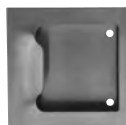

1846