




ELBOW CATCH




NUMBER	MATERIAL
1590	Cast

SHELF PACK: 10 Polybagged
FINISHES: 605, 613, 625, 626

HANDRAIL BRACKETS

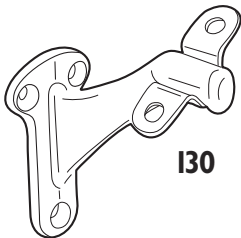

130

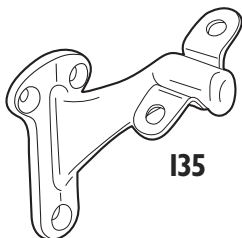


135


NUMBER	ANSI	MATERIAL
130	L33061	Cast Aluminum
135	L13061	Solid Brass

SHELF PACK: (130) 20, (135) 10 Polybagged
FEATURES: (130) Base 2 13/16" x 1 1/2"
(135) Base 2 1/4" x 1 1/4"
FINISHES: (130) 605, 609, 613, 619, 620, 625, 626
(135) 605, 613, 619, 620, 626

HINGE PINS/WINDOW BOLTS

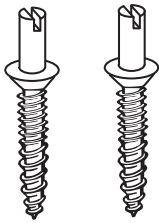

CHP-100
RHP-100

 


WB-112


NUMBER	DIMENSIONS
CHP-100	#12 Head
RHP-100	#10 Head
WB-112	Contains: 8 Bolts, 4 Tools

SHELF PACK: (CHP-100, RHP-100) 10 pack of 2 each Polybagged
(WB-112) 10
FINISHES: (CHP-100, RHP-100) BP (Brass Plated), CP (Chrome Plated)
(WB-112) ZINC

COAT HOOKS

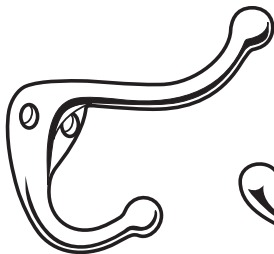

300

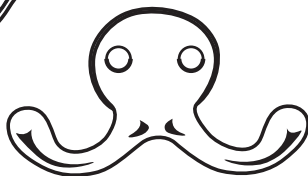

302



304

NUMBER	MATERIAL
300	Die Cast
302	Die Cast
304	Brass

SHELF PACK: (300, 302) 20 Polybagged
(304) 10
FINISHES: (300, 302) 605, 613, 619, 620, 625, 626
(304) 626