
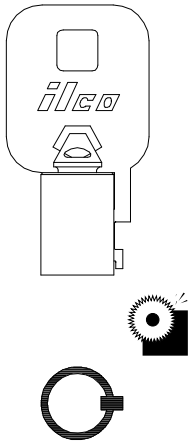


ACE
ACORN
ADAMS RITE


OD .377" - 9.6mm
ID .312" - 7.9mm
(BRASS)


1137B

—

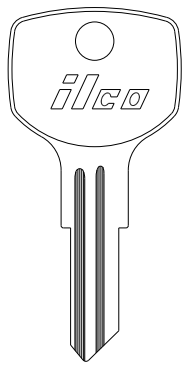


A54B

—

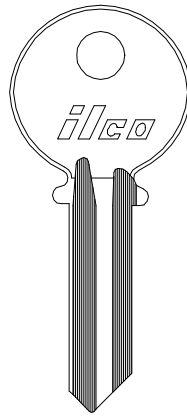


999

Y1

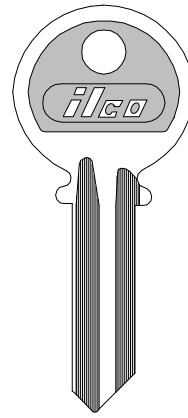


Y1-PC

—

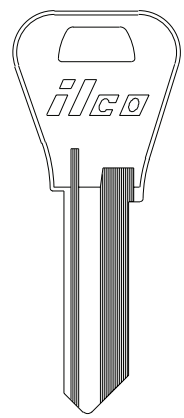


1054WB

WR3

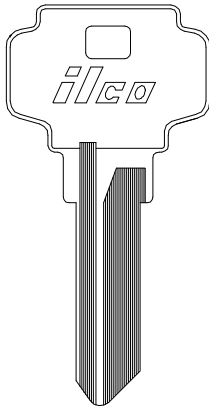ADAMS RITE
ALMET


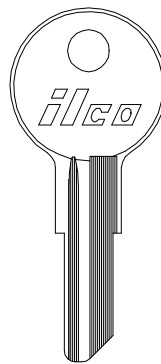
D1054K

DE6

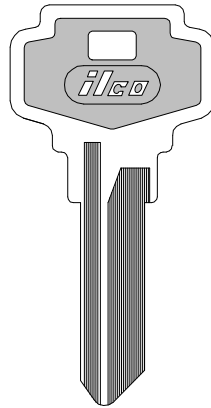


DE6-PC

—




L1054B

IN8

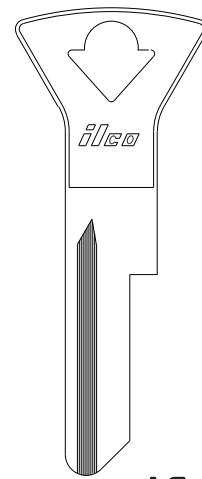


K1145

—

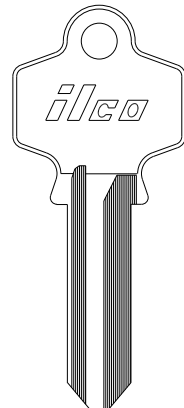


AE1

—

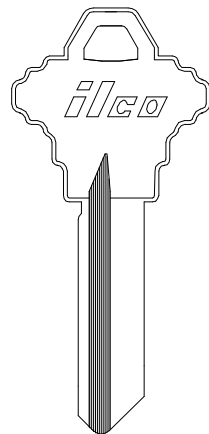ALMET


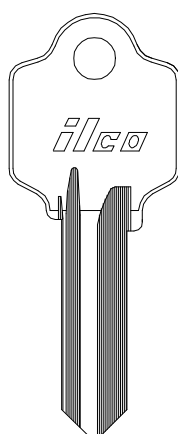
1145A

SC4

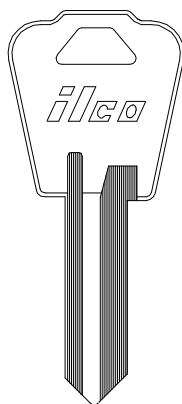


1177N

NH1




1179

AR1

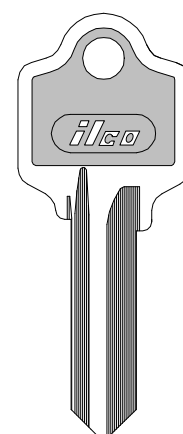

AR1-PC

—

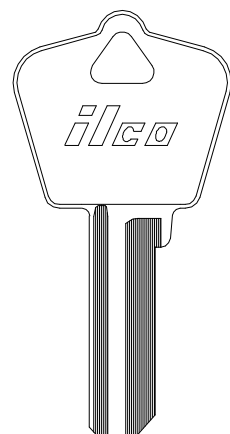

N1179

—


ILCO
EZ

ILCO
EZ


ILCO
EZ

ALMET

AMERICAN LOCK

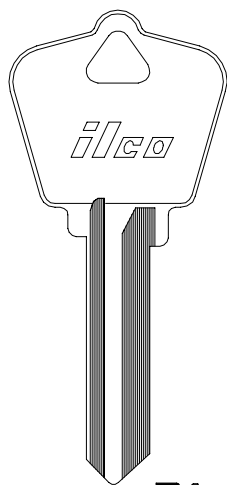

1179A
AR4

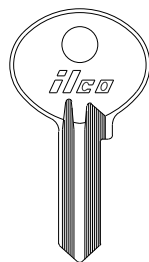

1041B
—




1041C
AM1



1041CK



1041CE

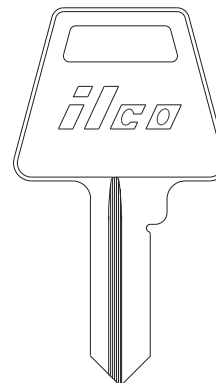

5 PIN
1045
AM3


6 PIN
A1045
—




ILCO
EZ

AMERICAN LOCK

AMEROCK

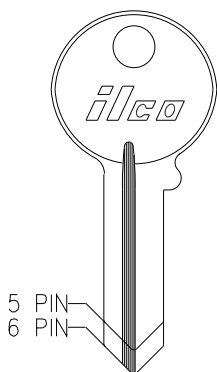

6 PIN
A1041U

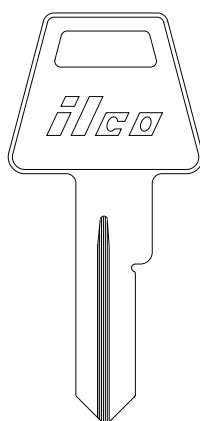


5 PIN
1046




6 PIN
1046A




1653
AM4

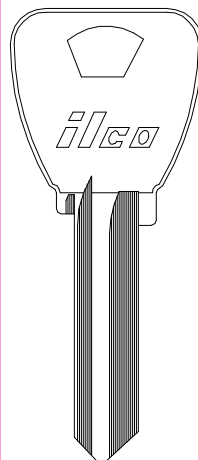

AK22W
—

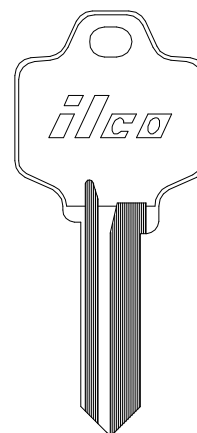

R1064E
NA25

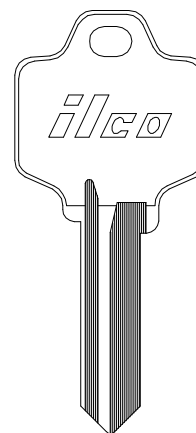


NA25-PC
—




ILCO
EZ

ARCO

ARFE

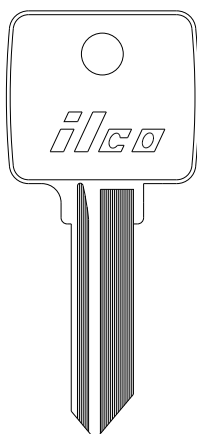

1130
—

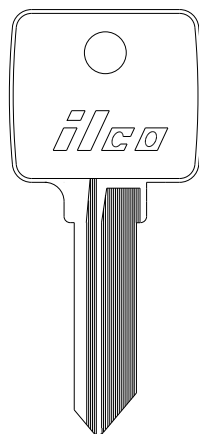


1130R
—




1131
—




1131R
—

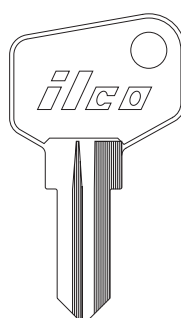


1635J
—

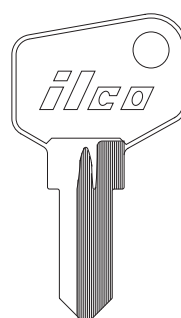

1635K
—

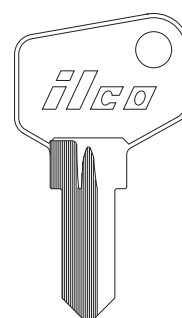

1635L
—

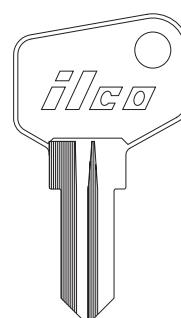

1635V
—



ILCO
EZ