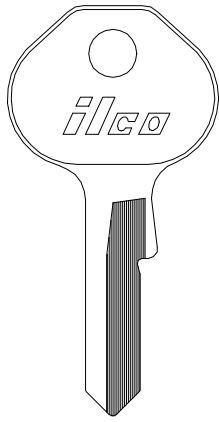
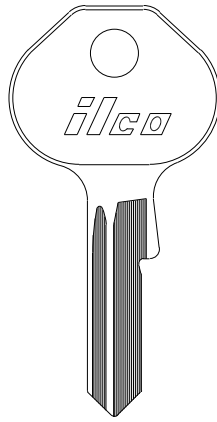
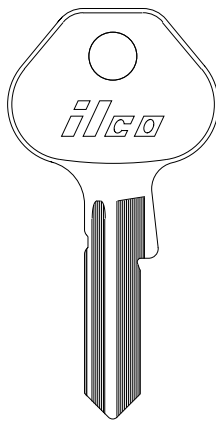
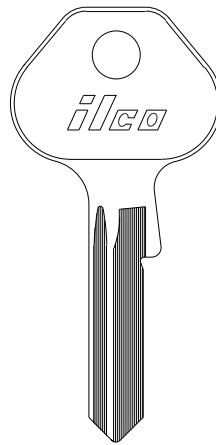
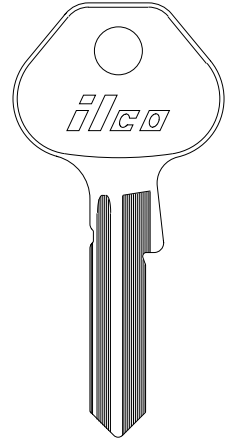
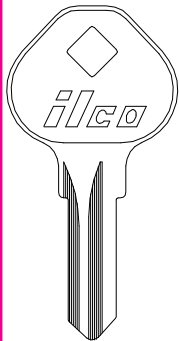
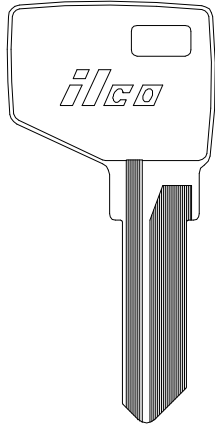
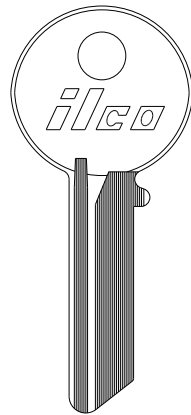
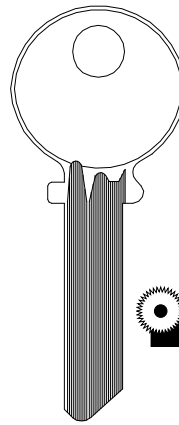
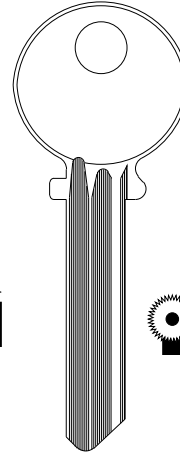
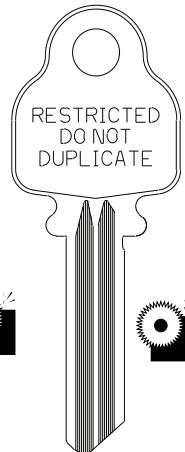








MASTER

1092-900
M19

1092-6000
M20

1092-6000B
M25

1092-7000
M21

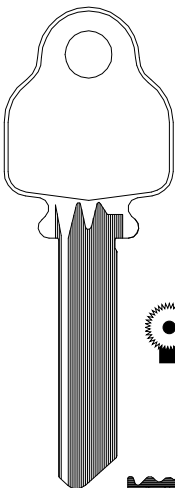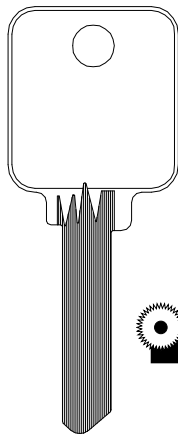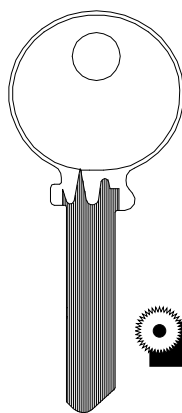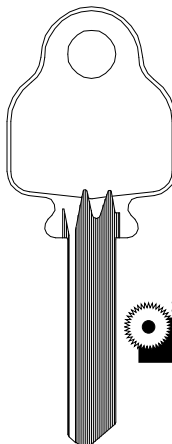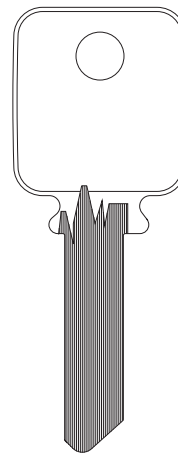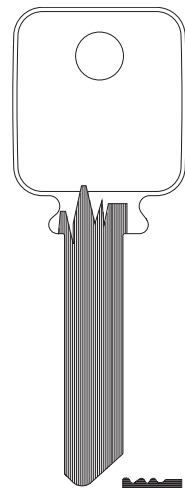1092-7000B
M26

ILCO
EZ

MASTER
MCKINNEY
MEDECO

1092-8105
—

MD1054K
—

O1054K O1054KR
—

1515
—

A1515
—

1517
—

 RESTRICTED
DO NOT
DUPLICATE

ILCO
EZ

MEDECO

A1517
—

1518
—

1542
—

1543
—

1638
—

A1638
—

ILCO
EZ