




FORD

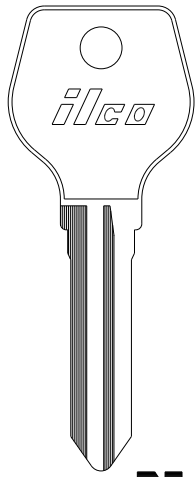


X26
MZ9

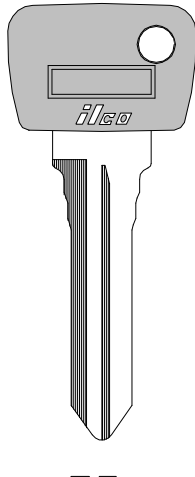


MZ9-P
—

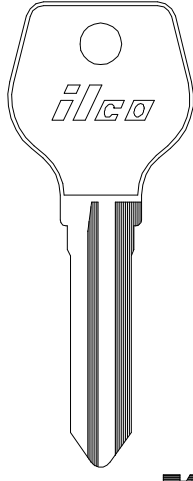

X27
MZ10

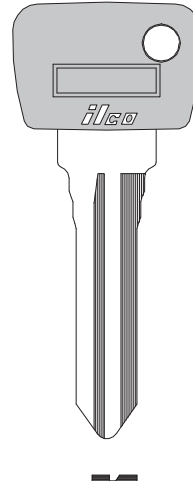


MZ10-P
—

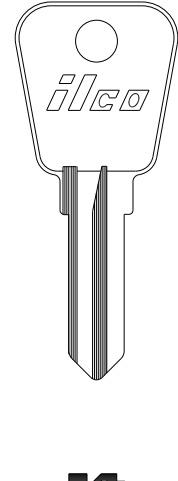


62FT
F68YT

ILCO
EZ


FORD

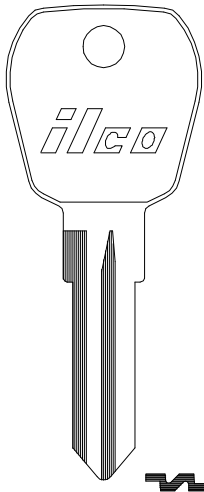


X86
FC7

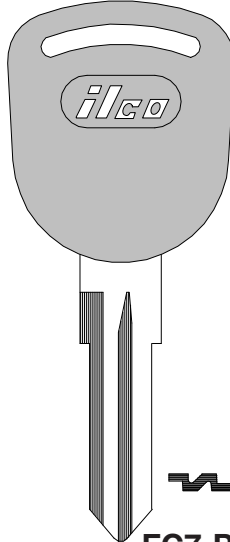


FC7-P
—

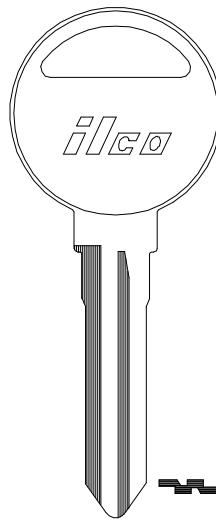

X131
MZ13

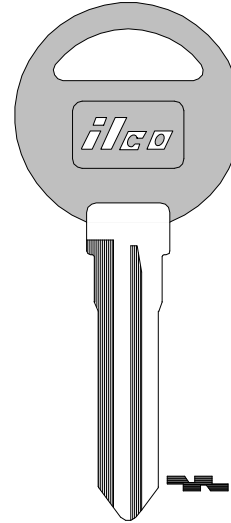


MZ13-P (-PC)
—

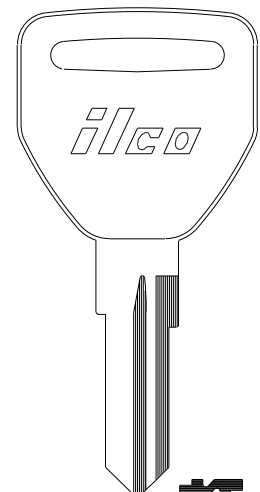


X169
WB3

ILCO
EZ


FORD

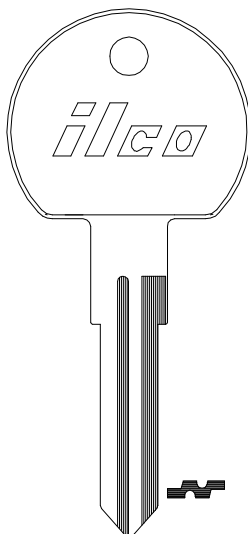


X170
NE48

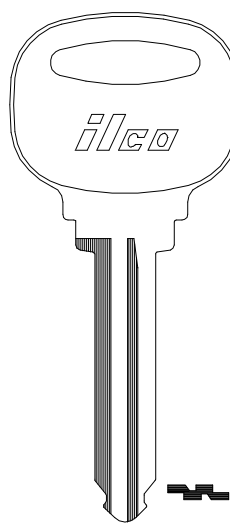


X202
H59

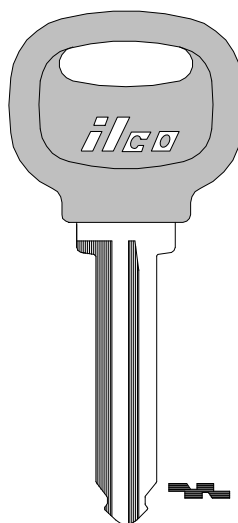

H59-P (-PC)
—

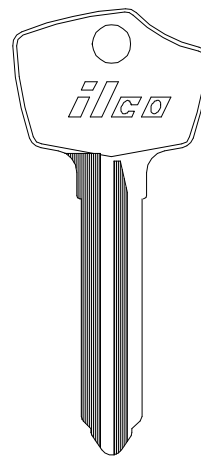


X207
H63

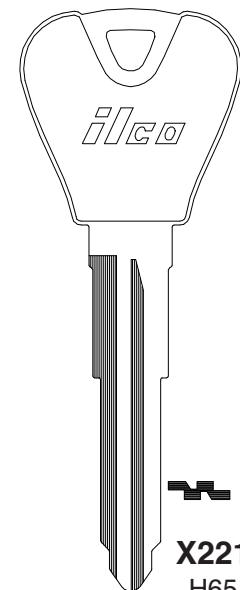


X221
H65

ILCO
EZ


KAWASAKI

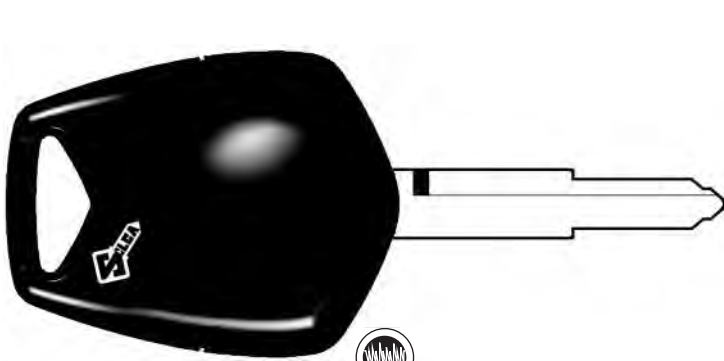

KW16EH2

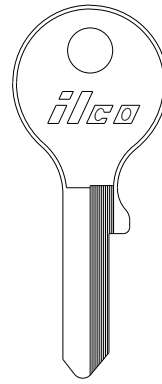

SR61N

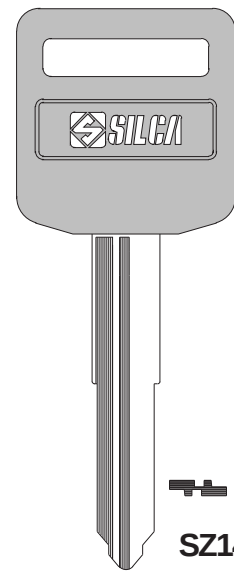


SZ14RAP





ILCO
EZ

KAWASAKI

KENWORTH

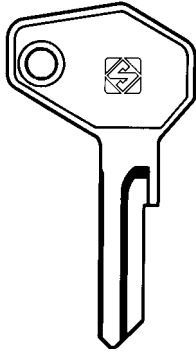

ZD7-SI

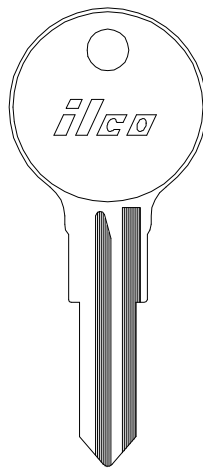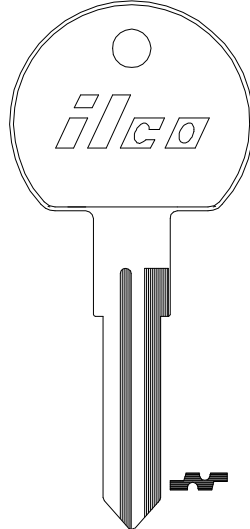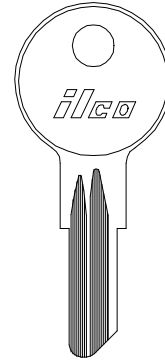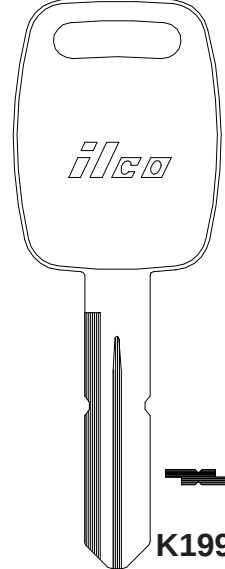

X53
V32

X170
NE48

1098DB
B5


K1994

ILCO
EZ

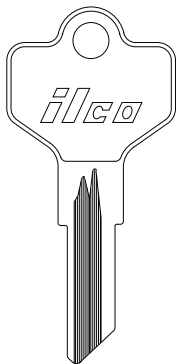KENWORTH



KIA




1656



1657

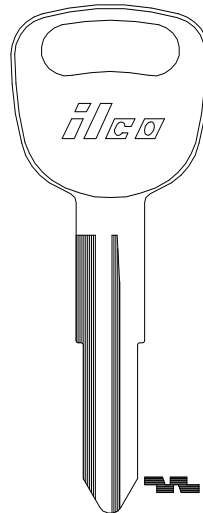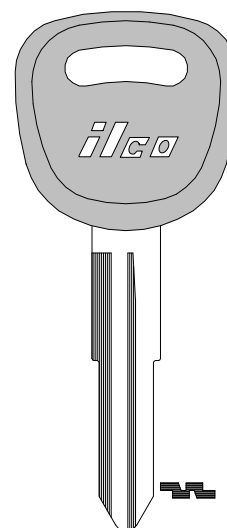
X233
KK1


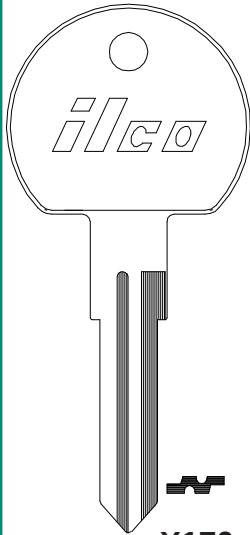
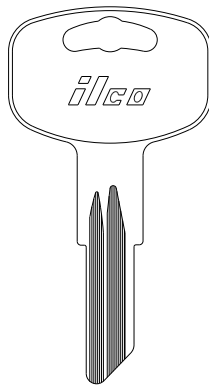
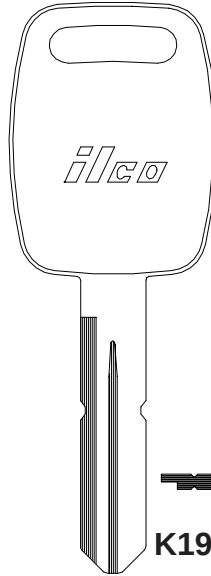
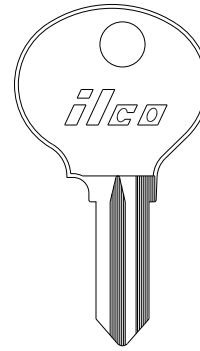
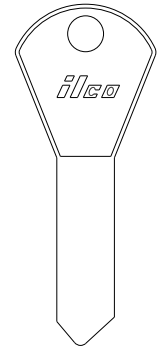
KK1-P

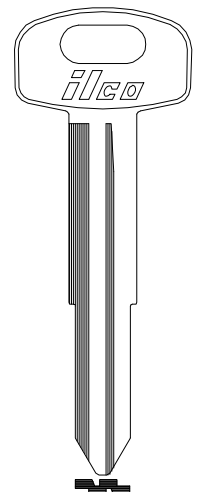
X240
KK2

ILCO
EZ




PETERBILT



PEUGEOT


X170
NE48

1098PB
—

K1994
—

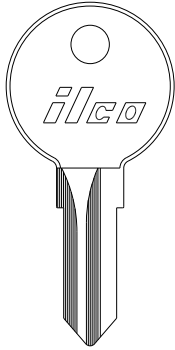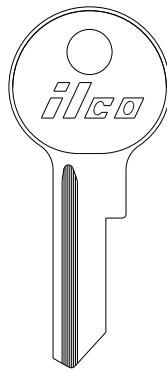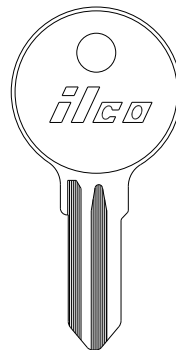KM1
—

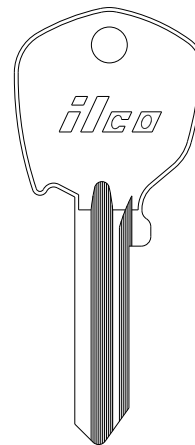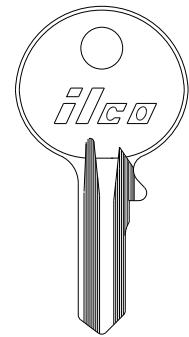LA1
—

ILCO
EZ

PEUGEOT





KM2
—

KM3
—

NE4
—



SM4
—

FT6
—

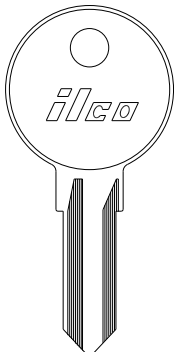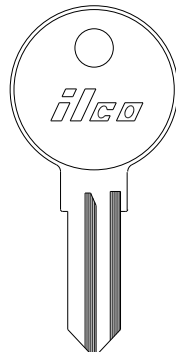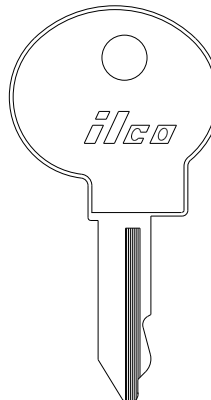7DC
—

R7DC
—

ILCO
EZ

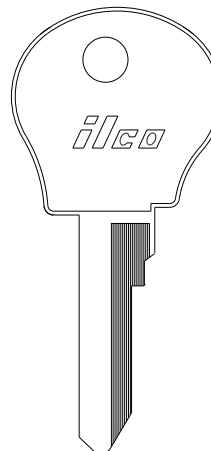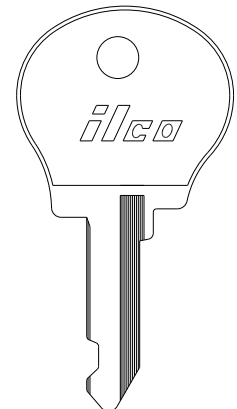PEUGEOT



KM8
—

X89
KM9

KM10
—

NE11
—

X12
RE61F

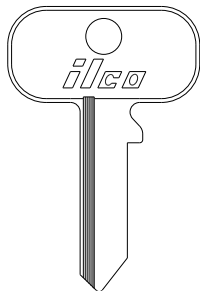NE18
—

ILCO
EZ


ROOTES GROUP

ROVER



B62DR

—

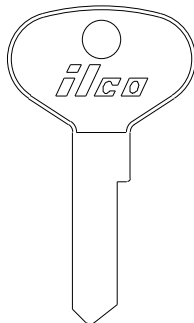


H62DG

—




HR62DG

—

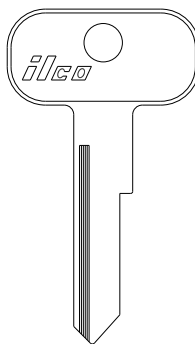


H62DP

—

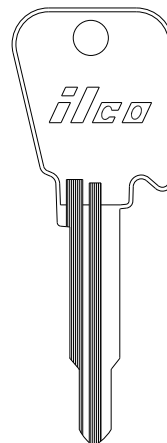

X13

LF4

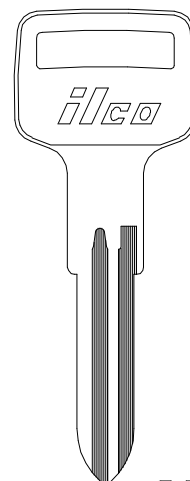


X29

VO73


ILCO
EZ

ROVER

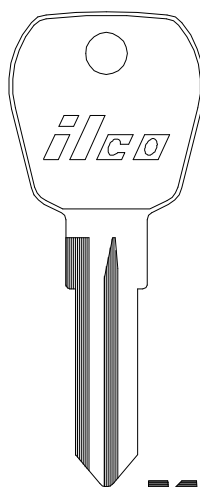


X86

FC7

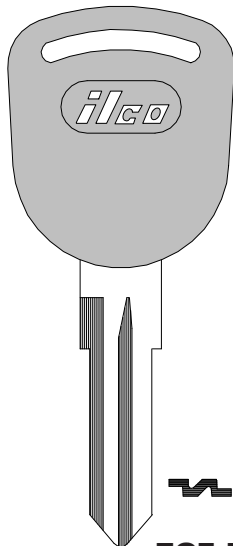


FC7-P

—

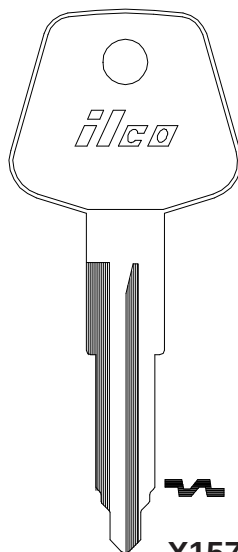


X157

LF17

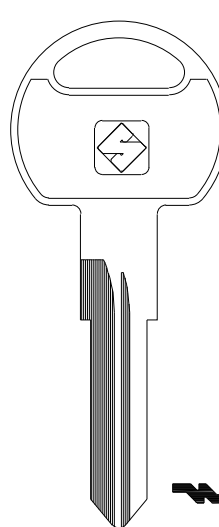

NE71R

—

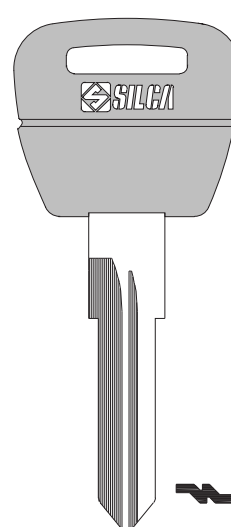


NE71RDP

—


ILCO
EZ

ROVER

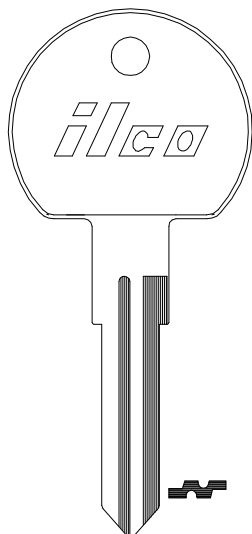

X170

NE48


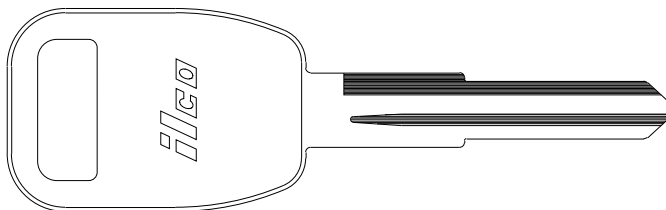


X239

RV4


ILCO
EZ

SKODA

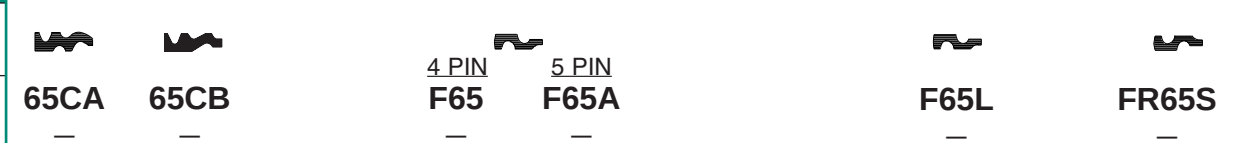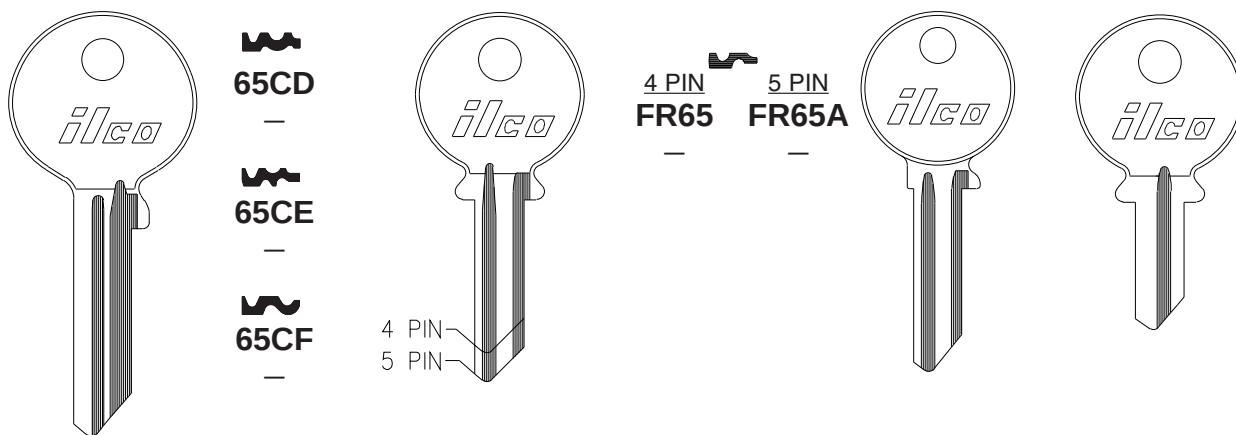

ILCO
EZ

SKODA



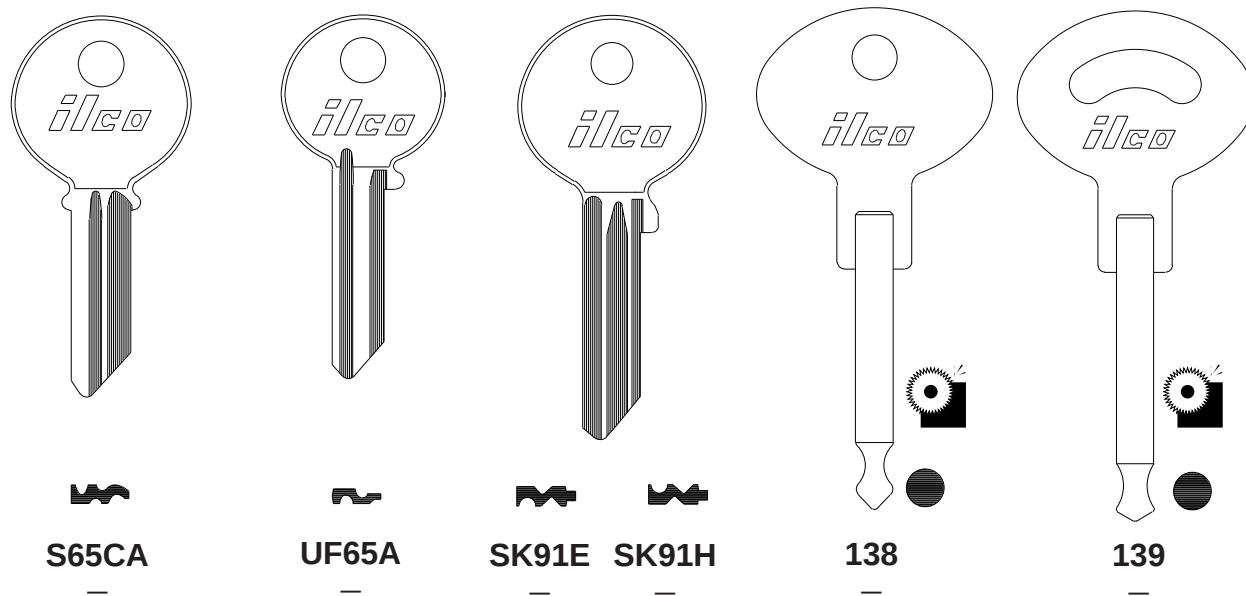


ILCO
EZ

SKODA

SKODA MOTORBIKE

STERLING

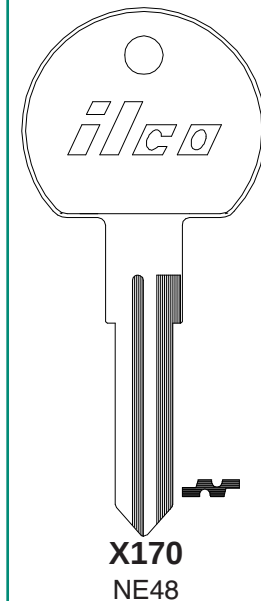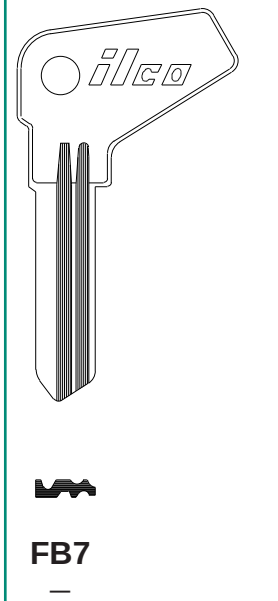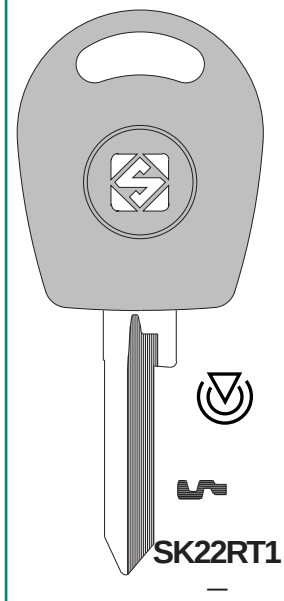

ILCO
EZ