


FORD INTERNATIONAL

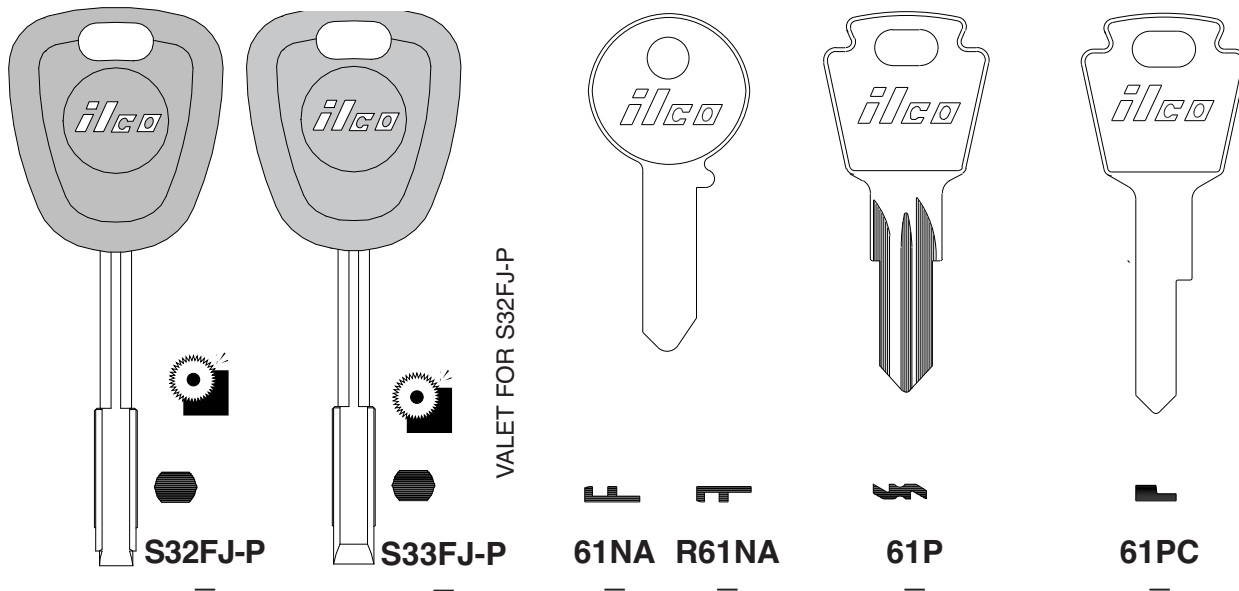


ILCO
EZ

sec
1 page
47


VEHICLE

FORD INTERNATIONAL

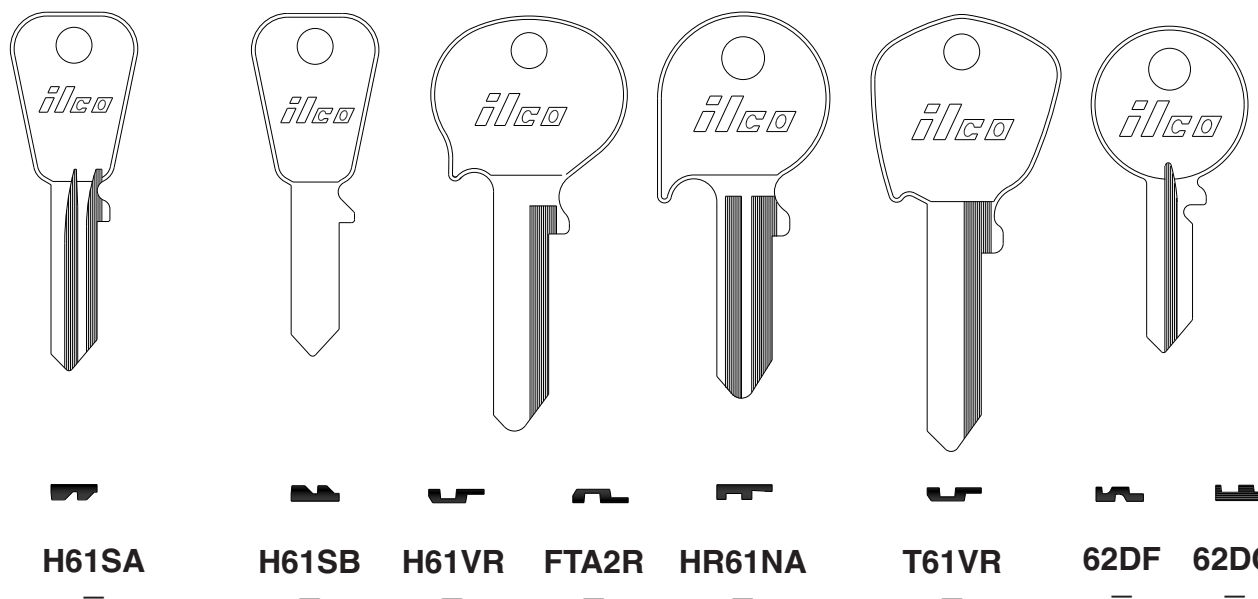


ILCO
EZ

FORD INTERNATIONAL

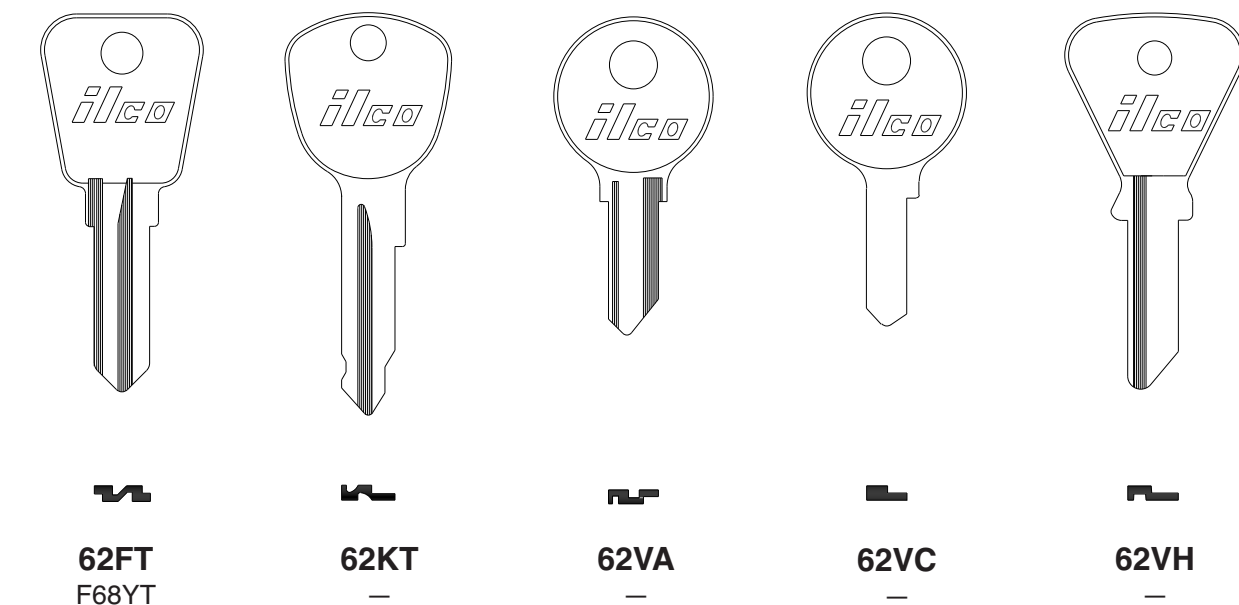


ILCO
EZ

RENAULT

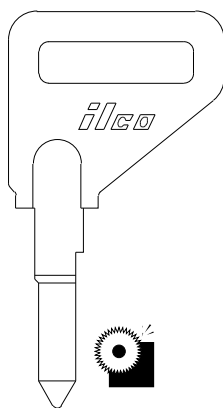


NE33

—

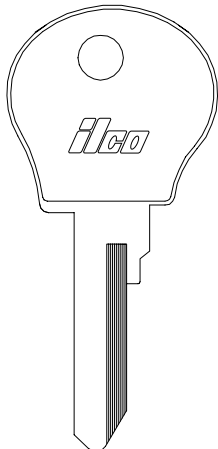

NE39

—

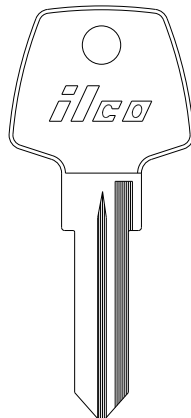

NE45


—



HV61 HVR61

—

—

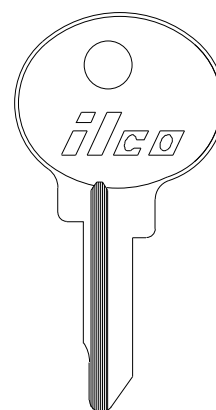


RE61N

—


ILCO
EZ

RENAULT

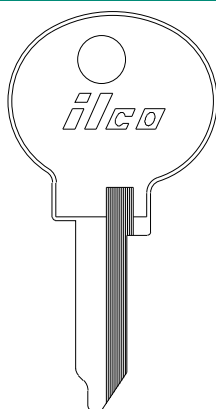


RE61XR

—

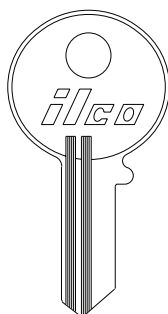


V61S

—

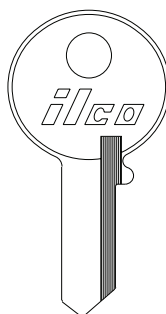

VR61S

—

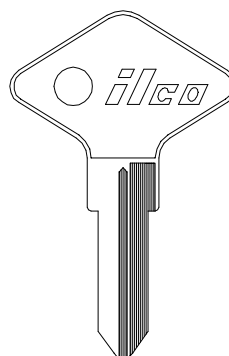

X61
NE40




62VC

—

ILCO
EZ

RENAULT

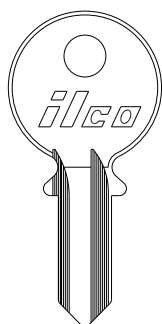

62R


—

62U

—

R62UC

—

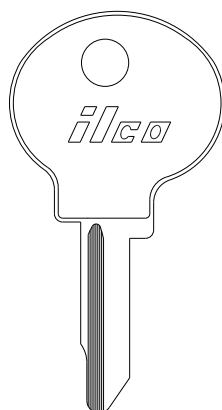

63M

—

63Q

—



64R

—

RK4

—

64X

—




P64K

—



ILCO
EZ

VOLKSWAGEN

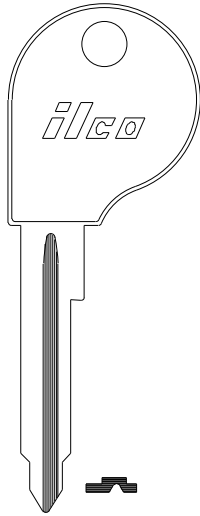

HF35

—

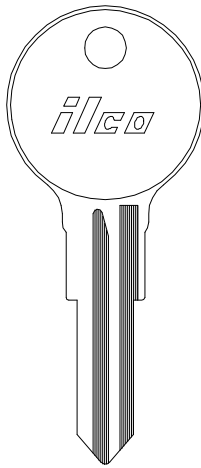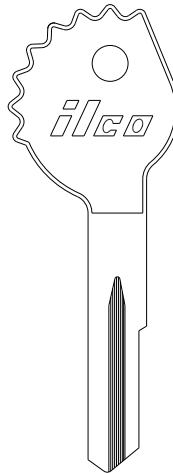X53
V32

OP60C

—




61N

—



61NC

—

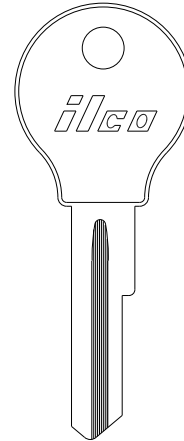

61VW

—



U61VW

—




V61VW

—


ILCO
EZ

VOLKSWAGEN

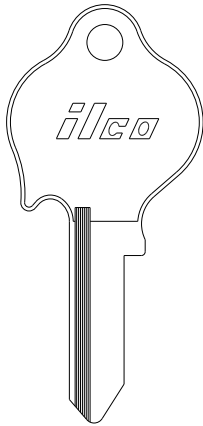


H61VM

—

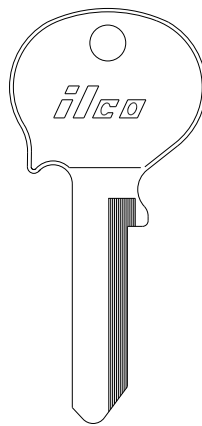


H61VR

—

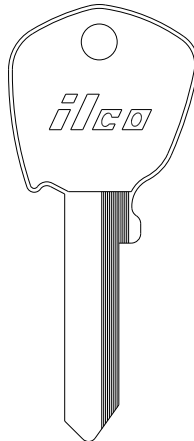

FT12R

—

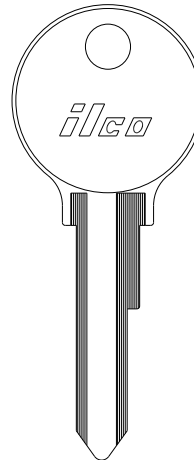


T61VR

—



62DW

—

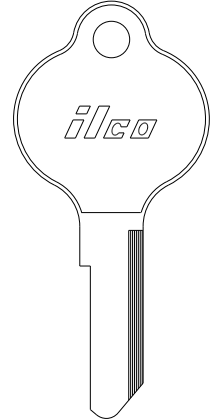

62VC

—



62VE

—


ILCO
EZ

VOLKSWAGEN




62VG

—

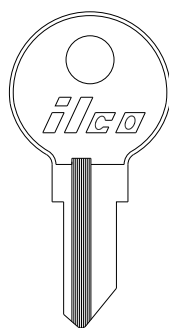


62VO

—

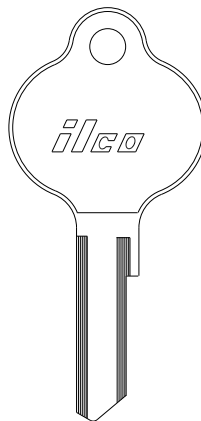


62VW

—

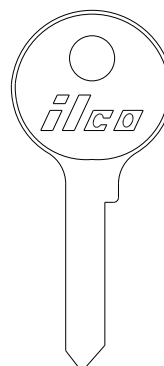

A62VC

—

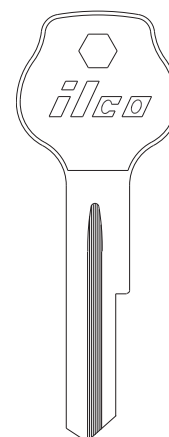

A62VN

—



HR62VK

—



L62VB

—

ILCO
EZ