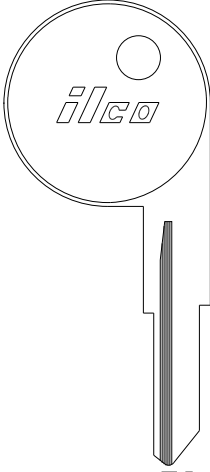

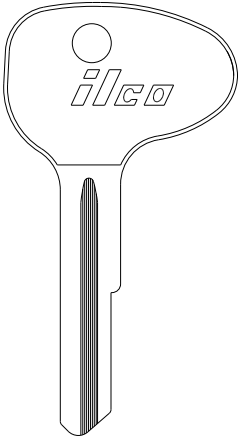
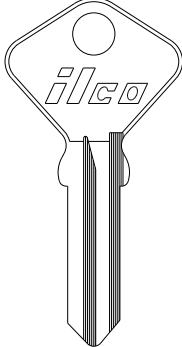

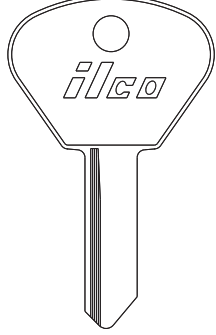










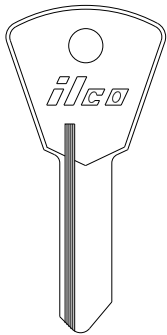

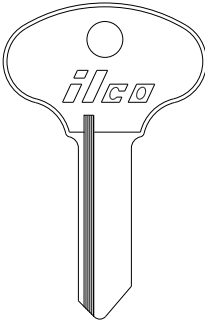

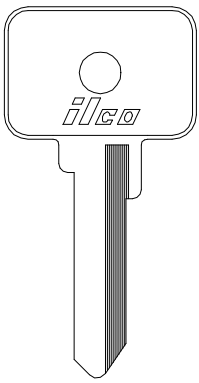
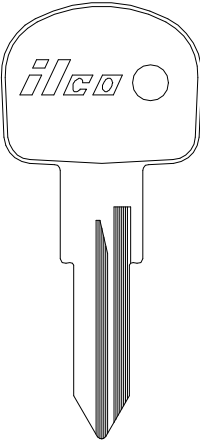
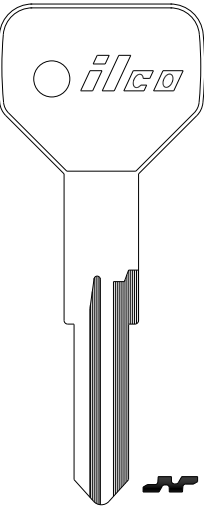











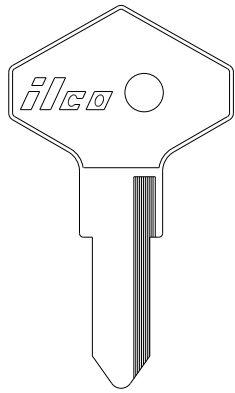
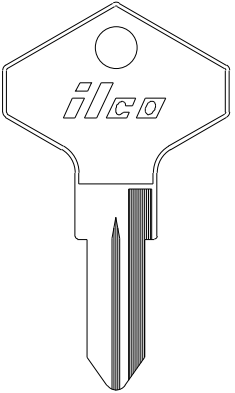
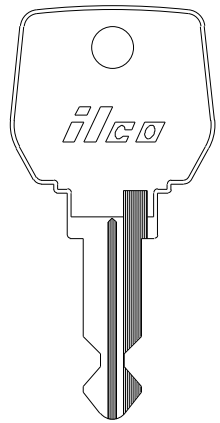
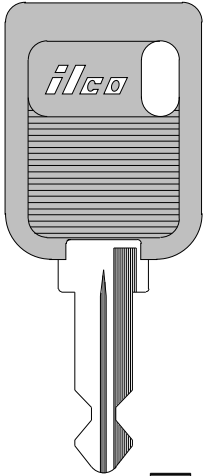
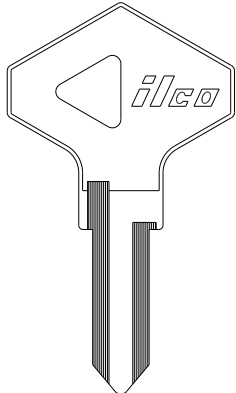




ALFA ROMEO

ILCO EZ		 X78 SP8			 F91CR —		 F91F —
		 X79 SP7			 F91C2 —		 F91G —
					 F91C8 —		 F91H —
			X64 SP6	 A81N —	 F91C —	 F91E —	

ALFA ROMEO

ILCO EZ		 F91FH —		 F91FS —			
		 F91GH —		 F91GS —			
		 F91HH —		 F91HS —			
		 F91EH —	 F91ES —	 X109 FT43	 X152 FT46	 X166 FT48	

AMERICAN MOTORS / JEEP / RENAULT

ILCO EZ					
		 X85 NE36	 X92 RN25	 X116 RN24	 RN24-P —