

APRILIA

ARIEL

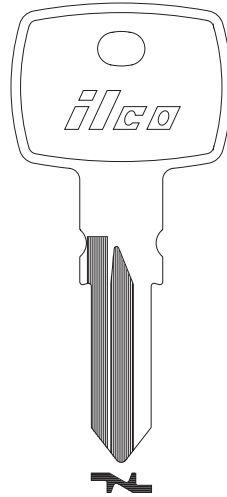
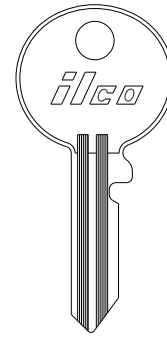
ASTON MARTIN



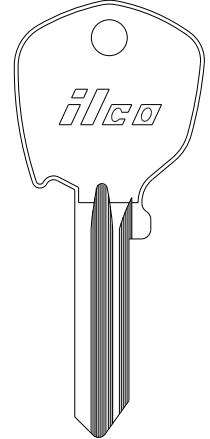
ZD23RT5-SI



ZD30T5-SI

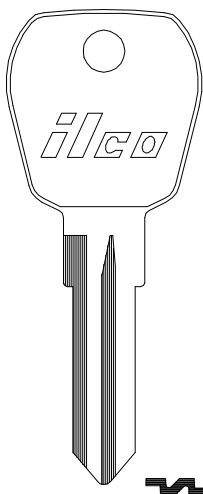
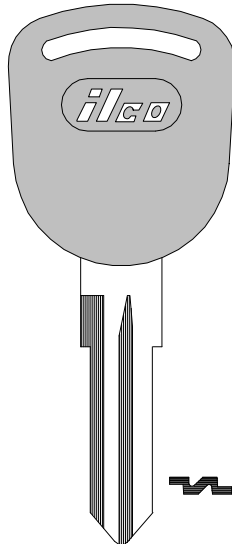

X270
TMC1


R62DH

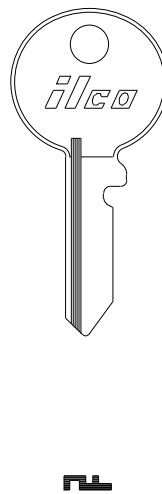

FT6R
F81E

ILCO
EZ

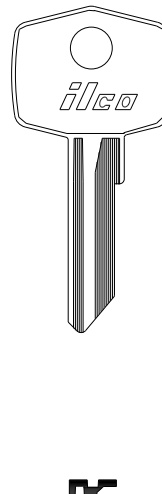
ASTON MARTIN


X86
FC7


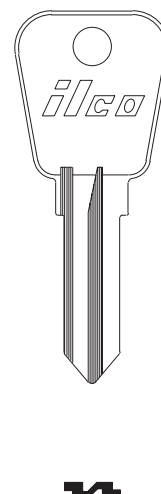
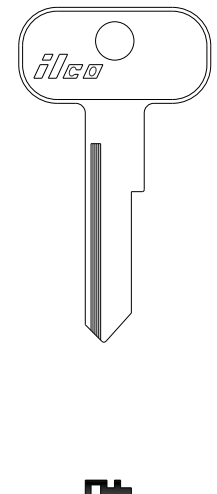
FC7-P



62DP



62FS

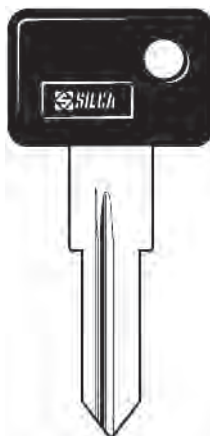

62FT
F68YT


H62DP

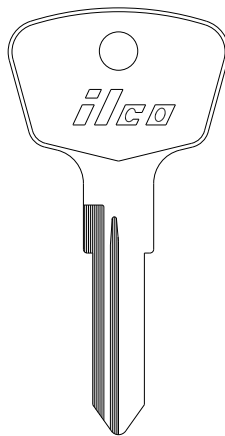
ILCO
EZ

ATALA

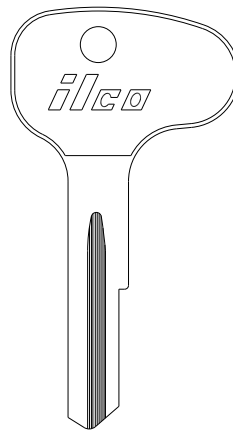
AUDI



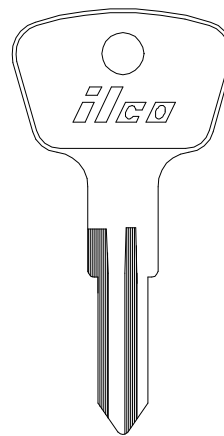
ZD16RP-SI



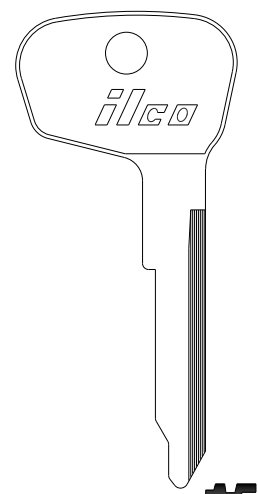
AD1



PR1



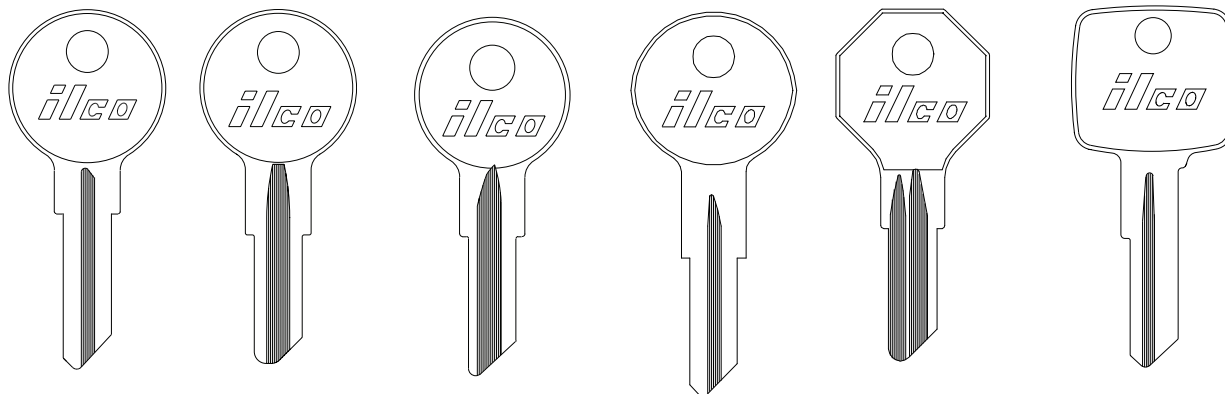
PA5



WT5

ILCO
EZ

BRIGGS & STRATTON / STRATTEC



1561

—



1098GM

—



1098M

B1



1098XL

B4



H1098DB

B16

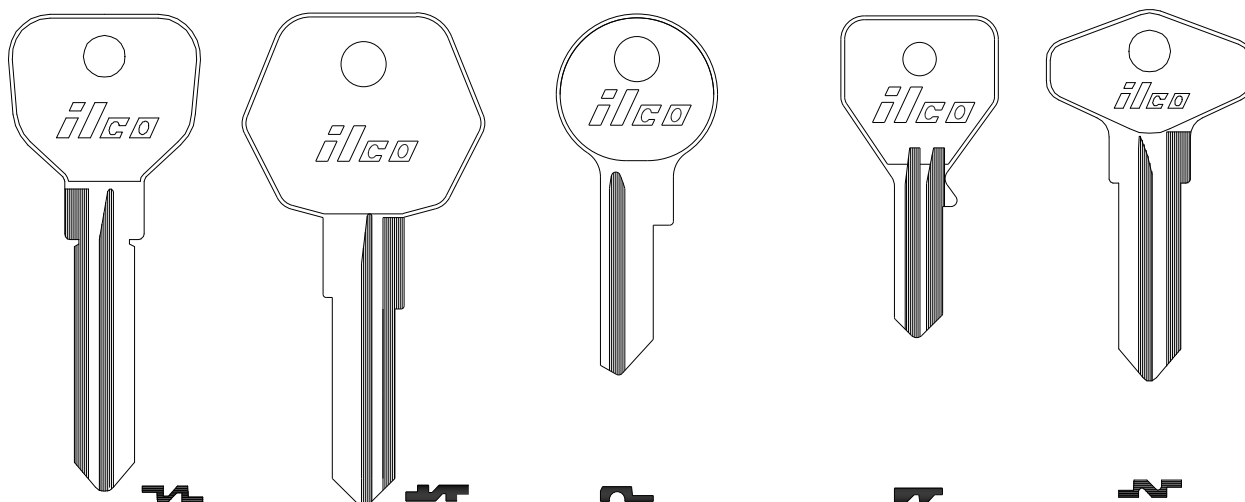


1595

—

ILCO
EZ

BRITISH LEYLAND



MG1

—



WB2

—



NE4

—



BR5

—

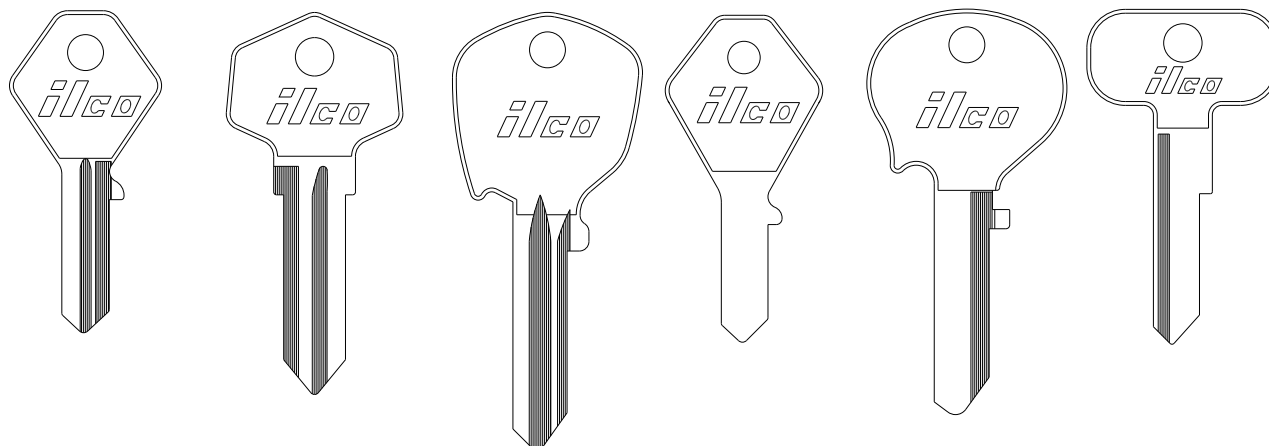


BL6

—

ILCO
EZ

BRITISH LEYLAND



BR6

—



CE6

—



FT6

—



FT6R

F81E



BR7

—



NE7

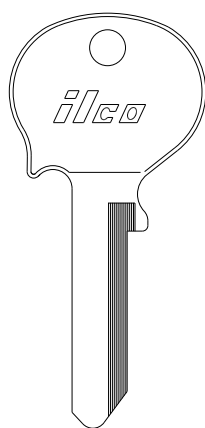
—

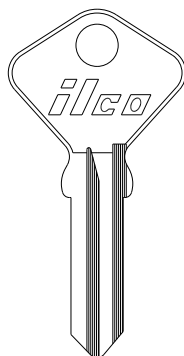


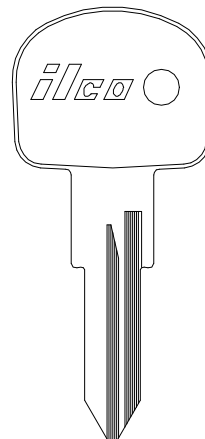
BR9

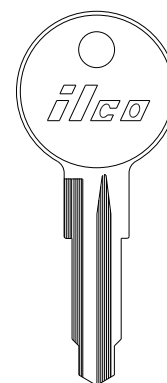
—

ILCO
EZ

FERRARI
FIAT


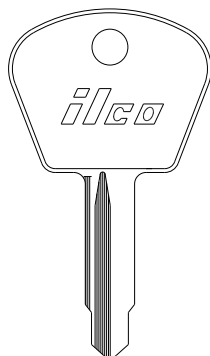
H61VR
 —


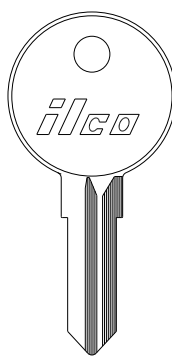
F91C
 —


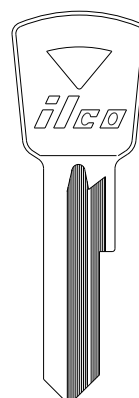
X152
 FT46


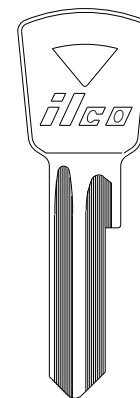
FS1
 —

 ILCO
EZ

FIAT


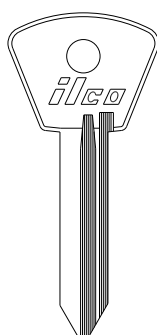
SP1
 —


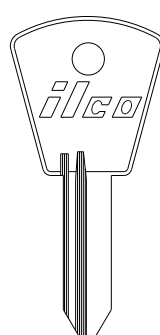
TR1
 —


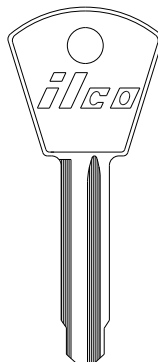
WS1
 —


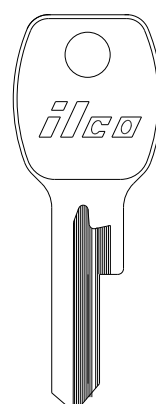
WS2
 —

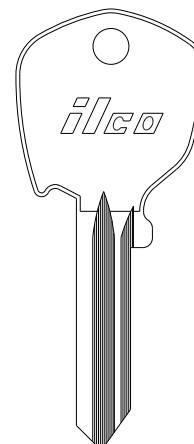
 ILCO
EZ

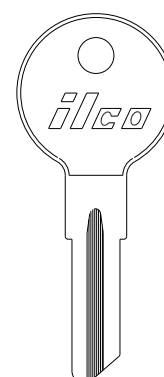
FIAT


AL3
 —


AL4
 —


SP5
 —


WS5
 —


FT6
 —


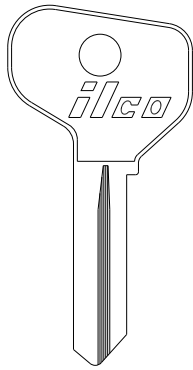
FT6R
 F81E

 ILCO
EZ

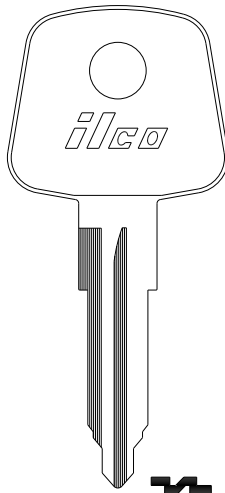
LA6
 —

IVECO

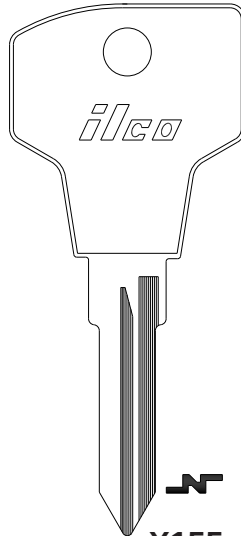
JAGUAR



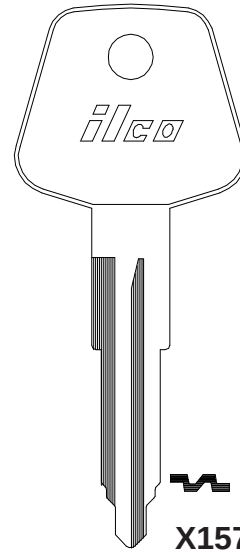
FT37
—



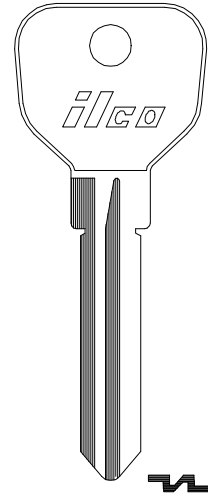
X50
AA3



X155
IV1



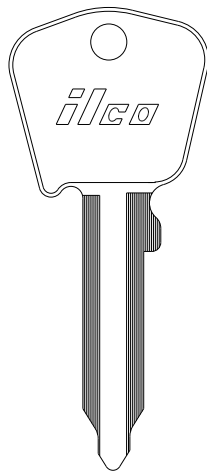
X157
LF17



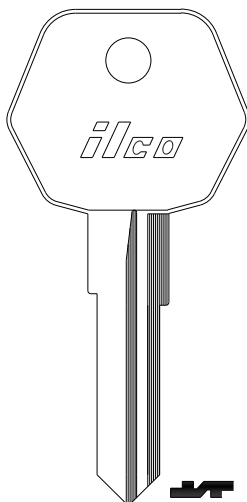
MG1
—

ILCO
EZ

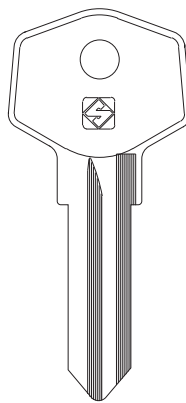
JAGUAR



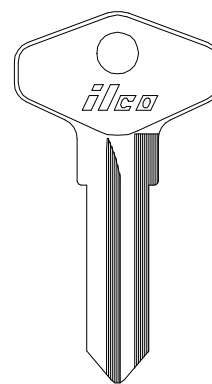
KL2
—



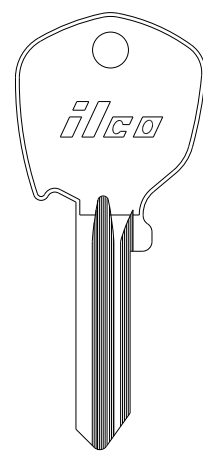
WB2
—



CEM5
—



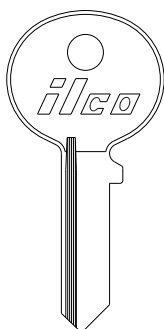
BL6
—



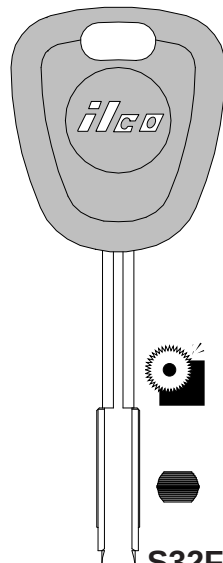
FT6R
F81E

ILCO
EZ

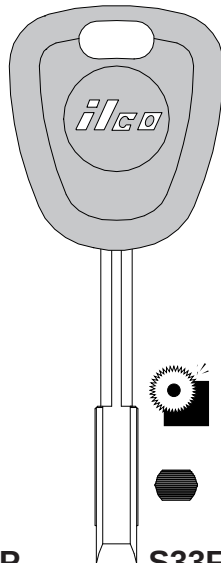
JAGUAR



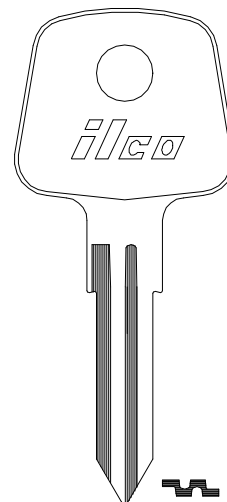
UN16
—



S32FJ-P
—



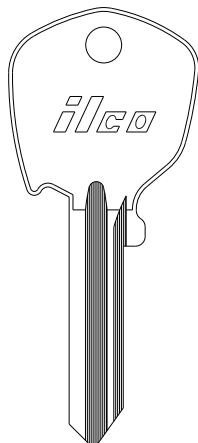
S33FJ-P
—



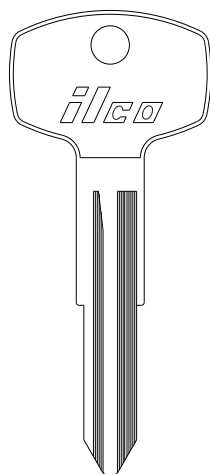
X51
AA2

ILCO
EZ

NISSAN

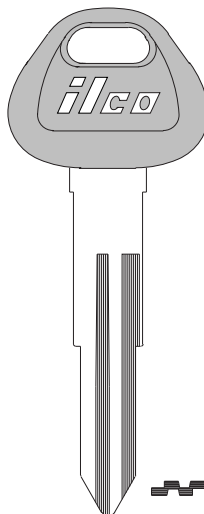

FT6
FT6R

— F81E

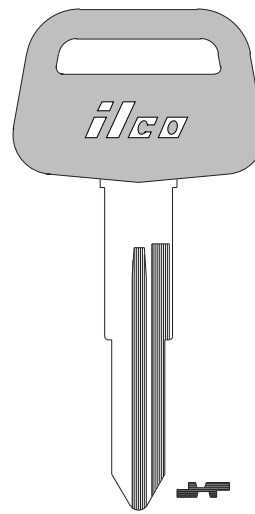

X6
X7

62DT

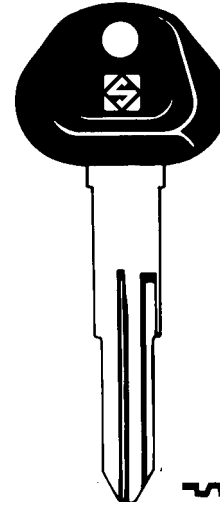
62DU


DAT6P

—


DAT6BP

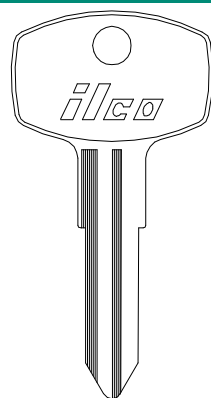
—


DAT6RP

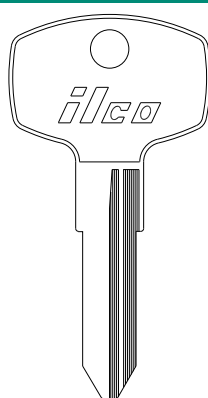
—

ILCO
EZ

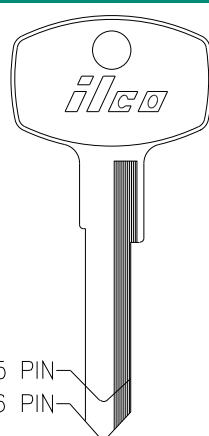
NISSAN


X10

62DV


DT20

—


5 PIN
6 PIN

5 PIN

DT13

—



6 PIN

DT9

—

5 PIN


DT14

—

6 PIN


DT10

—


DT15

—


DT11

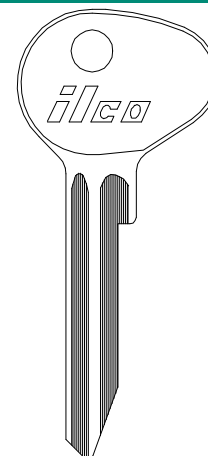
—


DT16

—


DT12

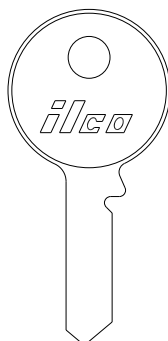
—


DA20

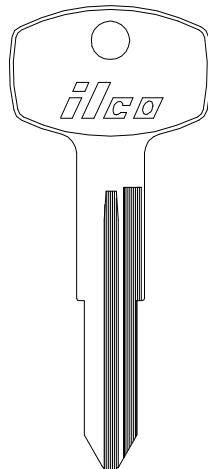
—

ILCO
EZ

NISSAN


65TA

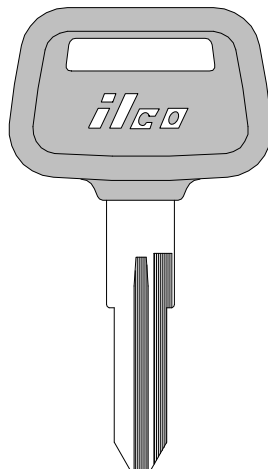
—


X115

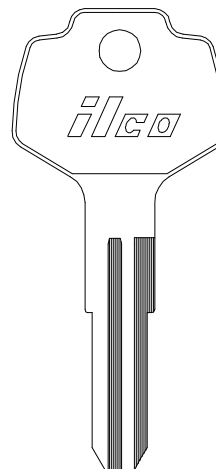
DA23


X114

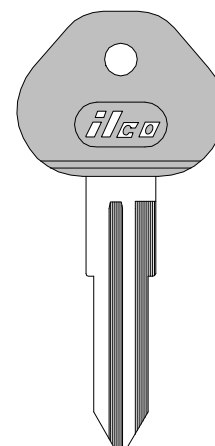
DA24


DA23-P

—


X123

DA25


DA25-P (-PC)

—

ILCO
EZ