

APRILIA

ARIEL

ASTON MARTIN





ZD23RT5-SI

—




ZD30T5-SI

—

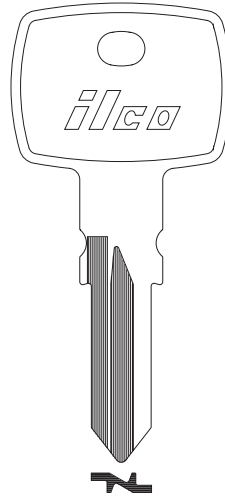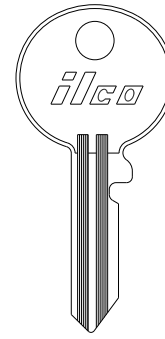
X270
TMC1


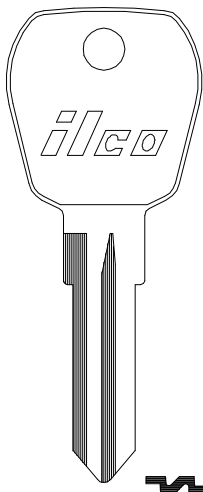
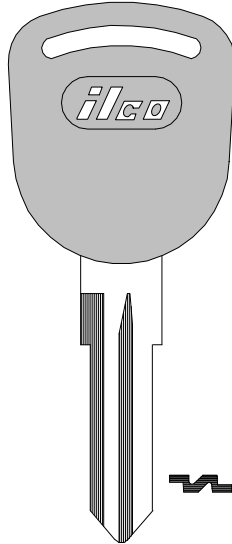
R62DH

—

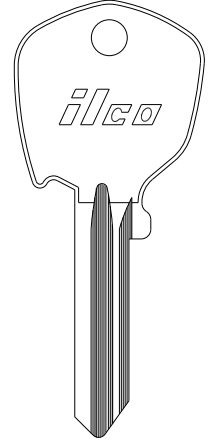
FT6R
F81E


—

ASTON MARTIN


X86
FC7


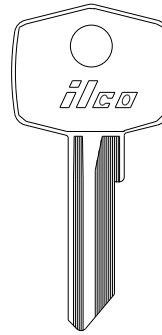
FC7-P

—

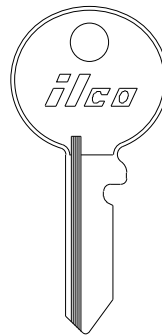


62DP

—




62FS

—

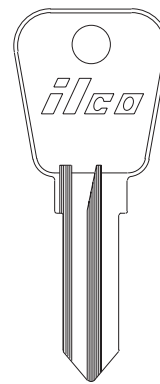
62FT
F68YT

—

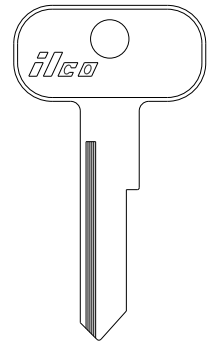


H62DP

—


ATALA

AUDI

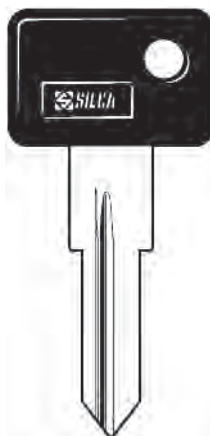


ZD16RP-SI

—

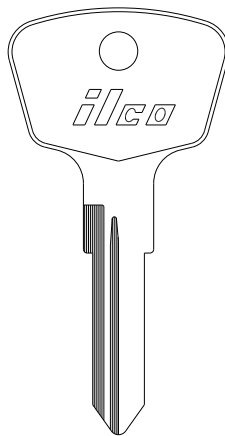


AD1

—

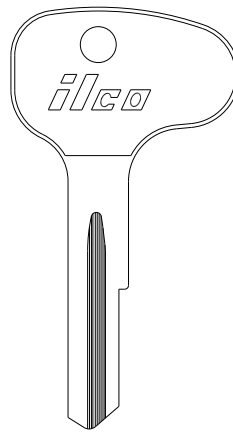


PR1

—

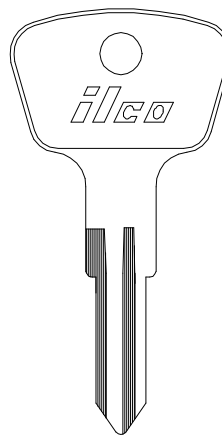

PA5

—

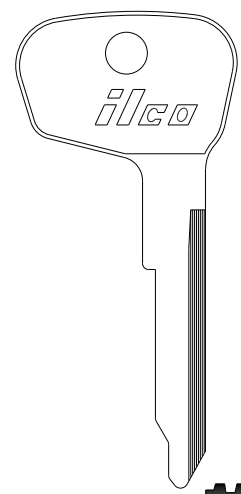

WT5


—

ILCO
EZ


ILCO
EZ

ILCO
EZ


BRITISH LEYLAND

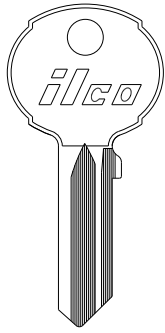**BR13**

—

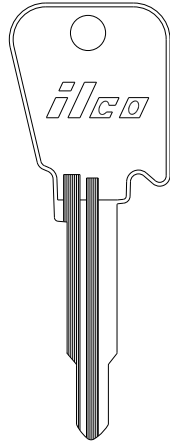**X13**


LF4

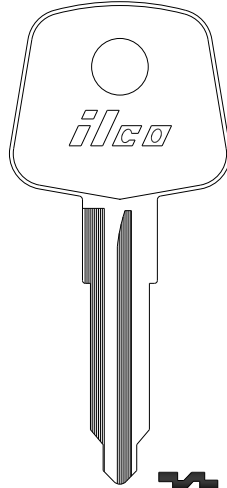**LF15**

—

**BR16**


—

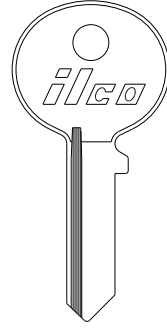**UN16**


—

ILCO
EZ


BRITISH LEYLAND

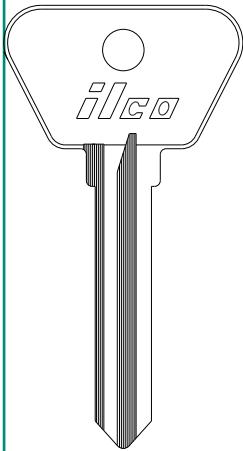**BR20**


—

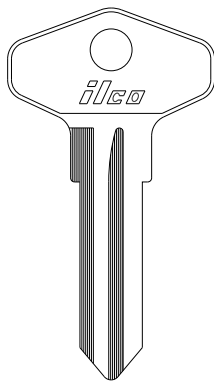**X20**


FC2

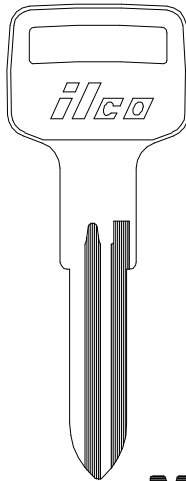**X29**

VO73

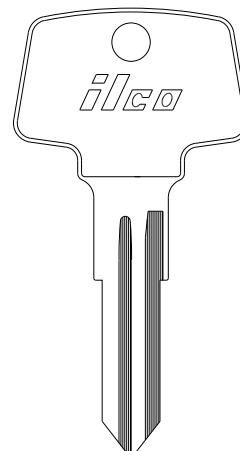**NE49**

—

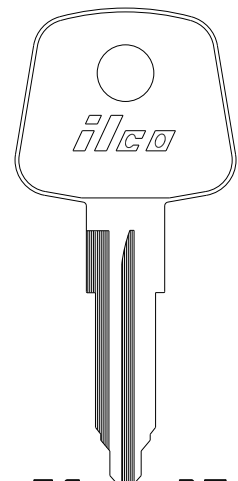**X50**


AA3

**LF13**


—

ILCO
EZ


BRITISH LEYLAND

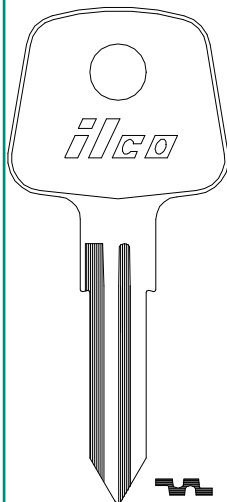**X51**

AA2

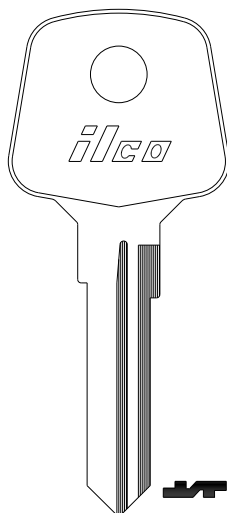**X55**

WB1

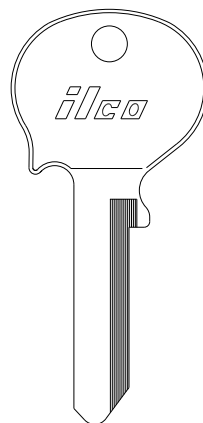**H61VR**

—

**62DC**

—

62DE

—

62DF

—

62DG

—

62DK

—

62DM

—

R62DM

—

F70S

—

M72F

—

62DH

—

62DP

—

ILCO
EZ

JAGUAR



62DG

—



62DH

—



62DK

—



62DM

—



62DP

—



R62DM

—



62DC

—



62DX

—




62FS

—




62FG

—

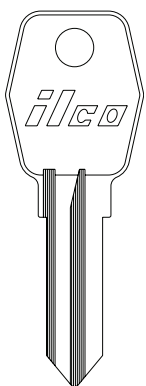

62FT

F68YT

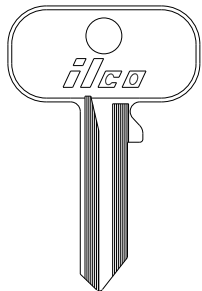

B62DR

—




B62DP

—


ILCO
EZ

JAGUAR

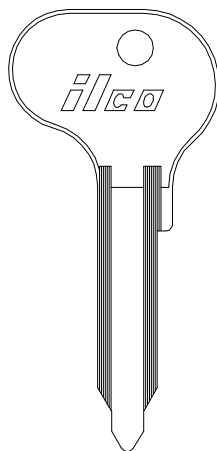


VW77

—

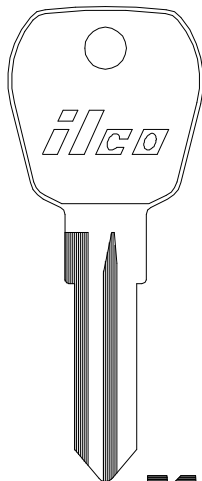


X86

FC7

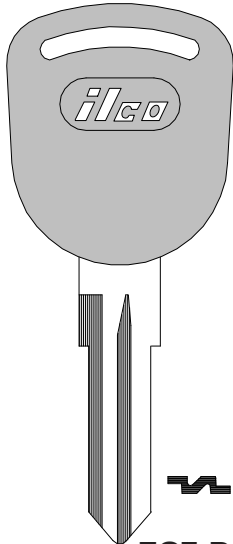


FC7-P

—

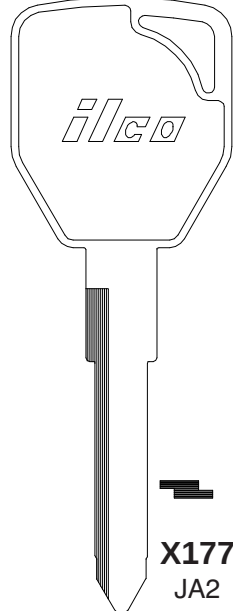

X177

JA2

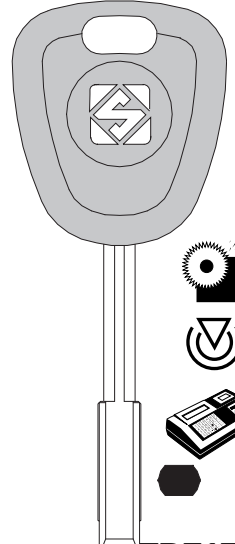


TBE1T5

—

ILCO
EZ


JAGUAR

JAWA CYCLE

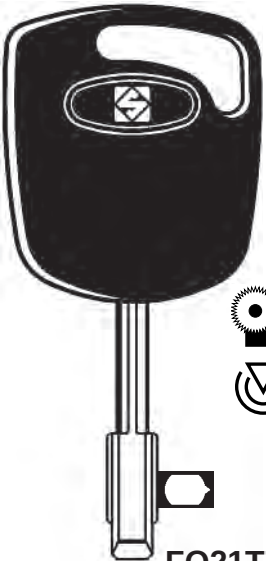


FO21T7-SI

—

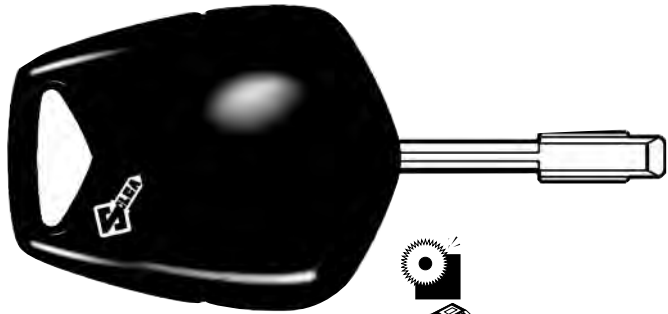

FO21EH2

—

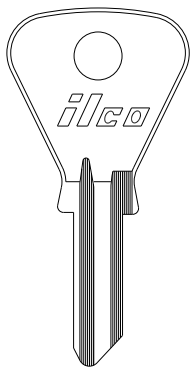

J66M

—

ILCO
EZ

**ILCO
EZ**


MOB	MOPED				
62DP —	Z1 —	Z3H —	SR61N —	Y61 —	Z91 —

**ILCO
EZ**

MORETTI					
61D —	R61G —	65FA —	R65FA —	66A —	66BB —

**ILCO
EZ**

MORGAN	MOTO GUZZI			
SEE BRITISH LEYLAND				
	ZD7-SI —	ZD9P-SI —	ZD24RDP-SI —	ZD30T5-SI —

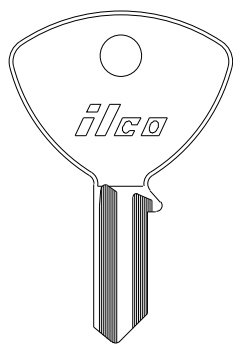RENAULT

R80B


—


X85


NE36


X92


RN25

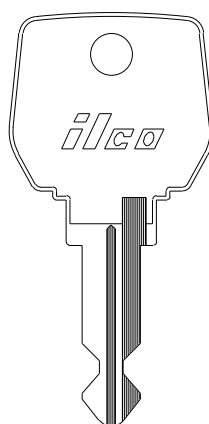
X116

RN24

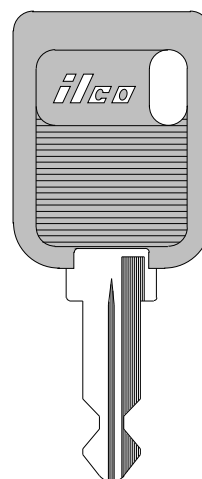

RN24-P

—

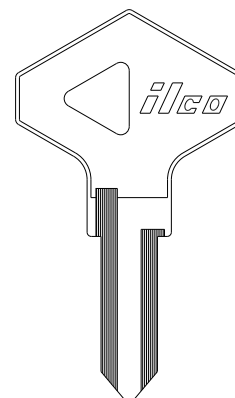

X122

RN29


ILCO
EZ

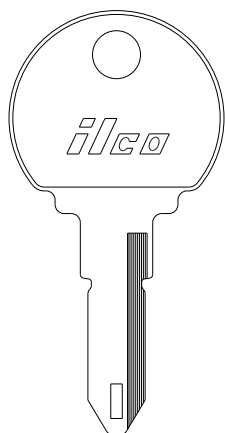RENAULT

X147

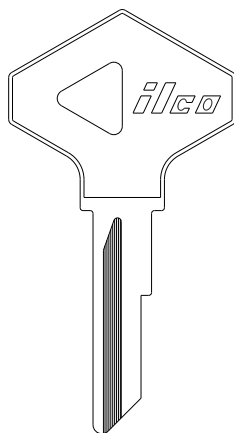
RN30


X150

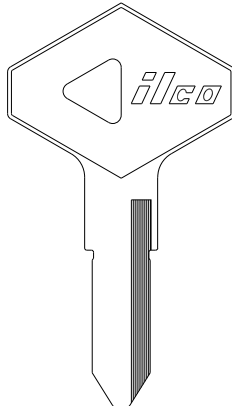
RN27


X171

RN31

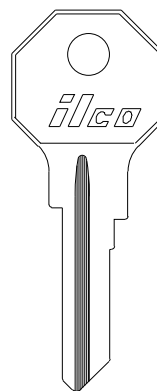

H199N

—

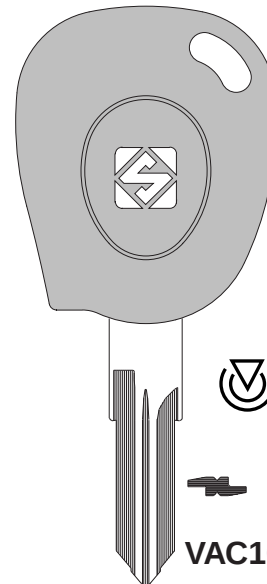

VAC102T1

—


ILCO
EZ

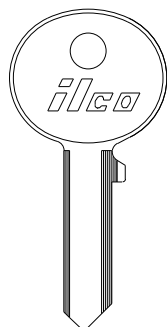RILEY
RIZZATO
ROLLS ROYCE

62DB

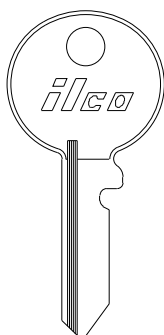
—


62DP

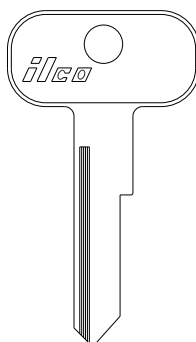—


H62DP


—

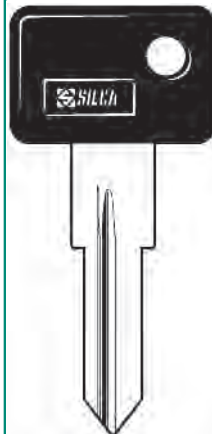
ZD16RP-SI

—


YL5

—

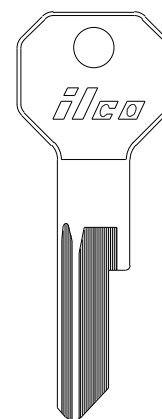
X28

62HE

ILCO
EZ

ROLLS ROYCE/BENTLEY


VEHICLE



					
62HA	62HB	62HC	62HD	62HF	62HG
—	—	—	—	—	—

ILCO
EZ

ROLLS ROYCE/BENTLEY ROOTES GROUP

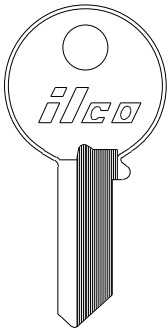



62JB
—





SR1
—



SR2
—

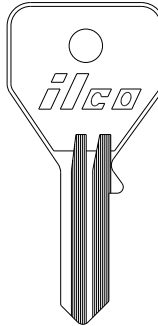


BR5
—

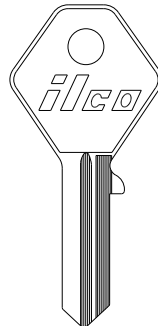



BR6
—

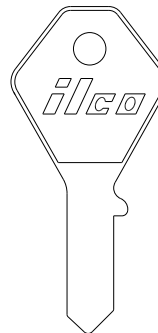



BR7
—

ILCO
EZ


ROOTES GROUP

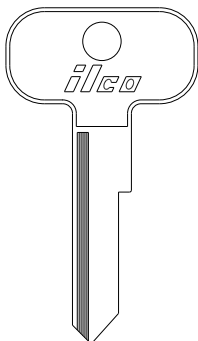


BR9
—

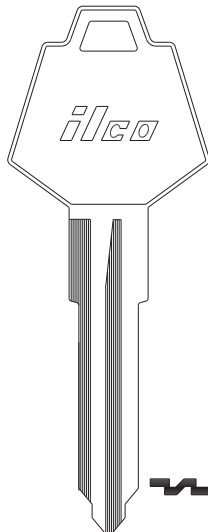

X16
P1771CR

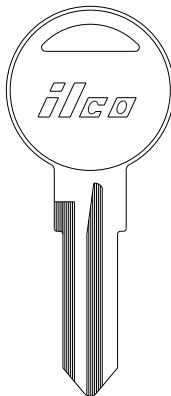


X17
S1771CR




62DC
—


62DG
—


R62DG
—


62DH
—


62DP
—



F70S
—


M72F
—

ILCO
EZ

TOYOTA

TRABANT

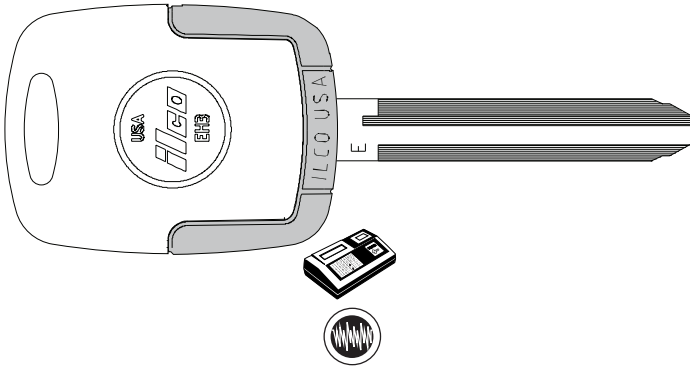


EH3
(Head Only)


EB3-E-TOY43
(Blade Only)




TOY43-EK3
(Complete Key)

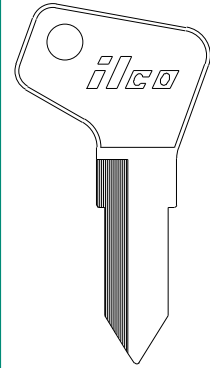


 
DB1 DB2
— —

ILCO
EZ


TRIUMPH

TRIUMPH MOTORCYCLE


**SEE
BRITISH
LEYLAND**

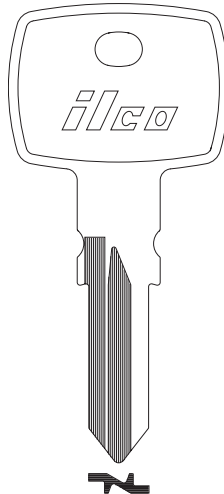



X270
TMC1

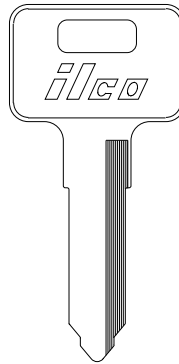


X259
KW14

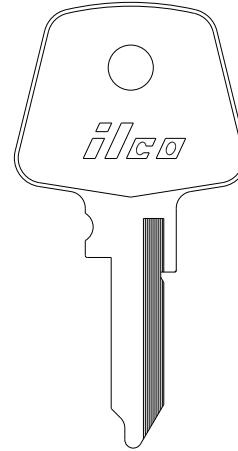


Y16
—

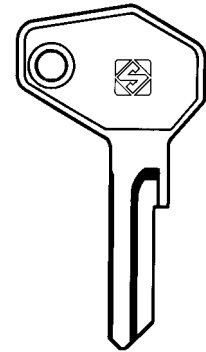


ZD7-SI
—

ILCO
EZ

TRIUMPH MOTORCYCLE

VAN GUARD

VAUXHALL





ZD24RDP-SI
—





62FS
—





R62DM
—

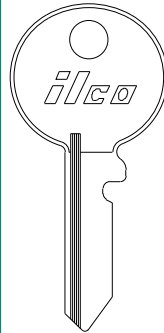


62DP
—

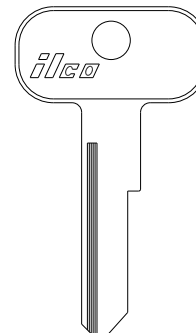



H62DP
—

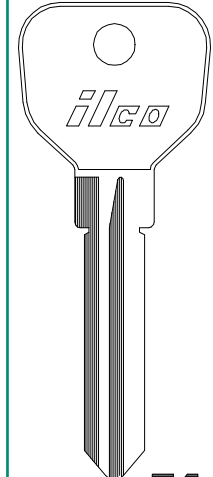


MG1
—


ILCO
EZ

VOLVO

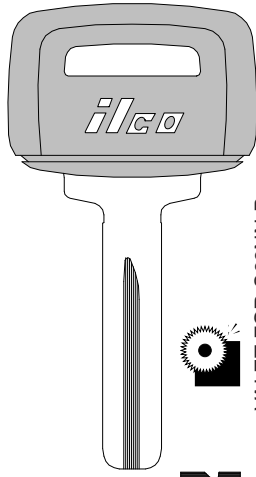



S67NN-P

—

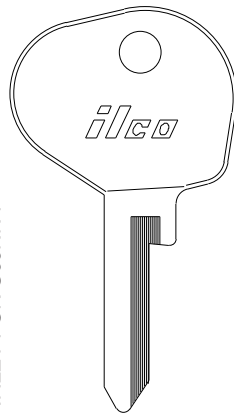


V80P

—

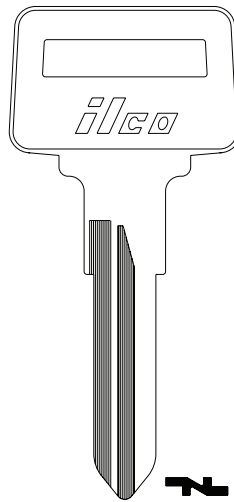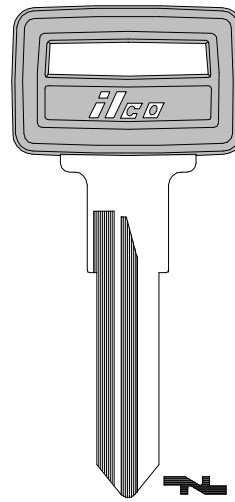
X80
VL6


VL6-P


—

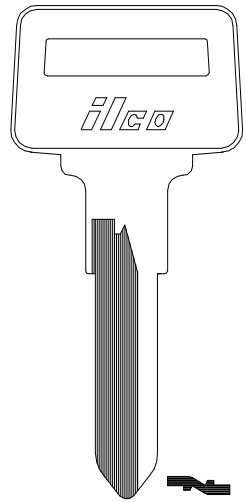
X140
VL8


VALET FOR S66NN-P



ILCO
EZ

VOLVO

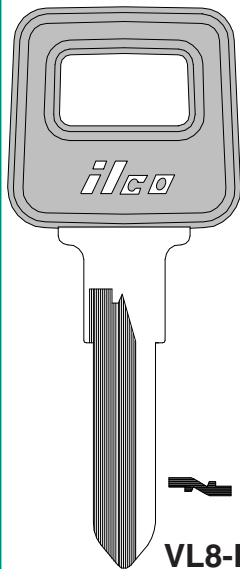


VL8-P

—

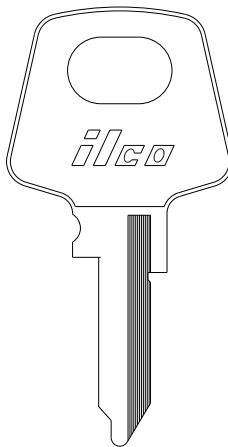
X163
BL11


WARTBURG

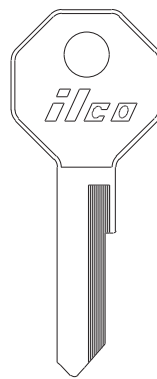


WAR3

—



WAR4

—

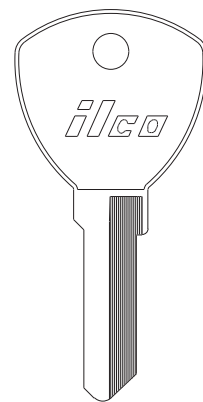

WA3

—



WAR1


WAR2

—

—


ILCO
EZ

WOLSLEY

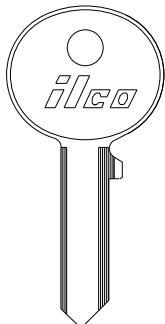


62DB

—

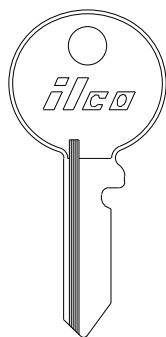


62DP

—

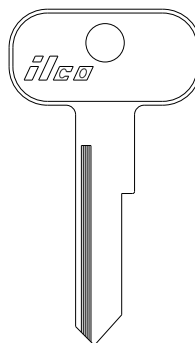

H62DP

—

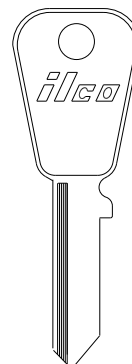


S62DP

—




YAMAHA

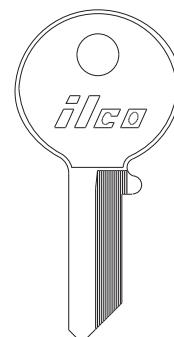

YH1

—

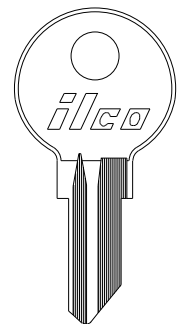

YH2

—


ILCO
EZ