




KAWASAKI

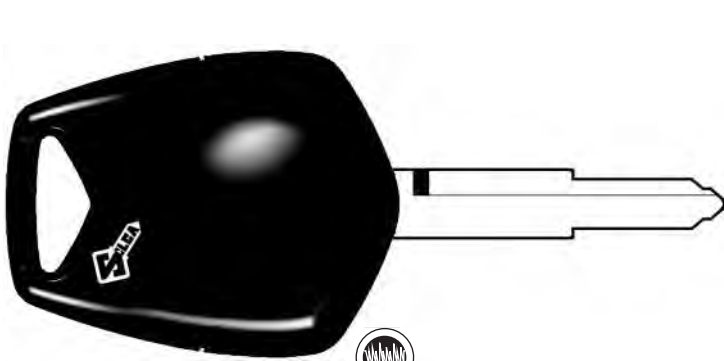

KW16EH2

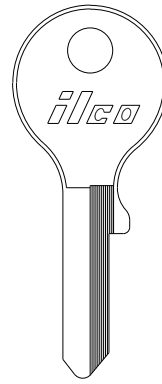

SR61N

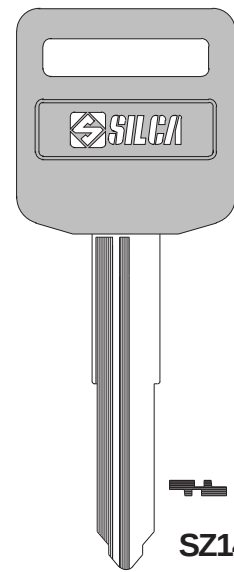


SZ14RAP





ILCO
EZ

KAWASAKI

KENWORTH

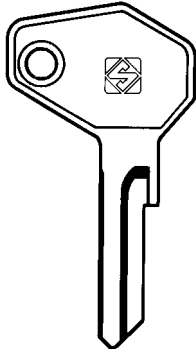

ZD7-SI

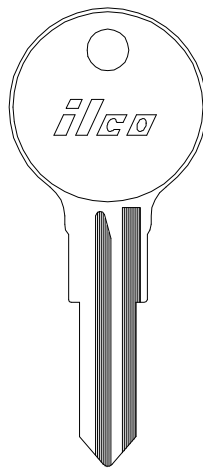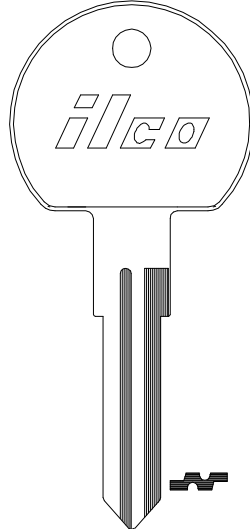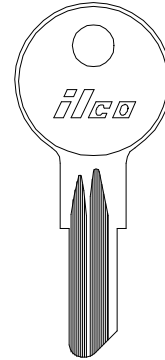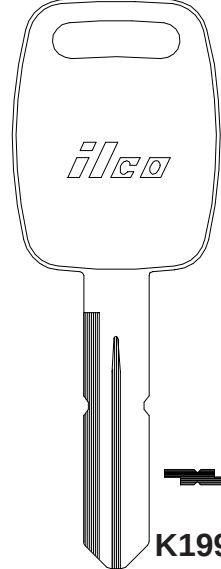
X53
V32

X170
NE48

1098DB
B5


K1994

ILCO
EZ

KENWORTH



KIA




1656



1657

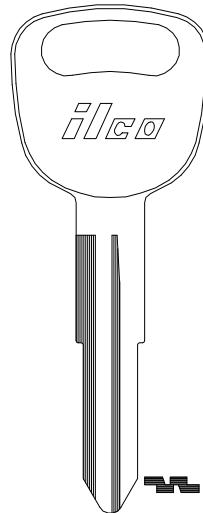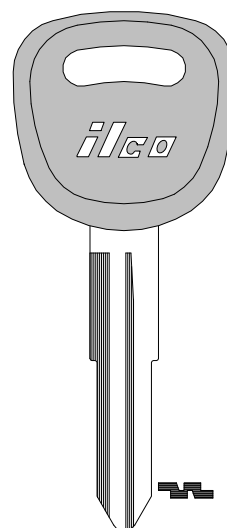
X233
KK1


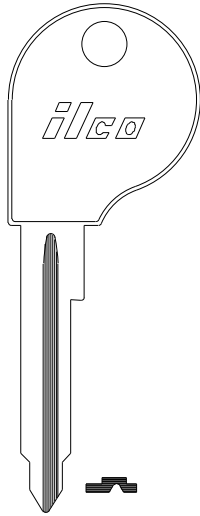
KK1-P

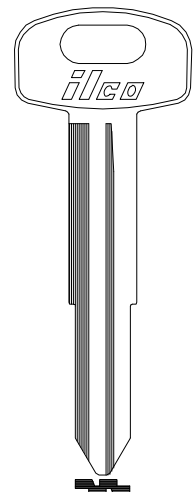
X240
KK2

ILCO
EZ



OPEL	PANHARD				
 OP91S —	 OP91SV —	 Y91C —	 X168 B61	 PA1 —	ILCO EZ
PANHARD					
 	 —	 —	 — P65A — P65C —	 —	
7DC —	62BZ —	R62BZ —	62R —	H62BZ —	
					ILCO EZ
PANHARD	PANTERA		PETERBILT		
 PA91 —	 FT37 —	 FT38 —	 X86 FC7	 FC7-P —	
				X53 V32	ILCO EZ

VOLKSWAGEN



HF35

—

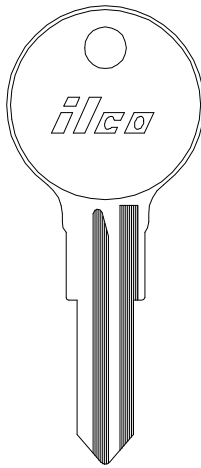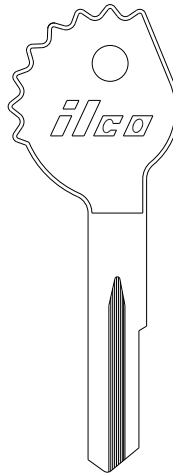X53
V32

OP60C

—




61N

—



61NC

—

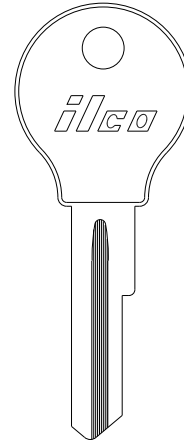

61VW

—



U61VW

—




V61VW

—


ILCO
EZ

VOLKSWAGEN

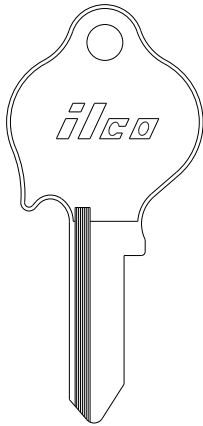


H61VM

—

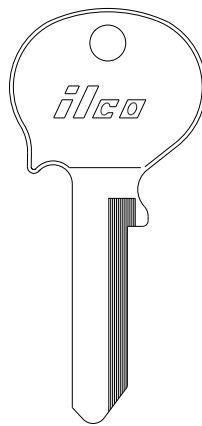


H61VR

—

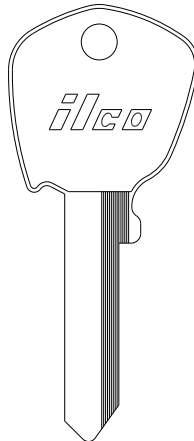

FT12R

—

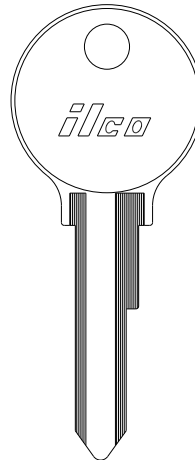


T61VR

—



62DW

—

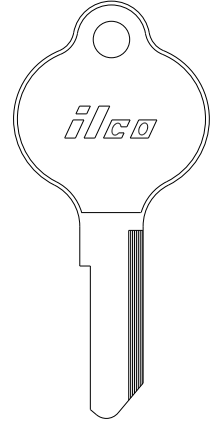

62VC

—



62VE

—


ILCO
EZ

VOLKSWAGEN




62VG

—

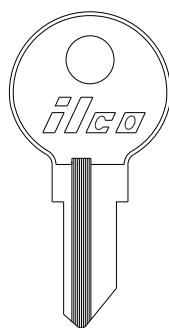


62VO

—

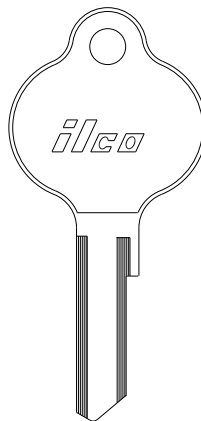


62VW

—

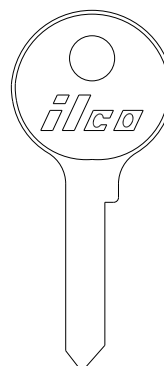

A62VC

—

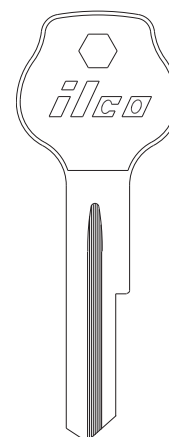

A62VN

—



HR62VK

—



L62VB

—

ILCO
EZ