

Cylinders

How to Order Cylinders...

How to Order Cylinders

Example: Standard 1 inch, 5 pin mortise cylinder, Arrow keyway with Adams Rite cam, satin chrome finish, keyed alike in pairs.



BH+

7 1 6 5

AA

2 - 2 6 D

- K A 2

Add 'BH' prefix for Bump Halt Bump Resistance Technology.

MODEL NO.

KEYWAY

CAM OR
TAILPIECE

FINISH

KEYING

1

Model Numbers

Mortise Cylinders					Turn Knob Rim Cylinders	
Model	Description				Model	Description
7124	3/4"	(19 mm)	4 Pin		7011	Turnknob Rim Cylinder
7155	1 1/16"	(23.8 mm)	5 Pin		Turn Knob Mortise Cylinders	
7165	1"	(25.4 mm)	5 Pin		Model	Description
7185	1 1/8"	(28.6 mm)	5 Pin	Drilled 6 Pin	7151	1 1/16" (23.8 mm) Turn Knob
7186	1 1/8"	(28.6 mm)	6 Pin		7161	1" (25.4 mm) Turn Knob
7205	1 1/4"	(31.7 mm)	5 Pin	Drilled 7 Pin	7181	1 1/8" (28.6 mm) Turn Knob
7206	1 1/4"	(31.7 mm)	6 Pin	Drilled 7 Pin	7201	1 1/4" (31.7 mm) Turn Knob
7207	1 1/4"	(31.7 mm)	7 Pin		7221	1 3/8" (34.9 mm) Turn Knob
7225	1 3/8"	(34.9 mm)	5 Pin	Drilled 7 Pin	7241	1 1/2" (38.1 mm) Turn Knob
7226	1 3/8"	(34.9 mm)	6 Pin	Drilled 7 Pin	7261	1 5/8" (41.2 mm) Turn Knob
7227	1 3/8"	(34.9 mm)	7 Pin		7281	1 3/4" (44.4 mm) Turn Knob
7245	1 1/2"	(38.1 mm)	5 Pin	Drilled 7 Pin	7301	1 7/8" (47.6 mm) Turn Knob
7246	1 1/2"	(38.1 mm)	6 Pin	Drilled 7 Pin	7321	2" (50.8 mm) Turn Knob
7247	1 1/2"	(38.1 mm)	7 Pin		ADA7151	1 1/16" (23.8 mm) ADA Turn Knob
7265	1 5/8"	(41.2 mm)	5 pin		ADA7161	1" (25.4 mm) ADA Turn Knob
7266	1 5/8"	(41.2 mm)	6 pin		ADA7181	1 1/8" (28.6 mm) ADA Turn Knob
7285	1 3/4"	(44.4 mm)	5 pin		ADA7201	1 1/4" (31.7 mm) ADA Turn Knob
7286	1 3/4"	(44.4 mm)	6 pin		ADA7221	1 3/8" (34.9 mm) ADA Turn Knob
7305	1 7/8"	(47.6 mm)	5 pin		ADA7241	1 1/2" (38.1 mm) ADA Turn Knob
7306	1 7/8"	(47.6 mm)	6 pin		ADA7261	1 5/8" (41.2 mm) ADA Turn Knob
7325	2"	(50.8 mm)	5 pin		ADA7281	1 3/4" (44.4 mm) ADA Turn Knob
7326	2"	(50.8 mm)	6 pin		ADA7301	1 7/8" (47.6 mm) ADA Turn Knob
					ADA7321	2" (50.8 mm) ADA Turn Knob
					41651	1 5/16" (23.8 mm) Captive Turn Knob
					41671	1 1/8" (28.6 mm) Captive Turn Knob
Key-In-Knob Cylinders					Rim Cylinders	
Model	Description				Model	Description
15395	5 Pin	UniversalLockset/Leverset/Padlock			7075	5 Pin Cylinder with screw cap
15396	6 Pin	UniversalLockset/Leverset/Padlock			7076	6 Pin Cylinder with screw cap
15495	5 Pin	Cylindrical Deadbolt			Dummy Rim Cylinders	
15496	6 Pin	Cylindrical Deadbolt			Model	Description
15695	5 Pin	Emtek Cylindrical Deadbolts			7010	1 1/8" (28.6 mm) Dummy Rim Cylinder
15696	6 Pin	Emtek Cylindrical Deadbolts			Dummy Mortise Cylinders	
15795	5 Pin	Sargent 6 Line, 10 Line, T Zone			Model	Description
15796	6 Pin	Sargent 6 Line, 10 Line, T Zone			7150	1 5/16" (23.8 mm) Dummy
15985	5 Pin	Combination Knob/Deadbolt			7160	1" (25.4 mm) Dummy
15995	5 Pin	Combination Knob/Deadbolt			7180	1 1/8" (28.6 mm) Dummy
15996	6 Pin	Combination Knob/Deadbolt			7200	1 1/4" (31.7 mm) Dummy

 
 
 
 
 
 
 
 
 
 
2

Keyways

Arrow AA 1179	Sargent LA-LC GB LA-LC	Schlage SX C-K, 1145
Corbin 60 CA 1001EH	Sargent RA-RC GC RA-RC	ILCO® UA X1054K
Corbin 67 CB 1001EN	Kwikset KS 1176	Lori L100 Eagle 11929 Harloc 700
Corbin 77 CC R1001EN	Lockwood LA 1004	UB
Corbin CD 59A1-A2	Composite NA R1064E	Lori 90 6 pin only UD Centric 90
Corbin/ Russwin CE L4	Composite NB HR1	Lori 80 5 pin UE Lori 80
Dominion 1054F DA S54F	Russwin RA 5981R N1011P	Weiser E Falcon WA 1054WB 1054WC
Schlage Everest EA C123	Russwin D1 RB 1011D1	Weiser WE P1555
Schlage Everest EB C145	Schlage C SC 1145	Yale 8 YA 999
Segal 9 FA (1022)	Schlage E SE 1145E	Yale YG Yale GA
Sargent LA GA 1007LA	Schlage F SF 1145F	

Minimum Order of
10 each per item.

3 Cams & Tailpieces

1 Standard (863G)		13 22PR-E-RM (863K)		10 Long Standard 2 3/4" (60.3mm) 862B for 7075	
2 Adams Rite (863A)		15 Schlage L (863M)		14 Long Lazy Action 2 3/4" (60.3mm) 862L for 7075	
3 Clover (863D)		16 Sargent/Yale (863N)			
4 Narrow (863E)		17 Segal/ Emhardt (863P)			
5 Marks Cam (863F)		18 Lori Deadbolt (863R)			
6 Yale (863)		19 Clover Corbin/ Russwin Best (863S)			
7 Sargent Offset (863U)		20 Adams Rite 4070 (863T)			
11 14PR-RM (863H)		23 Falcon/ Saflok (863V)			
12 22PR-A-RM (863J)					

4 Finish Codes

Code	Description	US#	BHMA
03	Bright Brass	03	605
03P	Bright Brass Permanent	03	605
04	Satin Brass	04	606
05	Antique Brass	05	609
10	Satin Bronze	10	612
10B	Oil Rubbed Bronze	10B	613
26	Bright Chrome	26	625
26D	Satin Chrome	26D	626
28	Clear Aluminum Anodized	28	628
29	Black Aluminum	19	622
32	Bright Stainless Steel	32	629
32D	Satin Stainless Steel	32D	630
46	Duracolor Brown Aluminum	46	624

All finish codes are ANSI/BHMA E (equivalent in appearance to category A) codes and do not reflect the product's base material.

Master Keys

Master keys will be sent separately from the cylinders via certified mail, return receipt requested. Name and address for this package must be supplied with the cylinder order.

5 Keying Codes

Code	Description
KA	All keyed alike
KD	Keyed different
KA2	Keyed alike in pairs
KA4	Keyed alike in fours
0B	0 bitted - Blade Height
MK Φ	Master keyed
GMK Φ	Grand master keyed

Φ When requesting MK or GMK, an additional Keying Code is required (KA, KD, KA2, etc.)
Example: 7165AA2-26D-MK/KA2

Chart below indicates stock KA biting combinations this does not apply to any other keying code.

Factory Keyed Alike Combinations

YA .019 (OEM)	SC .015 (OEM)
13335	13531
14251	15513
14455	24642
24158	26264
34532	31315
34562	31515
41224	33563
41242	34032
41255	34562
41256	35315
41263	42642
41321	44634
42131	46246
42145	51315
43244	54645
43263	55313
44254	62646
45324	64254
43356	66464
14544	78348



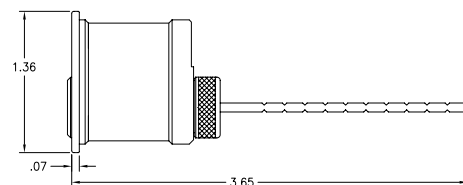
 
 
Rim Cylinders

Iico Rim Cylinders are machined from solid brass bar stock, engineered and manufactured to OEM specifications. Master Key and Grand Master Key quality, and are re-keyable to original manufacturers systems. The broad selection of models and components within our line provides you with the flexibility to cover numerous applications

Rim Cylinders are used on 1 3/8" (35mm) – 2 1/4" (57 mm) thick doors.

7075 & 7076 Rim Cylinders - Keyed

- Model 7076 is 6 pin
- 13 finishes - 03, 03P, 04, 05, 10, 10B, 26, 26D, 28, 29, 32, 32D, 46
- 31 keyways
- Screw cap design
- 1 1/8" (28.6mm) Length
- Includes rigid tailpiece installed and lazy action tailpiece in box
- Includes trim ring, mounting plate, and break off screws
- Horizontal or vertical tailpiece
- Factory master keying/construction master keying available



7010 Rim Cylinders - Dummy

- 13 finishes - 03, 03P, 04, 05, 10, 10B, 26, 26D, 28, 29, 32, 32D, 46
- 1 1/8" (28.6mm) Length
- Includes trim ring, mounting plate, and break off screws



7010 Rim Cylinders - Turnknob

- 12 finishes - 03, 04, 05, 10, 10B, 26, 26D, 28, 29, 32, 32D, 46
- 1 1/8" (28.6mm) Length
- Includes trim ring, mounting plate, and break off screws
- Horizontal or vertical tailpiece

