

## ProSeries® High Security

- Greatest physical security available:
  - Heavy steel bodies
  - Hardened steel and boron alloy shackles for superior cut resistance
  - Dual deadbolt locking for extreme resistance to prying
- High key security:
  - 5-pin tumbler ProSeries® cylinders provide tens of thousands of key changes
  - Special spool pins are virtually impossible to pick
- Rekeyable - replaceable cylinder and shackle

 


## Solid Iron Shroud


- Greatest security against bolt cutters
- Proprietary rustproofing for longer life
- Defeats attempts to pry and cut

Master Lock Model#	Laminated Steel Description	Vertical Shackle Clearance (B)
6321	2-1/8 in. (54mm) w. Body. Shackle Dim.: A: 5/16 in. (8mm) C: 7/8 in. (22mm)	3/4 in. (19mm)
6325	2-3/8 in. (60mm) w. Body. Shackle Dim.: A: 3/8 in. (10mm) C: 7/8 in. (22mm)	3/4 in. (19mm)
6327	2-5/8 in. (67mm) w. Body. Shackle Dim.: A: 7/16 in. (11mm) C: 7/8 in. (22mm)	3/4 in. (19mm)

Keying Options:	KD-Keyed Different (default option), KA-Keyed Alike, MK-Master Keyed, N-BumpStop® Advanced Cylinder Technology, WP4-Edge® Key Control 4-pin and WP6-Edge® Key Control 6-pin cylinders
-----------------	---



6321

 

7035  
7045


## Solid Steel

 - Outstanding protection against physical attacks
- Chrome rustproofing provides longer life
- Shrouded & hidden shackle models defy bolt cutters and prying


Master Lock Model#	Solid Steel Description	Vertical Shackle Clearance (B)
7030	1-9/16 in. (40mm) w. Body. Shackle Dim.: A: 1/4 in. (6mm) C: 25/32 in. (20mm)	1-1/16 in. (27mm)
7035	1-9/16 in. (40mm) w. Body, Shrouded. Shackle Dim.: A: 1/4 in. (6mm) C: 25/32 in. (20mm)	1-1/16 in. (27mm)
7040	1-3/4 in. (44mm) w. Body. Shackle Dim.: A: 5/16 in. (8mm) C: 29/32 in. (23mm)	1-3/16 in. (30mm)
7045	1-3/4 in. (44mm) w. Body, Shrouded. Shackle Dim.: A: 5/16 in. (8mm) C: 29/32 in. (23mm)	1-3/16 in. (30mm)
7050	2 in. (51mm) w. Body. Shackle Dim.: A: 3/8 in. (10mm) C: 29/32 in. (23mm)	1-1/2 in. (38mm)
6230	2-1/2 in. (63mm) w. Body. Shackle Dim.: A: 7/16 in. (11mm) C: 7/8 in. (22mm)	1-1/8 in. (29mm)
6270	2-7/8 in. (73mm) w. Body. Hidden 3/8 in. (10mm) Diameter Shackle: Stepped Back	n/a
6271	2-7/8 in. (73mm) w. Reinforced Die Cast Body. Hidden 3/8 in. (10mm) Diameter Shackle: Stepped Back	n/a
770	9 in. (23mm) w. x 4-1/2 in. (11.4cm) High Solid Steel Hasp. Use With 6270 and 6271 Locks	n/a

Keying Options:	KD-Keyed Different (default option), KA-Keyed Alike, MK-Master Keyed, N-BumpStop® Advanced Cylinder Technology, WP4-Edge® Key Control 4-pin and WP6-Edge® Key Control 6-pin cylinders
-----------------	---


Shackle Options:	LF = 1-9/16 in. (40mm) - Lock Model 7030 LH = 2 in. (51mm) - Lock Model 6230 LJ = 2-1/2 in. (63mm) - Lock Models 7040, 7050 LT = 3 in. (72mm) - Lock Model 7030
------------------	--




7030  
7040  
7050

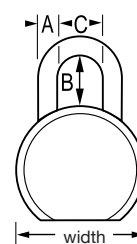

6230

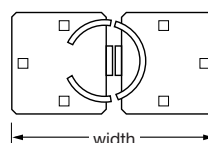

770

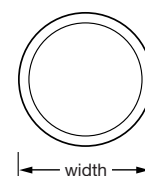

6270, 6271