

## Cam and Utility Locks

Medeco® XT cam locks are built for strong physical security and offer all the benefits of the Medeco XT Electronic Locking System. Medeco XT cam locks are available in lengths of 7/8" and 1-1/8" with a wide variety of cams and security collars. The cylinder is designed for interior and exterior use and requires no wiring or modification to the door. Audit information recorded in both the lock and key shows a time-and-date stamped record of every event, including authorized accesses and unauthorized attempts. A quick retrofit to existing hardware – all in one convenient package. An excellent application for utility cabinets, retail fixtures, narcotics storage, safes and more.



### Cam Locks

Description	Part Number	Price
7/8" Cam lock assembly	EN-150002-XXX (Op Code)	
1 1/8" Cam lock assembly	EN-150003-XXX (Op Code)	

### Cam Lock Operation Codes

Description	Op Code
2 flat, 1 keypull, clockwise 90 degree	219
2 flat, 1 keypull, counter-clockwise 90 degree	239
2 flat, 1 keypull, clockwise 180 degrees	259

### Medeco XT T-bolt Cylinders

Description	Part Number	Price
Medeco XT T-bolt – Key Retaining, unlocked at 180 degree	6280550 G -XX	
Medeco XT T-bolt – Non-Key Retaining, unlocked at 360 degree	6282550 G -XX	

### Medeco XT Cam Lock

Description	Part Number	Price
Medeco XT Cam Lock 180 degree, Non-Key Retaining	600650269 G -XX	

### Medeco XT Switch Locks

Description	Part Number	Price
2 Position, Key Retaining	6522560 G -121-XX	
2 Position, Non-Key Retaining	6522560 G -122-XX	

## Retail/Showcase Locks

Medeco® XT has an electronic cylinder for many types of retail applications. Ideal for loss & liability management with flexible authorization and auditing capabilities. Respond quickly to security threats, lost or stolen keys, or personnel changes without the added cost of changing your locks and keys. The cylinder is powered by the rechargeable key so no wiring or power supply is needed. Medeco XT Plunger Locks are specifically designed for use in wooden or metal sliding doors. Cabinet style locks are also available and along with the plunger locks are ideal applications for security merchandise showcases, metal cabinets, and laboratory and office furniture.



### Medeco XT Retail/Showcase Locks


Description	Part Number	Price
Cabinet Lock, Latchbolt	490359 G	
Cabinet Lock, Deadbolt	490366 G	
XT Deadbolt Cabinet Lock, KR	6210555 G XX	
XT Deadbolt Cabinet Lock, NKR	6212555 G XX	
XT Spring Latch Cabinet Lock	6211555 G XX	
XT T Bolt Cam Lock, KR	6280550 G	
XT T Bolt Cam Lock, NKR	6282550 G	

## How To Order Key-in-Knob/Lever Cylinders

Complete part numbers are required for all orders. To determine the correct part number, fill in the "X's" in sequential order.

1	2	3	4	5			
200200S1 base part #	T cylinder	05 finish	LT keyway	S pinning			
Refer to pages 71-89 for descriptions and technical specifications to find the corresponding base part number.	<ul style="list-style-type: none"><li>– = Original</li><li>K = Medeco KM</li><li>T = Medeco<sup>3</sup></li><li>W = Biaxial</li><li>J = Medeco<sup>3</sup> BiLevel</li><li>C = Classic CLIQ</li><li>N = Medeco X4</li><li>S = M<sup>3</sup> CLIQ</li><li>M = Medeco X4 CLIQ</li></ul>	<p>Refer to the inside back cover of this catalog for finish options. Include the corresponding two digit finish number.</p> <p>Upcharge for split finish.</p>	<p>Insert keyway if known or contact Customer Service for help.</p>	<table><tr><td>S = Sub-Assembled (Uncombined)  No additional information needed</td><td>P = Pinned (Combined)  Keyed alike (KA)  Keyed different (KD)  2 keys per cylinder</td><td>M = Master Keyed  Provide specific pinning or contact Customer Service for support  Must specify quantity for keys.</td></tr></table>	S = Sub-Assembled (Uncombined)  No additional information needed	P = Pinned (Combined)  Keyed alike (KA)  Keyed different (KD)  2 keys per cylinder	M = Master Keyed  Provide specific pinning or contact Customer Service for support  Must specify quantity for keys.
S = Sub-Assembled (Uncombined)  No additional information needed	P = Pinned (Combined)  Keyed alike (KA)  Keyed different (KD)  2 keys per cylinder	M = Master Keyed  Provide specific pinning or contact Customer Service for support  Must specify quantity for keys.					

### BUILD A KEY-IN-KNOB/LEVER PART #:

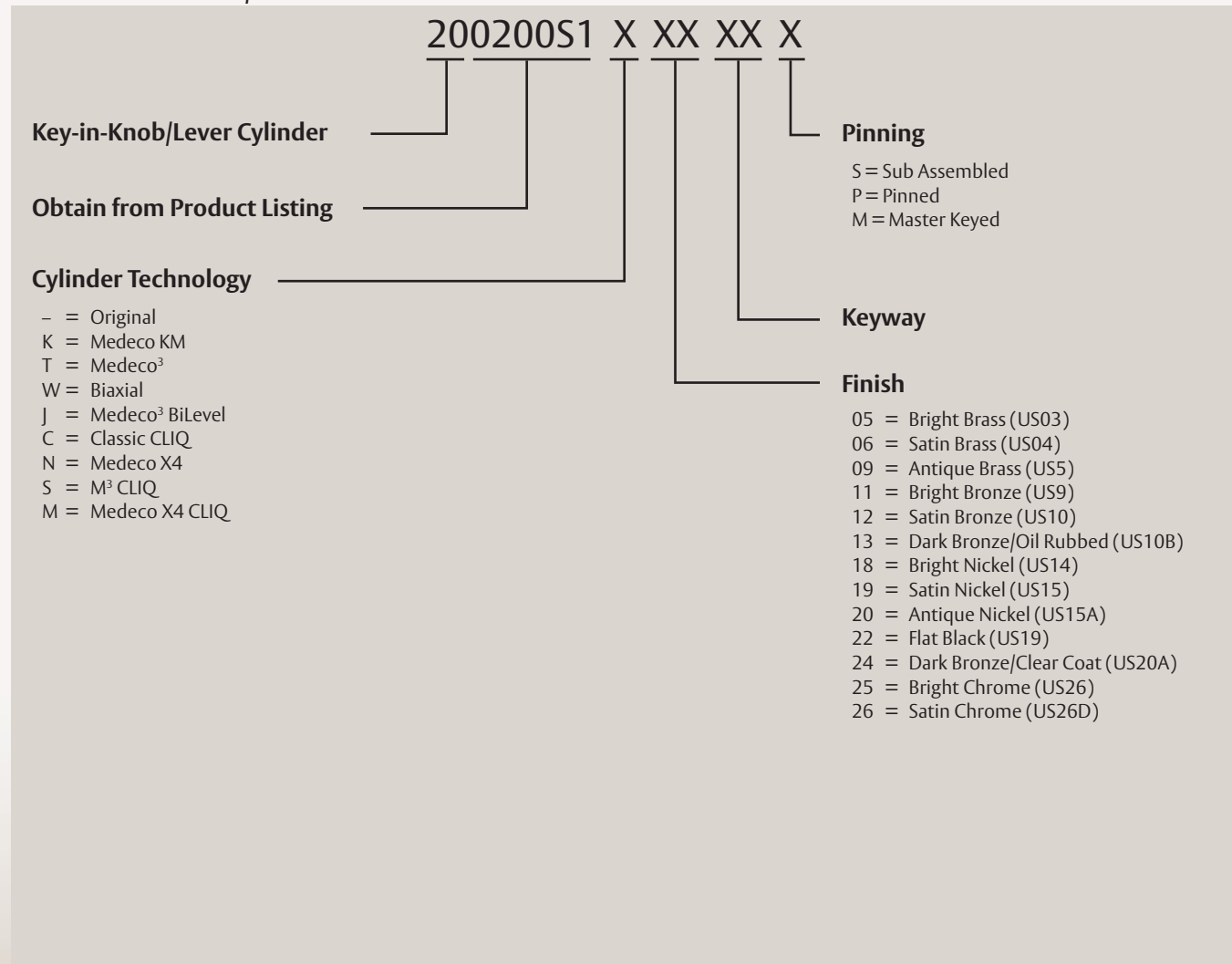

\*\*Refer to the eCylinder section for more detail on specific technologies available and pricing. Technologies are represented by the following letters:  
 T = Medeco<sup>3</sup>, S = M<sup>3</sup> CLIQ, J = Medeco<sup>3</sup> BiLevel, W = Biaxial, V = Medeco Biaxial CLIQ, K = Medeco KM, N = Medeco X4, C = Classic CLIQ, M = Medeco X4 CLIQ,  
 “-” = Original, Z = Medeco Original KW CLIQ, G = Medeco XT \*\*\*See key section for surcharges for custom coined cut keys or special stamping requirements.

**Note:** (P) refers to **Pinned** and (S) to **Sub-Assembled** at the end of each part string in the price book.