


960H/700 Line Ultra Miniature Indoor Day/Night Cameras


OSD, D-WDR, DNR



MC700

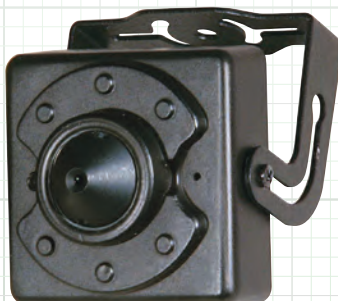

MC700CP

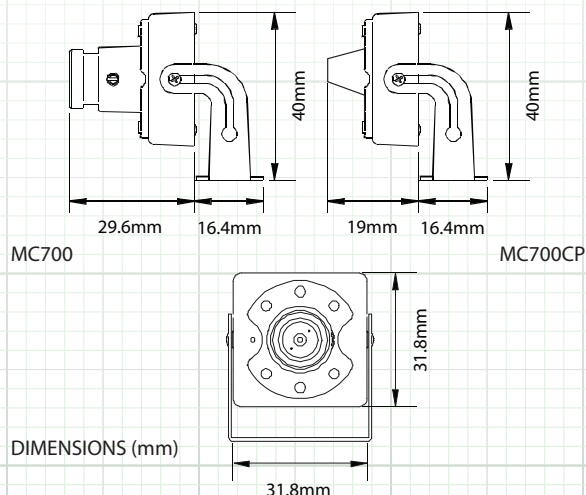

SPECIFICATION	MC700	MC700CP
Imaging Device	1/3" SONY Super HAD II CCD	
Resolution	Color 700 TV Lines – B/W 800 TV Lines	
TV System	NTSC	
Effective Pixels	976 (H) X 494 (V)	
Lens	Standard 3.6mm	Conical Pinhole 3.7mm
Sync System	Internal	
Scanning System	2:1 Interlace	
Video Output	1.0Vp-p 75 OHM Composite BNC	
Minimum Illumination	0.1 Lux	
S/N Ratio	52dB (AGC Off)	
Gamma Characteristic	0.45	
Electronic Shutter Speed	Auto - Manual (1/60 ~ 1/100,000 sec.)	
OSD	Yes Built-in on Back of Camera	
BLC (Backlight Compensation)	DWDR / BLC / HLC / OFF	
AGC (Auto Gain Control)	x0.25 / x0.50 / x1.0	
Day/Night	Electronic Type (Auto, Color, B/W)	
D-WDR (ATR)	Yes, Luminance & Contrast Adjustable	
Power Requirement	Regulated 12 volts DC +/- 10%	
Power Consumption	120mA	
Operating Temperature	14° ~ 122°F	
Weight	1.8 oz	
Housing	Metal Case (Black)	
Dimensions (H x W x D)	1.25" x 1.25" x 1.19"	1.25" x 1.25" x .75"

Note: Specification subject to change without notice

FEATURES

- ◆ SONY 960H Chip / 700 Line Resolution
- ◆ Digital Wide Dynamic Range
- ◆ OSD Control of All Major Functions
- ◆ Auto Electronic Shutter
- ◆ 3.6mm Standard Lens (MC700)
or
3.7mm Conical Pinhole Lens (MC700CP)
- ◆ 12VDC Power Required
- ◆ For Indoor Use

INCLUDED ACCESSORIES

1. Camera User Manual
1. Mounting Screws (set)
1. Camera Mount