


Widescreen LED Security Monitors

18.5" & 21.5" LED Monitors w/HDMI, VGA & BNC Video Inputs, PC Audio In/Output

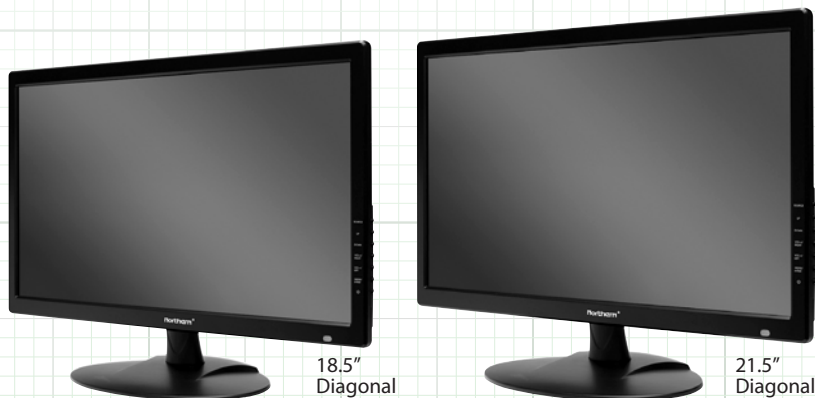

| SPECIFICATION | LED18 | LED22 |
|-------------------------------------|--|--|
| Video System | NTSC/PAL (Auto Sensing) | |
| Max Resolution | 1360 x 768 | 1920 x 1080 |
| Supported Resolutions | 720x400; 640x480; 800x600; 1024x768; 1280x1024; 1360x768; 1920x1080 (scaled) | 720x400; 640x480; 800x600; 1024x768; 1280x1024; 1360x768; 1440x900; 1600x900; 1680x1050; 1920x1080 |
| 3D Comb Filter | Yes | |
| 3D De-Interlace | Yes | |
| OSD (On Screen Display) | Yes | |
| Backlight | LED (RGB) | |
| Active Display Area | 18.5" Diagonally | 21.5" Diagonally |
| Impedence | 75 OHM Self Terminating | |
| Video Input Signals | HDMI, VGA, Composite BNC | |
| Aspect Ratio | Selectable 16:9 or 4:3 in OSD or by One Touch Instant Scaling | |
| Pixel Pitch | 0.28 | 0.248 |
| Color Depth | Over 16 million colors | |
| Brightness | 250 CD/m ² | |
| Contrast Ratio | 2000:1 | |
| Viewing Angle (H/V) | (170/160) | |
| Response Time | 5ms | |
| Auto Adjustment | Yes | |
| Certificates | UL, CUL, CE, FCC, HDMI Forum | |
| Languages | English, Chinese, German, French, Spanish, Italian | |
| Input Voltage | 100 ~ 240VAC (detachable USA line cord provided) | |
| Power Consumption | < 20W | < 30W |
| Video Connections | HDMI, VGA, BNC 1 Input, BNC 2 Input/Output | |
| Audio Connections | PC Audio (3.5mm Stereo) for VGA & BNC Inputs | |
| Dimensions (with stand) (H x W x D) | 13.42 x 17.8 x 7.28 | 14.81 x 20.34 x 7.28 |
| Weight | 5.51lb | 8.75lb |
| Vesa Mounting | Yes (100 x 100) | |
| Operating Temperature | 32° ~ 104°F | |

Note: Specification subject to change without notice


FEATURES

- ◆ 16:9 Aspect Ratio
- ◆ 1360 x 768 Max Resolution (LED18)
- ◆ 1920 x 1080 Max Resolution (LED22)
- ◆ Super Fast 5ms Response Time
- ◆ LED Backlight
- ◆ Built-in Power Supply
- ◆ 3D Comb Filter & 3D De-Interlace
- ◆ Includes 6' HDMI & VGA Cables
- ◆ 3D Digital Noise Reduction
- ◆ HDMI Input
- ◆ VGA & Looping BNC Inputs
- ◆ PC Audio Input/Output
- ◆ Low Power Consumption
- ◆ Full OSD Control of All Monitor Functions
- ◆ Vesa Mounting (100 x 100)
- ◆ UL, CUL, CE Certifications

INCLUDED / ACCESSORIES


1. 6' HDMI Cable
1. 6' VGA Cable
1. 3.5mm Stereo Audio Cable
1. Power Cord
1. User Manual

REAR PANEL CONNECTIONS

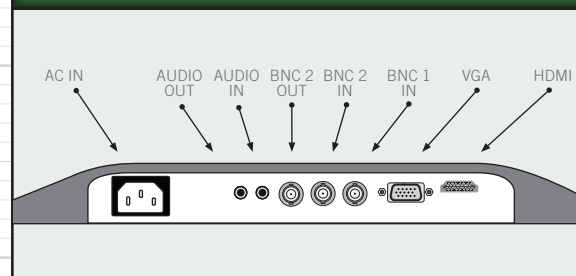


Monitor Dimensions:

LED18

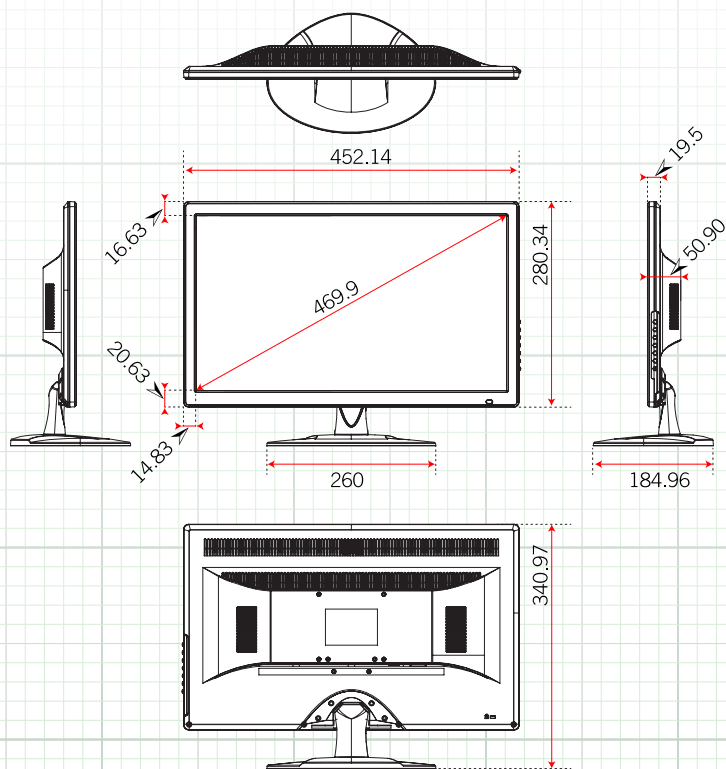

LED22

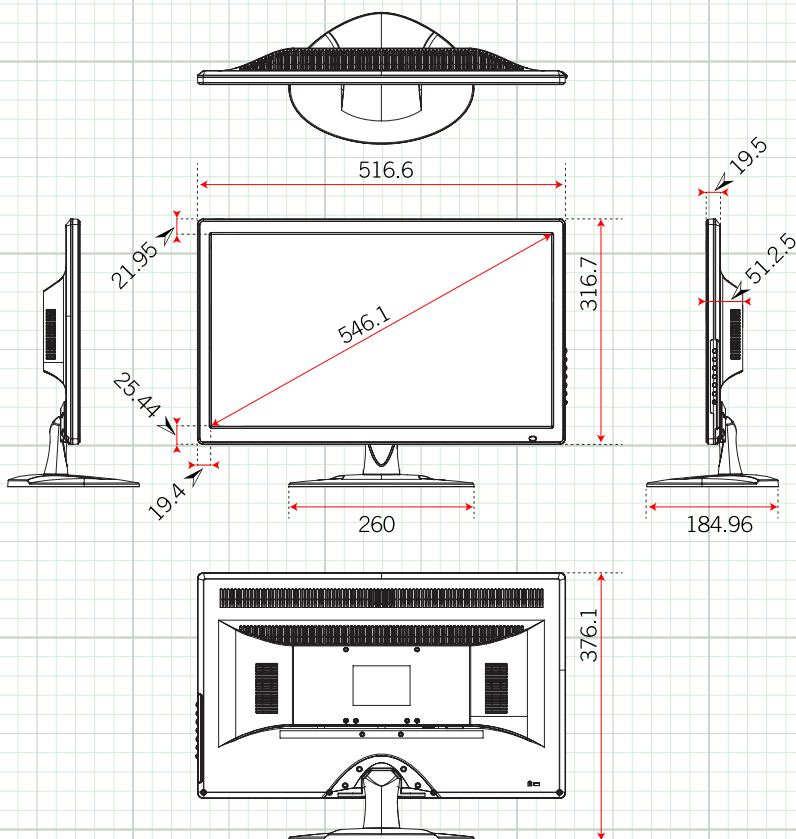

Note: Specification subject to change without notice