


HD Baluns for TVI, CVI, AHD & 960H Cameras

BNC Male to Screw Terminal or BNC Male with 4" Mini Coax to Screw Terminal

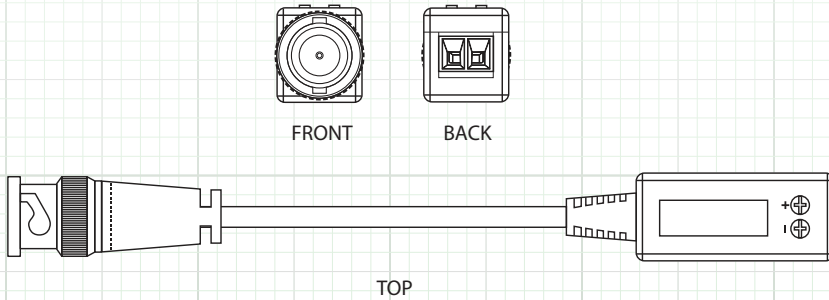


FEATURES

- ◆ Transmission: 300M (720P & 960H), 250M (1080P)
- ◆ Compatible with TVI, CVI, AHD & 960H Formats
- ◆ 4" BNC Male Mini COAX to Screw Terminal for Easy Connection
- ◆ Compact & Mini Size, Eliminates the Need for Bulky Coaxial Cable
- ◆ Passive, No Power Required
- ◆ Built-in ESD, EFT & Transient Protection



VC4PAIRHD

SPECIFICATION	VC4PAIRHD
Connections	Screw Terminal to BNC Male w/4" Mini Coax
Video Signal	1Vp-p, 75 Ohms
Bandwidth	50Hz ~ 60MHz (-3dB)
Transmission Distance	300M (720P & 960H), 250M (1080P)
ESD Protection	30KV (Air), 15KV (Contact); IEC 61000-4-2 Compliant
Cable Type	For Use with CAT5e/CAT6 UTP (Unshielded Twisted Pair)
EFT Protection	40A (5/50ns); IEC 61000-4-4 Compliant
Lightning Protection	2A (8/20µs); IEC 61000-4-5 Compliant
Surge Protection Attack Time	< 1nS
Dimensions	7.2" x 0.6" x 0.5" / 113mm x 16mm x 13mm
Weight	8 Oz

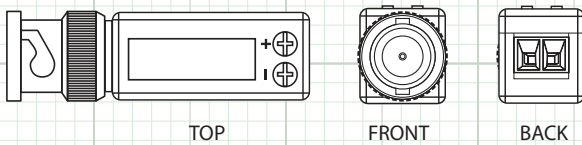

FEATURES

- ◆ Transmission: 300M (720P & 960H), 250M (1080P)
- ◆ Compatible with TVI, CVI, AHD & 960H Formats
- ◆ BNC Male to Screw Terminal for Easy Connection
- ◆ Compact & Mini Size, Eliminates the Need for Bulky Coaxial Cable
- ◆ Passive, No Power Required
- ◆ Built-in ESD, EFT & Transient Protection



VC3PAIRHD

SPECIFICATION	VC3PAIRHD
Connections	Screw Terminal to BNC Male
Video Signal	1Vp-p, 75 Ohms
Bandwidth	50Hz ~ 60MHz (-3dB)
Transmission Distance	300M (720P & 960H), 250M (1080P)
ESD Protection	30KV (Air), 15KV (Contact); IEC 61000-4-2 Compliant
Cable Type	For Use with CAT5e/CAT6 UTP (Unshielded Twisted Pair)
EFT Protection	40A (5/50ns); IEC 61000-4-4 Compliant
Lightning Protection	2A (8/20µs); IEC 61000-4-5 Compliant
Surge Protection Attack Time	< 1nS
Dimensions	1.7" x 0.6" x 0.5" / 43mm x 16mm x 13mm
Weight	8 Oz

Note: Specification subject to change without notice