


## 3.5" VIDEO TEST MONITOR with PTZ CONTROLLER & CABLE TESTER



INCLUDED PROTECTIVE CASE

LCD3TM

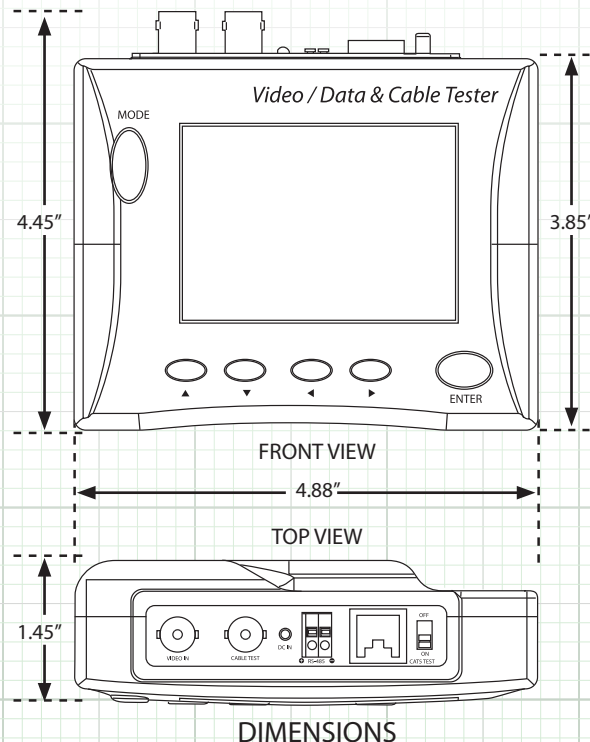

SPECIFICATION	LCD3TM
Panel Size	3.5 Inch Diagonal Color TFT
Resolution	480(H)x235(H) Dot
Active Area	72.00(W)X50.544(H)mm
Dot Pitch	0.150(H)x0.216(V)mm
Pixel Configuration	R.G.B.Delta
View Angle	Top=10deg., Bottom=30deg., Left=40deg., Right=40.,
Panel Dimension	83(W) x 60.5(H) x 3.2(D)mm
Back Light	LED Type
Video Input	NTSC Composite Signal Input ( H=15.734KHZ±0.1KHz V=60Hz±1% )
Video Type	1.0Vp-p / 75Ω
Video System	NTSC
Input Voltage	Built-in Battery or 12VDC Regulated Power Supply
Power Consumption	Normal : 12VDC, 170mA (2W) Charge : 12VDC, 1A (12W)
Working Time	6hr
Charge Time	5hr
Low Voltage Triggering	10.7 V
System Cut off Voltage	9.3 V
Keypad Control	6 KEY ( MODE / UP / DOWN / LEFT / RIGHT / ENTER KEY )
Operating Temperature	32°F ~ 122°F
Weight	11 Oz

- ### FEATURES
- ◆ 480 x 234 Resolution
  - ◆ BNC Video & CAT5 Cable Tester
  - ◆ PTZ Control & Setup
  - ◆ 6-Hour 2200mA Rechargeable Battery
  - ◆ Includes Battery Charger & Case
- ### INCLUDED ACCESSORIES
- (1) Monitor
  - (1) Power Adaptor
  - (1) Cable Tester
  - (2) BNC Converter
  - (1) DC Plug to DC Plug Cable
  - (1) AV Cable
  - (1) User's Manual
  - (1) Protective Carrying Case

Note: Specification subject to change without notice