

CR25LM/DM

Cam Lock For Corbin Russwin Interchangeable Core



For CORBIN RUSSWIN interchangeable core cylinders

SPECIFICATIONS

Cylinder diameter: 1-1/8"

Across flats: 7/8"

Max. material thickness: 1-1/8"

Min. material thickness: 0.08"

Functions: Includes parts for key-retaining or non-key-retaining function

Body: Zinc die cast

Finish: 26D

Packaged: 10 per box

CYLINDER INFORMATION

Cylinder: Not included

Accepts: Corbin/Russwin interchangeable core cylinders

INCLUDED ACCESSORIES

725-PA plastic thumbturn

1125-1 spacer to fit 6 or 7 pin cores

720-PL3 anti-rotation plate

720-3-1 short inverted cam

720-3-2 long vertical cam

720-CDLM lost motion cam shifter

720-CDDM key retaining door cam shifter

720-KR key retaining drawer cam shifter

OPTIONAL ACCESSORIES

Optional cams: 7-3-2, 7-3-3, 7-3-4, 7-3-5

Trim collars: TR200 Series

Switch accessory pack: SW-1


CL-MP-118: Double-D metal punch




US26D finish



INCLUDED CAMS

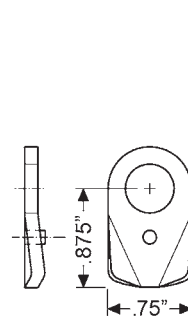


720-3-1
for inverted function

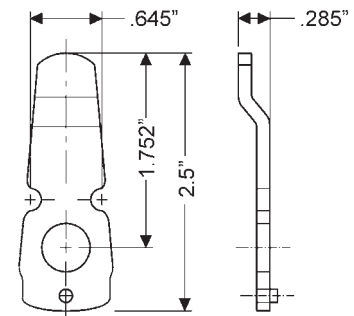

720-3-2
inbent cam for vertical function
(bottom-pin style)

HANDING CHART

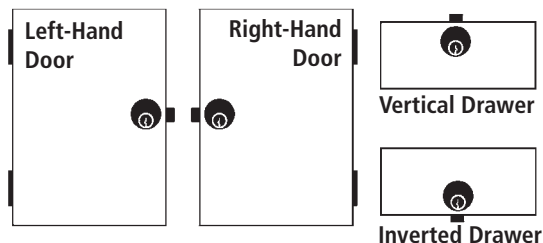


CR25LM/DM

Cam Lock For Corbin Russwin Interchangeable Core

OPTIONAL ACCESSORIES- See our website for a complete list of optional components.

Optional Cams

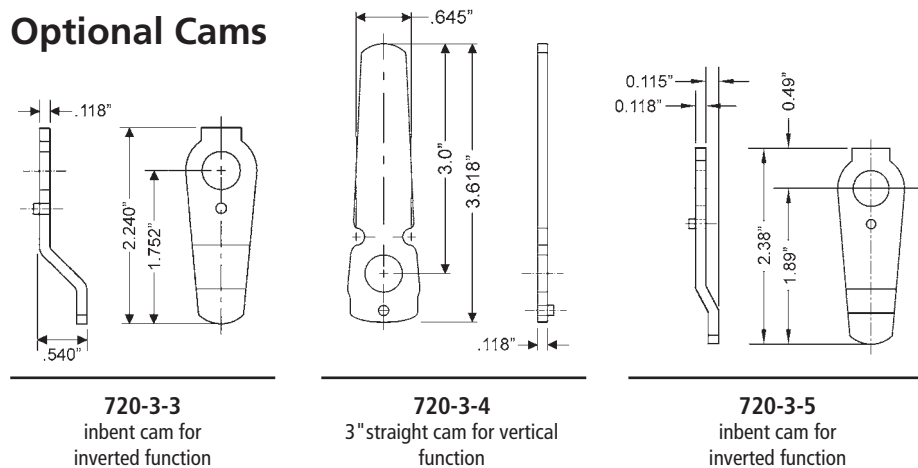

TR200 Series Trim Collars



CL-MP-118 Double-D Metal Punch

Hole size: Punches a DOUBLE "D" hole size approximately 7/8" wide by 1-1/8" high.



DIMENSIONS

