

# 12/24V 2A AC/DC PSU in cabinet

## System specifications

Cabinet construction	ABS plastic/ Powder coated metal
12V DC outputs	2
24V DC outputs	1
Cable type	Twin core flex
PSU type	Switch mode
UL 294 Rated	Yes
ACU integration	Net2 Plus, Net2 nano

## Electrical


Supply voltage input	24V AC/DC
Output current	12V DC (2A) 24V DC (0.75A)
Battery charging current	1A
Frequency	50 - 60Hz

## Other hardware features


Mains failure warning	Yes
Removable rising clamp terminal blocks	Yes
Back up battery	Optional
Tamper switch	Yes
Fitting kit	Yes

## Environment

Operating Temperature	0°C - +45°C +32°F - +113°F
Moisture resistance	No - if used externally, it must be protected in a weatherproof housing
Vandal Resistance	Low

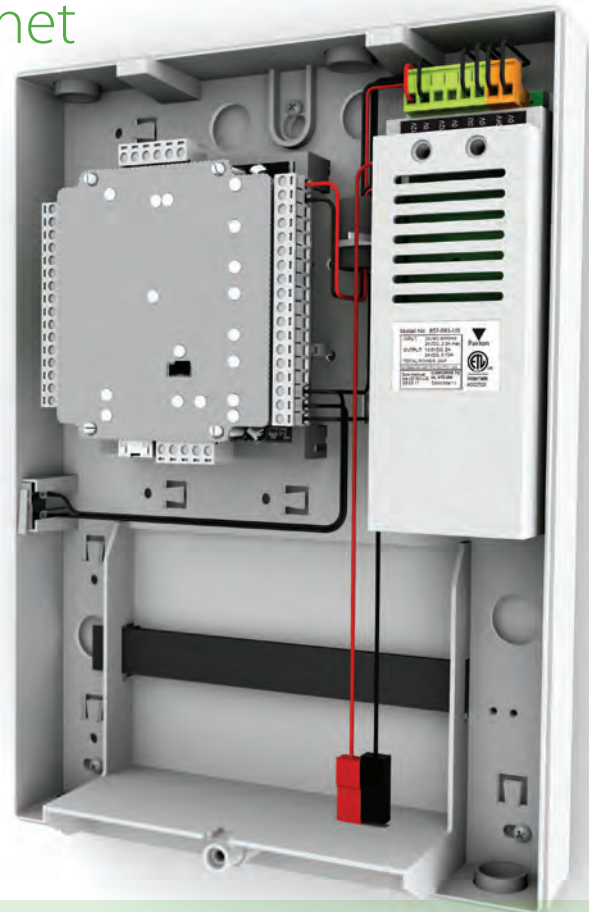

The 12/24V 2A AC/DC Power supply unit is available in either a plastic or metal cabinet. The cabinet can house both the 12/24V 2A AC/DC PSU and a Net2 ACU with the option to accommodate a 12V/7Ah back up battery if desired. A tamper switch is also installed which registers an alarm if the lid is opened when connected to an ACU. Please note that the Net2 nano ACU is not available for integration within the metal cabinet.

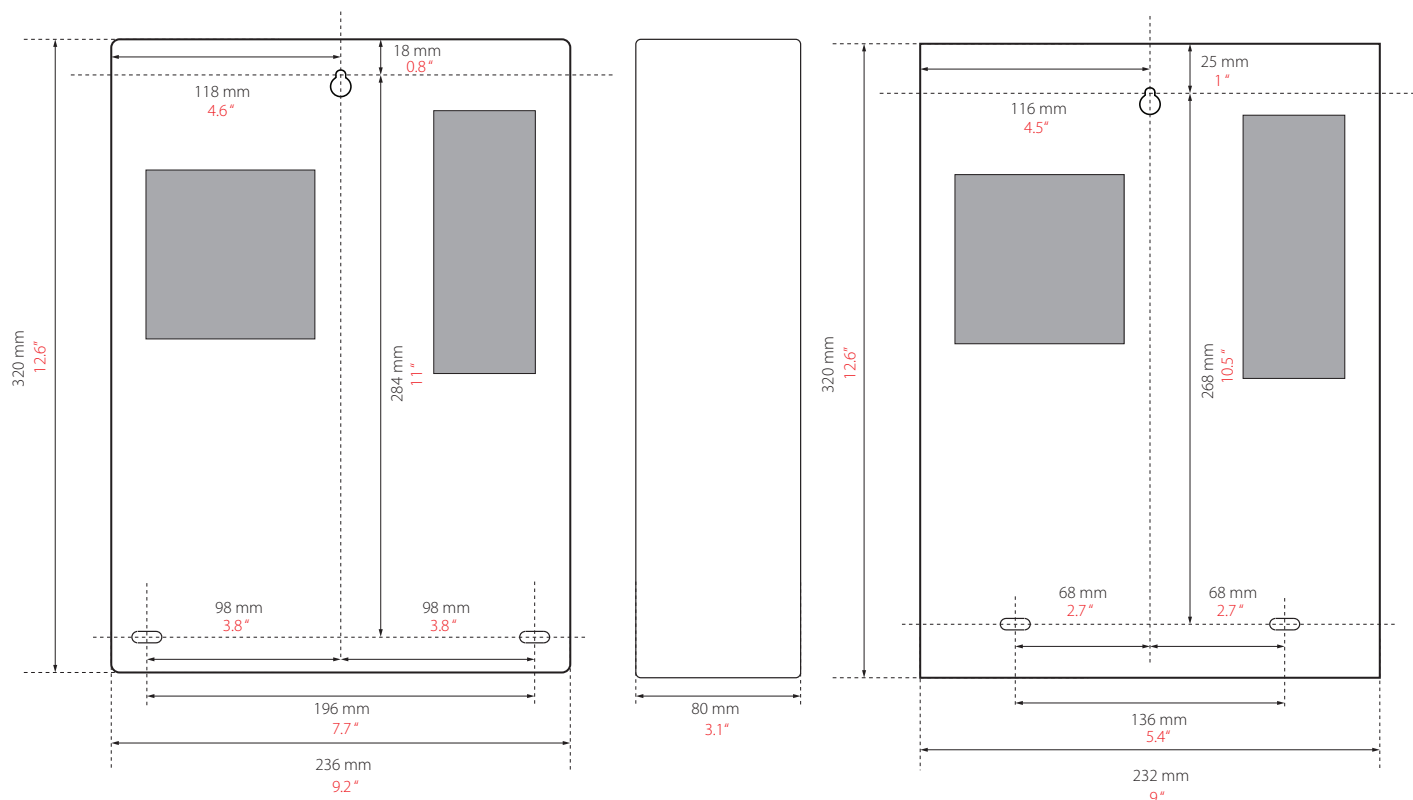

## Accessories and sales codes

12/24V 2A AC/DC power supply  
- Metal cabinet

857-381

Net2 plus 1 door controller - 12/24V 2A AC/DC  
PSU, Plastic cabinet

682-910

Net2 plus 1 door controller - 12/24V 2A AC/DC  
PSU, Metal cabinet

682-810

Net2 nano 1 door controller - 12/24V 2A AC/  
DC PSU, Plastic cabinet

654-910