


Lever finishes

							
	605 Bright brass	606 Satin brass	609 Antique brass	613 Oil rubbed bronze	619 Satin nickel	625 Bright chromium plated	626 Satin chromium plated
S Series locks							
Flair	•	•	•	•	•	•	•
Jupiter	•	•		•	•	•	•
Neptune	•	•		•	•	•	•
Saturn	•	•	•	•	•	•	•

Door handing

With the exception of the Flair lever design, the S Series lock is reversible. Hand information is necessary to ensure proper cylinder orientation in keyed functions, and finish of latchbolt and strike for locks that are to be installed on reverse bevel doors. Follow the diagram to correctly determine the hand of the door.

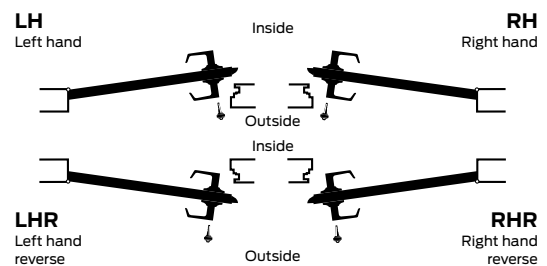

ADA-compliant products





In compliance with the American National Standards Institute (ANSI A117.1) and the Americans with Disabilities Act (ADA), Schlage Lock Company offers a wide selection of locks designed for the needs of the physically challenged. This act is designed to provide protection for people with disabilities.

The intent of ADA is that owners of certain types of buildings must remove barriers and provide people with disabilities with access equal to, or similar to, that available to the general public.

Product information and specifications contained in this catalog are subject to change without notice. Please consult the factory.


S Series lock functions

ANSI A156.2 Series 4000 Grade 2

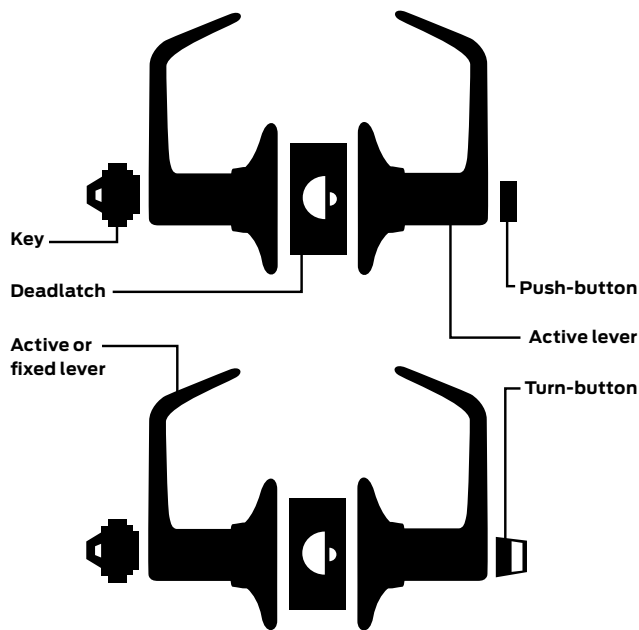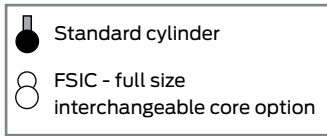


Non-keyed functions

Schlage **S10D** ANSI **F75**
Passage latch
 • Both levers always unlocked.

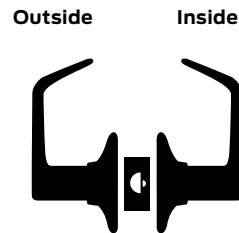

Schlage **S40D** ANSI **F76**
Bath/bedroom privacy lock
 • Push-button locking.
 • Can be opened from outside with small narrow tool.
 • Turning the inside lever releases button.

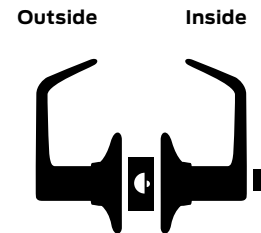

Keyed functions


Schlage **S170** ANSI **—**
Single dummy trim
 • Dummy trim for one side of door.
 • Used for door pull or as matching inactive trim.

Outside/Inside




Schlage **S70PD** ANSI **F84**
Classroom lock
 • Outside lever locked and unlocked by key.
 • Inside lever always unlocked.

Outside Inside

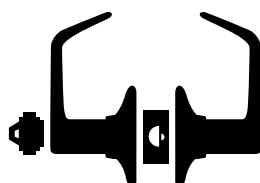


Schlage **S80PD** ANSI **F86**
Storeroom lock
 • Outside lever fixed.
 • Entrance by key only.
 • Inside lever always unlocked.

Outside Inside

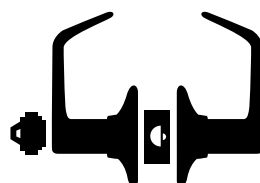

Schlage **S51PD** ANSI **F81**
Entrance lock
 • Outside lever locked and unlocked by key or by turn-button on inside lever.
 • Inside lever always unlocked.

Outside Inside

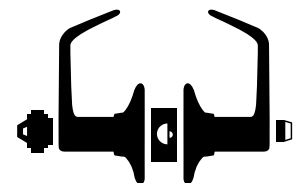

Strikes

All Schlage strikes are furnished complete with screws. The 10-001 standard S Series strike has a 1 1/8" (29 mm) lip. When ordering separately, specify quantity, product number, finish, and lip length. Standard strike is shown in bold type.

 
Strikes - options

- 1", 1 1/8" (Std), 1 1/4", 1 1/2", 1 3/4", 2" (25 mm, 29 mm, 32 mm, 38 mm, 44 mm, 51 mm - 1 1/8" x 2 3/4" (29 mm x 70 mm) square corner, standard
- 1 1/8" (29 Mm) - 1 1/8" x 2 3/4" (29 mm x 70 mm) 1/8" (3 mm) radius, round corner
- 1 3/16", 1 3/8" (30 mm, 35 mm) - 1 1/4" x 4 7/8" (32 mm x 124 mm) ANSI
- 1 1/8" (29 mm) - 1 5/8" x 2 1/4" (41 mm x 57 mm) full lip, square corner
- 1 1/8" (29 mm) - 1 5/8" x 2 1/4" (41 mm x 57 mm) full lip, 1/4" (6 mm) radius, round corner
- Box, ANSI

T-strike – standard

10-001


1 1/8" x 2 3/4" x 3/32"
(29 mm x 70 mm x 2 mm)



ANSI strike

10-025

 
1 1/4" x 4 7/8" x 3/32"
(32 mm x 124 mm x 2 mm)



Full lip - square corner

10-026

 
1 5/8" x 2 1/4" x 3/32"
(41 mm x 57 mm x 2 mm)



Full lip - round corner

10-027

 1 5/8" x 2 1/4" x 3/32"
(41 mm x 57 mm x 2 mm)



Rabbeted latch and strike kit

Rabbeted latch and strike kit finishes: 605, 626.

This kit adapts square corner latches and strikes for 1/2" (13 mm) rabbeted door and frame preparations.

Rabbeted latch and strike kit

39-030

