

# PSP MEDIUM

## Filtered DC Plug-In Power Supply

### Medium Capacity Plug-In Power Supply

The PSP Plug-in DC Power Supplies are available in 12 volts at 3A maximum capacity (model PSP-12-3) and 24 volts at 1.5A maximum capacity (model PSP-24-1.5). 6 ft. output cable is included. Input voltage 100 VAC to 240 VAC. PSPs are ideal for powering a wide range of DC devices where power is available via an outlet.




#### PRODUCT FEATURES

- 36 watts continuous output
- 6 ft. [1.8m] output cable included
- Folding, two-prong AC connector
- UL listed
- MagnaCare® lifetime replacement, no fault warranty

#### » MODELS

PART # | Description

<b>PSP-12-3</b>	Power Supply Plug-In - Switching, Regulated, 12 VDC, 3A
<b>PSP-24-1.5</b>	Power Supply Plug-In - Switching, Regulated, 24 VDC, 1.5A

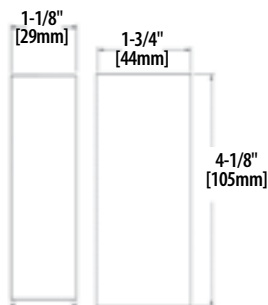

# PSP SMALL

## Filtered DC Plug-in Power Supply

### Small Plug-In Power Supply

PSP plug-in DC power supplies are available in 12 volts at 700 mA maximum capacity (model PSP-12) and 24 volts at 350 mA capacity (model PSP-24). PSPs are ideal for powering a wide range of DC devices. Accepts 120-240 VAC input.




#### PRODUCT FEATURES

- Internal thermal fuse
- 12 ft. [3.6m] output cable included
- UL listed
- 120-240 VAC input
- MagnaCare® lifetime replacement, no fault warranty

#### » MODELS

PART # | Description

<b>PSP-12</b>	Power Supply Plug-In - 12 VDC, 700 mA
<b>PSP-24</b>	Power Supply Plug-In - 24 VDC, 350 mA

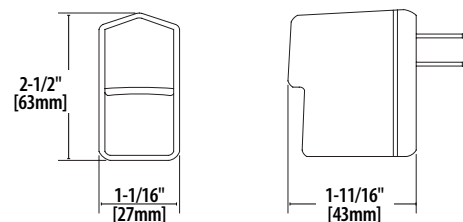

**SECURITRON**  
ASSA ABLOY