


Bored & Auxiliary Lock Cylinders

XC Series

SARGENT®
ASSA ABLOY

Shell & Slide Assembly

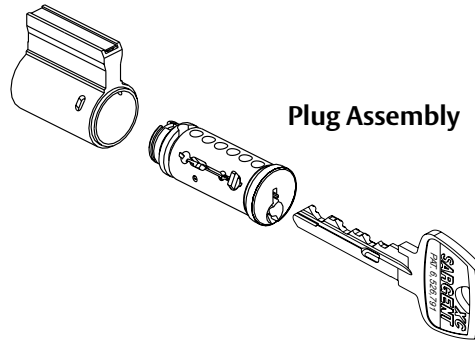

Plug Assembly

Bored Locks

Locks	Complete 6 pin Assembly	Plug Assembly	Shell & Slide Assembly
T-Zone (11 Line)	11-C11-1 (13-4562)	13-4332	13-4334
10 Line	11-C10-1 (13-4560)	13-4332	13-4334
9 Knobs***	11-C8-1 (13-4568)	13-4331	13-4335
8 Knobs***	11-C8-1 (13-4568)	13-4331	13-4335
8L ***	11-C10-1 (13-4560)	13-4332	13-4334
7600 ***	11-C7600-1 (13-4582)	13-4312	13-4339
7 Knobs***	11-C8-1 (13-4568)	13-4331	13-4335
7 Line	11-C10-1 (13-4560)	13-4332	13-4334
6500	11-C10-1 (13-4560)	13-4332	13-4334
6 "B" Knob	11-C6-1B (13-4566)	13-4332	13-4336
6 "S", "N" Knobs	11-C6-1 (13-4564)	13-4332	13-4336
5500	11-C5500-1 (13-4570)	13-4328	13-4338
8X Line	11-C8X-1 (13-5205)	13-4328	13-4338

Auxiliary Locks (Deadbolts)

Locks	Complete 6 pin Assembly	Plug Assembly	Shell & Slide Assembly
464***	11-C460-1 (13-4578)	13-4329	13-4337
465***	11-C460-2 (13-4580)	13-4329	13-4337
474	11-C480-1 (13-4572)	13-4330	13-4337
475	11-C480-3 (13-4576)	13-4330	13-4337
484	11-C480-1 (13-4572)	13-4330	13-4337
485	11-C480-2 (13-4574)	13-4330	13-4337
486	11-C480-3 (13-4576)	13-4330	13-4337
487	11-C480-2 (13-4574)	13-4330	13-4337

• Plug finishes: 4, 15

*** Discontinued Product Line

- Available for all functions except 50 function
- Plug finishes: 4, 15

Note: Use SARGENT 437 C pinning kit for field rekeying

For masterkeyed orders include Keyed Order Leadsheets with keying details as found in General Information section of price book
Parts shown on this page are unique to the XC feature. These plugs and shells cannot be used with non-XC components.

For all other cylinder components, refer to the standard Cylinder & Components section.

XC 11- option not available with 10-, 22-, 51-, 52-, 82-, 83-, 84-, SC- or SE- options.

11-758 Padlock Features

- Cylinder easily removed while in the unlocked position for rekeying
- 6 pin cylinder standard
- Shackle locked by dual ball bearings
- Higher security key capture feature standard
- Key only removed in locked position
- All shackles 5/16" (8mm) diameter
- Optional 11-63 XC LFIC (removable) core available

Complete Padlock	11-758 x Shackle height
Shackle Height (closed)	1" (25mm) standard, 2" (51mm) (-2 suffix) and 4" (102mm) (-4 suffix)
Shackle Material	Stainless steel -standard Boron hardened steel (-HS suffix) Brass chain 9" (228mm) long (-C suffix)
Cylinder assembly with tail piece	13-4584
Plug assembly	13-4332
Shell & Slide assembly	13-4334
Tail piece only	13-1230



11-758-C Shown
(Optional chain shown)


Note: XC 11- option not available with 10-, 22-, 51-, 52-, 82-, F1-82-, 83-, F1-83-, 84-, SC-or SE- options.

XC Series

ASSA ABLOY

XC vs. Standard Keyway Control

NOTE: XC keys and master keys will operate non-XC cylinders. Chart shows how XC key is fully compatible with non-XC cylinders

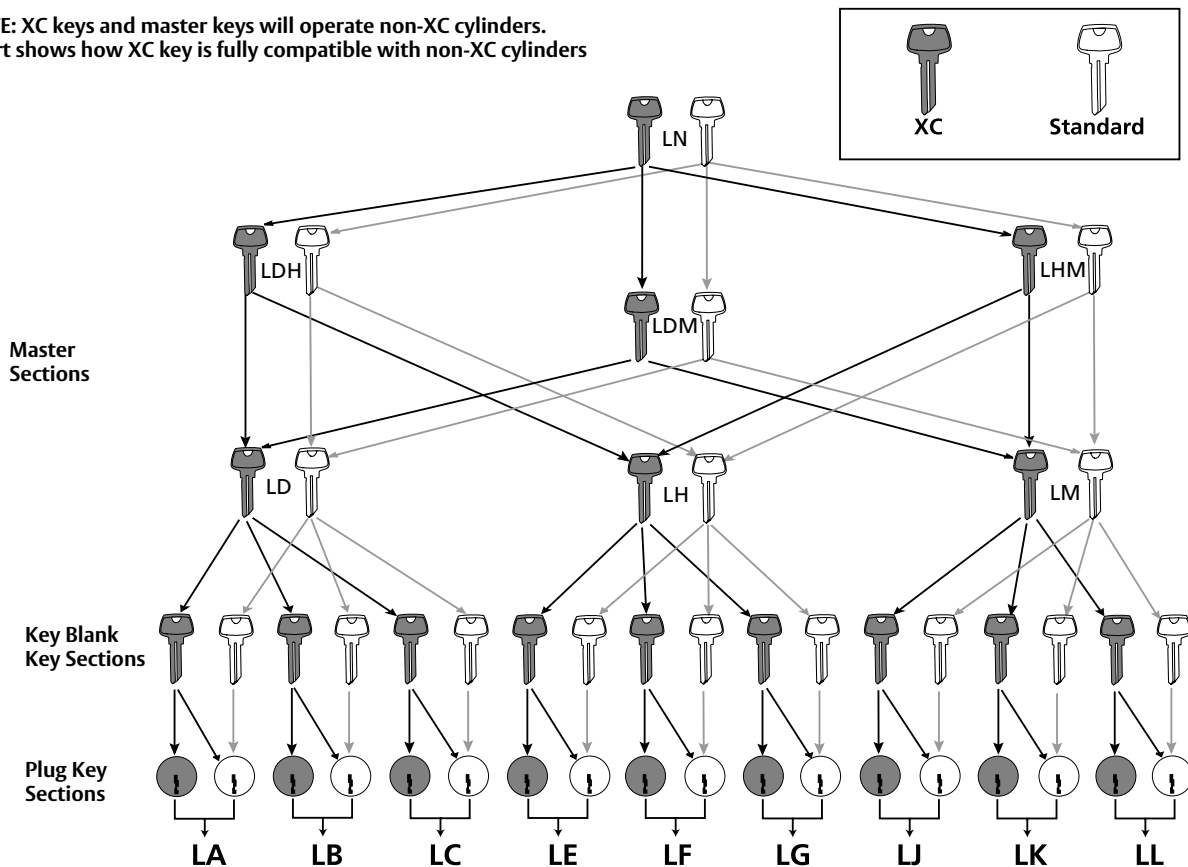

LA family shown above (also available in SARGENT R Multiplex family).

SARGENT Key Blanks

Master Key Section (6 Pin)	Day or Change Key (6 Pin)
Catalog Number 11-X6270	Catalog Number 11-X6275
LD	LA RA
LH	LB RB
LM	LC RC
LDH	LE RE
LHM	LF RF
LN	LG RG
RD	LJ RJ
RH	LK RK
RM	
RDH	
RDM	
RHM	
RN	

Small Format Interchangeable Core Keyways

[illegible]

- Packed 50 per box
- Order by Catalog Number x Keyway