

Bored Locks

HP ALP Trim



The HP Series Bored Lock with ALP push/pull trim provides an aesthetically pleasing alternative to standard push/pull products. Ease of operation allows its use in many environments, including healthcare and education. The paddle shape and location create a comfortable target for door activation without using hands.

Bored Locks

Program	Options	Functions	Trim	Finishes
1-Week & 2-Week	14, 24, 28, WBS	HPU15, HPU65*	ALP	32D

Mechanical Options

- 14- 505 Full Lip Strike
- 24- 2-3/4" (70mm) backset
- 28- 4-7/8" (124mm) ANSI curved lip strike # 808
- WBS Wrought Box Strike

Finishes


- 32D Satin Stainless Steel

Hand

- LH Left Hand
- RH Right Hand

Functions

- HPU15 Passage
- HPU65 Privacy*

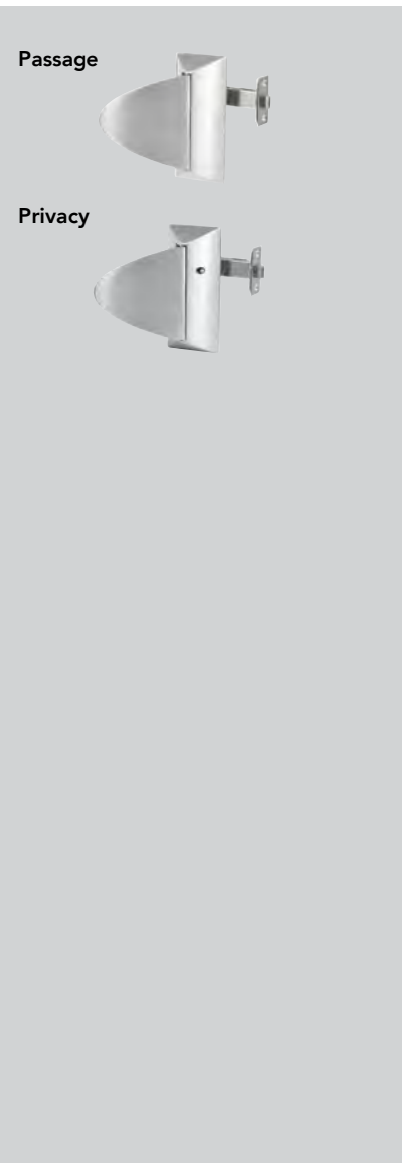

Note: Maximum quantity of 15 units per order

* Handed

Access Control Keypad Operated Products

KP Technology



The KP Series Keypad locks are designed for openings that require standalone, basic authorized entry capabilities. They are battery powered, motor driven, self contained locks that use a microprocessor based controller with non-volatile memory. All programming is done at the door using the keypad with functions selected by the user according to opening requirements.

Program	Options	Functions	Trim	Lever	Finishes
1-Week, 2-Week	60, 70, KD, LC	28-KP-10G77	G, L	B, J, L, P	26D

Program	Options	Functions	Trim	Lever	Finishes
1-Week, 2-Week	60, 70, KD, LC	KP-8276, KP-8278	LN	B, J, L, P	26D

Program	Options	Functions	Trim	Lever	Finishes
1-Week, 2-Week	60, 70, KD, LC	KP-8877	ET	B, J, L, P	32D

Cylinder Options

KD	Keyed Different
60	Disposable Construction Core
70	Interchangeable Core Disposable Plug
LC	Less Cylinder

Finishes

26D	Satin Chrome
32D	Satin Stainless Steel

Note: Electrified products have a total maximum quantity of 50 locks per order

Functions

28-KP-10G77	Cylinder override
KP-8276	Cylinder override and deadbolt
KP-8278	Cylinder override and no deadbolt
KP-8877	Deadbolt and no cylinder override

B Lever



J Lever



L Lever



P Lever



G Rose
(10 Line Only)



L Rose
(10 Line Only)



LN Rose
(10 Line Only)



ET Trim

