

THE BF® SERIES GUN SAFES - 120 MINUTE FIRE

BF®
 Burglary/Fire


BF7240

Shown with Optional Stor-it Cabinets and LED Light Kit



ETL-Intertek laboratory testing confirms that AMSEC's BF® Gun Safes have superior fire protection for two hours at 1,200°F. AMSEC's BF Gun Safes use a proprietary fill material called DryLight, which offers exceptional fire protection without adding excess weight. This superior fire protection was confirmed at ETL-Intertek, the industry's leading independent laboratory for gun safe fire testing. When analyzing the fire performance of competitive safes, be sure to weigh reports from independent laboratories against unverified factory testing or un-tested claims.

SECURITY

Door

- 1/2"-Thick Steel Plate Door (BF7250 & BF6024 have 3/8" steel plate)
- Three-Way Bolt Work
- UL Residential Security Container Burglary Classification
- 12 massive 1-1/2" Chrome Plated Bolts
- **Optional Redundant Boltwork Available**
 - Two installed locks operate completely independently
 - Either lock allows access to safe
 - Protects against any type of lock failure
 - Available on standard and HD models

Body

- 2" double wall steel construction
- Standard total steel thickness 1/4"
- HD series total steel thickness 3/8"
- 4 pre-cut anchor holes

FIRE PROTECTION

- Seamless DryLight Fill
- 120-Minute Intertek Verified Fire Rating
- Dual Door Seals to Protect Against Fire and Smoke

FUNCTIONALITY

- Industry's Most Flexible Interior
- Door Organizer
- Storage for Two Long Guns or Assault Rifles on Door
- Mirrored Back for Added Interior Visibility
- AC Power Outlet

COLOR OPTIONS:

High-Gloss Exterior Colors:

Burgundy Metallic (BY), Pearl Essence (PE), Platinum Metallic (PL), Charcoal Metallic (CM), Macadamia Metallic (MM), Onyx (OX), Rosso Corsa Red (RC), Sapphire Blue (SB)

Textured Exterior Colors:

Granite (GR), Sandstone (ST), Black (BK), Chocolate Brown (CB)

Two-Tone Finishes:

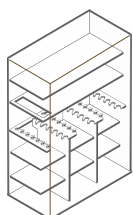
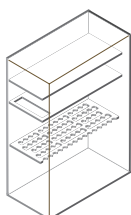
 
 
 
 
 
 
Onyx High-gloss door / Black Textured body or Charcoal Metallic High-gloss door / Granite Textured body

Any combination available on request

Dimensions listed are exterior dimensions. Add 2-7/8" on all BF safes to overall depth for lock and handle.

^ Add 5lbs for Redundant Boltwork option.

Model	Outside Dimension H x W x D	Thickness (Inches)		Interior Capacity	Wt. Lbs.^
		Door Overall / Steel plate	Body		
BF7250	71-1/4" x 50" x 28"	4 ⁵ / ₈ / 3/8"	2	14-14-14-28-42 + 2 Gun	1,789
BF7250HD	71-1/4" x 50" x 28"			73 + 2 Gun	2,204
BF7240	71-1/4" x 40" x 26"	4 ³ / ₄ / 1/2"	2	12-12-12-24-36 + 2 Gun	1,585
BF7240HD	71-1/4" x 40" x 26"			58 + 2 Gun	1,923
BF6636	65-1/4" x 36" x 26"	4 ³ / ₄ / 1/2"	2	12-12-24 + 2 Gun	1,319
BF6636HD	65-1/4" x 36" x 26"				1,601
BF6030	59-1/4" x 30" x 26"	4 ³ / ₄ / 1/2"	2	11-11-22 + 2 Gun	1,036
BF6030HD	59-1/4" x 30" x 26"				1,244
BF6032	59-1/4" x 30" x 21"	4 ³ / ₄ / 1/2"	2	9-9-18 + 2 Gun	913
BF6032HD	59-1/4" x 30" x 21"				1,118
BF6024	59-1/4" x 24" x 21"	4 ⁵ / ₈ / 3/8"	2	8-8-16 Gun + 1 Gun	720
BF6024HD	59-1/4" x 24" x 21"				893

BF7250 STANDARD
GUN INTERIORBF7250
73 GUN INTERIORBF7240 STANDARD
GUN INTERIORBF7240
58 GUN INTERIORBF6636 STANDARD
GUN INTERIORBF6030 STANDARD
GUN INTERIORBF6032 STANDARD
GUN INTERIORBF6024 STANDARD
GUN INTERIOR