



NF SERIES - 90 MINUTE FIRE

GUN SAFES



NF6030

The American Security Products NF Gun Safe offers both superior performance and value. For burglary protection, it has a stout ¼"-thick steel plate in the door. For fire protection, it is lined with 3 layers of drywall that are strategically engineered for optimal fire protection. This enables the NF Gun Safe to pass a verified 90-minute fire test at Intertek, an independent testing laboratory.

SECURITY

- ¼"-Thick Steel Plate Door
- Four-Way Bolt Work
- 11-Gauge Steel Body
- UL Residential Security Container Burglary Classification
- 14 Massive 1½" Chrome Plated Bolts
- 4 Pre-Cut Anchor Holes

FIRE PROTECTION


- Lined with Three Layers of Drywall (4 on top and bottom)
- 90-Minute Intertek Verified Fire Rating
- Dual Door Seals to Protect Against Fire and Smoke

FUNCTIONALITY


- Industry's Most Flexible Interior
- Door Organizer
- Storage for Two Long Guns or Assault Rifles on Door (One on NF5924)
- AC Power Outlet




NF6030 WITH NEW STANDARD STOR-IT PDO AND OPTIONAL STOR-IT CABINETS

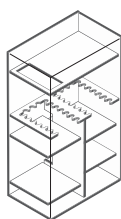


NF6036/NF6036E5
STANDARD
GUN INTERIOR

 

NF6030/NF6030E5
STANDARD
GUN INTERIOR

 

NF6032/NF6032E5
STANDARD
GUN INTERIOR

 

NF5924/NF5924E5
STANDARD
GUN INTERIOR

COLOR OPTIONS:

High-Gloss Exterior Colors:

Burgundy Metallic (BY), Pearl Essence (PE), Platinum Metallic (PL), Charcoal Metallic (CM), Macadamia Metallic (MM), Onyx (OX), Rosso Corsa Red (RC), Sapphire Blue (SB)

Textured Exterior Colors:

Granite (GR), Sandstone (ST), Black (BK), Chocolate Brown (CB)

Two-Tone Finishes:

Onyx High-gloss door / Black Textured body or Charcoal Metallic High-gloss door / Granite Textured body

Any combination available on request

NFE5 SERIES STANDARD COLOR:

Textured Black (BK) with Black Nickel Hardware (LTN)

Model	Outside Dimension H x W x D	Thickness (Inches)		Interior Capacity	Wt. Lbs.
		Door Overall / Steel plate	Body		
NF6036 / NF6036E5	59" x 36" x 26"	4¼ / ¼"	11 ga	17-17-34 + 2 Gun	977
NF6030 / NF6030E5	59" x 30" x 26"	4¼ / ¼"	11 ga	14-14-28 + 2 Gun	854
NF6032 / NF6032E5	59" x 30" x 21"	4¼ / ¼"	11 ga	9-9-18 + 2 Gun	761
NF5924 / NF5924E5	59" x 24" x 18"	4¼ / ¼"	11 ga	8-8-16 Gun + 1 Gun	600

Dimensions listed are exterior dimensions. Add 2-7/8" to overall depth for lock and handle.