


# Standard Dome Accessories


Accessories for Indoor/Outdoor Ceiling, Wall, Pole and Corner Mounting Solutions




**Ceiling Mount Configuration**

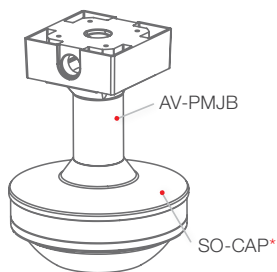


**Wall Mount Configuration with Pole Mount Adapter**

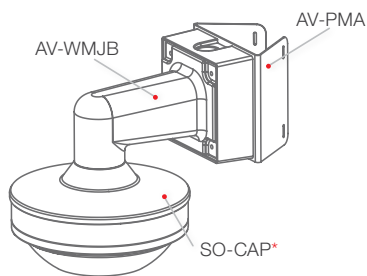

**Wall Mount Configuration**

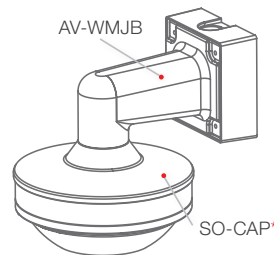

**Wall Mount Configuration with Corner Mount Adapter**

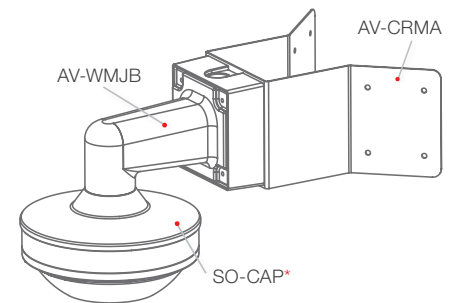


## Cap Options:

**SO-CAP**



Works with SurroundVideo® Omni and SurroundVideo® Omni G2

**SO3-CAP**

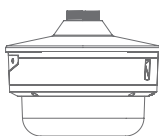

Works with SurroundVideo® Omni G3

**SV-CAP**



Works with SurroundVideo® and SurroundVideo® G5

**MD-CAP**



Works with MegaDome® 4K, MegaDome® Series, SurroundVideo® G5 Mini and MegaVideo® Compact D4SO

## Compatible Cameras:



**SurroundVideo® Series**



**MegaDome® 4K**



**MegaDome® Series**



**MegaVideo® Compact D4SO**

\* Can be switched with SO3-CAP, SV-CAP or MD-CAP

## AV-EBAR

Electrical Box Adapter Round



### Features:

- Easy Installation and Superior Design
- Heavy Duty Enclosure Protection for Applications in Harsh Environments
- Die-Cast Aluminum is Resistant to Impact and Salt Damage


### Compatibility

Compatible with 3/4" NPT standard

Works with MegaBall® Series, MegaDome® Series, MicroDome® Series -S cameras, SurroundVideo® Series, SurroundVideo® Omni Series, MegaVideo® D4SO Housing, MCD-CMT and MB2-JBA

### Mechanical

<b>Casing</b>	Die-Cast Aluminum	
	IP66 Weather Proof Standard	
	IK-10 Impact-Resistant	
<b>Color</b>	Ivory (Pantone Cool Gray 1C)	
<b>Dimensions</b>	Ø6" (152.4mm) x 0.15" W (4mm)	
<b>Weight</b>	<b>w/o Camera</b>	0.4lbs (0.18kg)

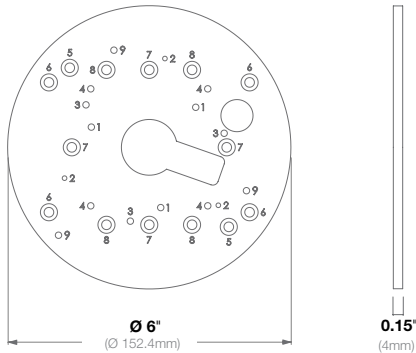

### Hole No. Model Compatibility

1	MegaBall Series Wall Mount (legacy), MCD-CMT
2	MegaBall Series Dome Mount
3	MegaBall Series Bell Mount, MicroDome Series Surface Mount*
4	MegaDome 2*, SurroundVideo Series Panoramics*, MegaVideo D4SO Housing, MB2-JBA
5	4S Box
6	4-11/16" Square Box
7	Single Gang Box
8	Double Gang Box
9	SurroundVideo Omni Series

\* The mounting plate on MegaDome 4K, SurroundVideo G5 Mini, and MicroDome Duo negate the need for a separate electrical box adapter and therefore this accessory is not applicable.

### Quick Installation:

1. Pass cables through the center hole of the adapter plate.
2. Attach the adapter plate to the electrical box (sold separately) using the appropriate hardware and mounting holes.
3. Attach the compatible part noted above.

## AV-EBAS

Electrical Box Adapter Square



### Features:

- Easy Installation and Superior Design
- Heavy Duty Enclosure Protection for Applications in Harsh Environments
- Die-Cast Aluminum is Resistant to Impact and Salt Damage


### Compatibility

Compatible with 3/4" NPT standard

Works with MegaDome® Series, MegaView® Series, MicroBullet®, SurroundVideo® Panoramic Series, MegaVideo® D4SO Housing, AV-JBA, AV-WMJB, AV-SWMJB, MCD-WMT, MDD-WMT, HSG2-WMT, and AV-PMJB

### Mechanical

<b>Casing</b>	Die-Cast Aluminum	
	IP66 Weather Proof Standard	
	IK-10 Impact-Resistant	
<b>Color</b>	Ivory (Pantone Cool Gray 1C)	
<b>Dimensions</b>	4.7" L (120mm) x 0.15" W (4mm) x 4.7" H (120mm)	
<b>Weight</b>	<b>w/o Camera</b>	0.33lbs (0.13kg)

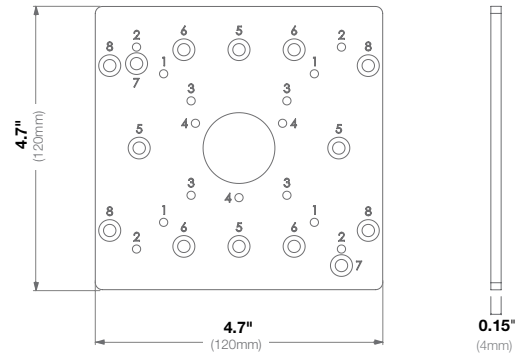

### Hole No. Model Compatibility

1	AV-JBA, AV-WMJB, AV-PMJB, MegaDome 2*, MegaView 2 (standard), SurroundVideo Panoramics*, MegaVideo D4SO Housing
2	HSG2-WMT, AV-WMJB bracket, AV-PMJB bracket, MegaView 2 bracket
3	AV-SWMJB, MCD-WMT, MDD-WMT
4	MicroBullet
5	Single Gang Box
6	Double Gang Box
7	4S Box
8	4-11/16" Square Box

\* The mounting plate on MegaDome 4K and SurroundVideo G5 Mini negate the need for a separate electrical box adapter and therefore this accessory is not applicable.

### Quick Installation:

1. Pass cables through the center hole of the adapter plate.
2. Attach the adapter plate to the electrical box (sold separately) using the appropriate hardware and mounting holes.
3. Attach the compatible part noted above.

AV-PMJB

Pendant Mount Bracket with Junction Box






Features:

- Easy Installation and Superior Design
- Heavy Duty Enclosure Protection for Applications in Harsh Environments
- Die-Cast Aluminum is Resistant to Impact and Salt Damage

Compatibility	Compatible with 1.5" NPT Female
	Works with SurroundVideo® Series, MegaDome® 4K, MegaDome® Series, and MegaVideo® Compact D4SO

Mechanical	Casing	Die-Cast Aluminum
		IP66 Weather Proof Standard
		IK-10 Impact-Resistant
	Color	Ivory (Pantone® Cool Gray 1C)
	Dimensions	5.87" H (149.31mm) x 4.69" W (119.20mm)
	Weight	w/o Camera 2.12lbs (0.96kg)

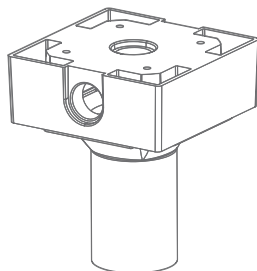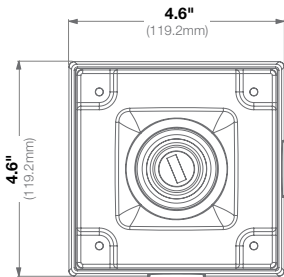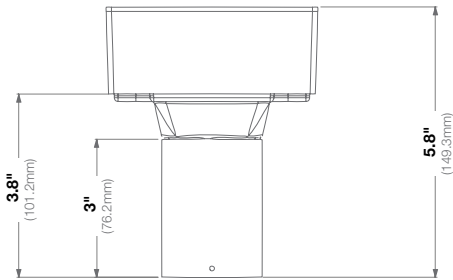

AV-WMJB

Wall Mount Bracket with Junction Box






Features:

- Easy Installation and Superior Design
- Heavy Duty Enclosure Protection for Applications in Harsh Environments
- Die-Cast Aluminum is Resistant to Impact and Salt Damage

Compatibility	Compatible with 1.5" NPT Female
	Works with SurroundVideo® Series, MegaDome® 4K, MegaDome® Series, and MegaVideo® Compact D4SO

Mechanical	Casing	Die-Cast Aluminum
		IP66 Weather Proof Standard
		IK-10 Impact-Resistant
	Color	Ivory (Pantone® Cool Gray 1C)
	Dimensions	7.68" L (195.05mm) x 4.69" W (119.20mm)
	Weight	w/o Camera 2.49lbs (1.13kg)

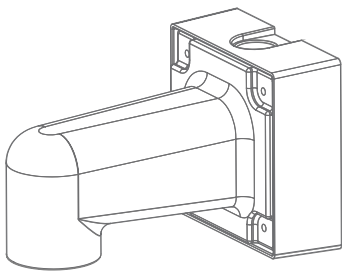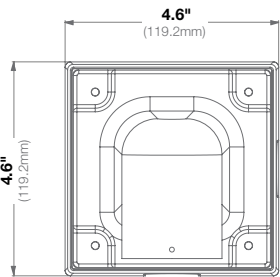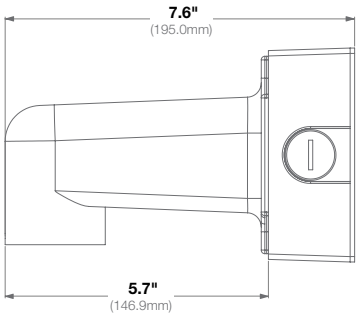

AV-PMA

Pole Mount Adapter





Features:

- Easy Installation and Superior Design
- Heavy Duty Enclosure Protection for Applications in Harsh Environments
- Die-Cast Aluminum is Resistant to Impact and Salt Damage

**Compatibility** Works with AV-WMJB, AV-SWMJB, MDD-WMT, MCD-WMT, and AV-JBA

<b>Mechanical</b>	<b>Casing</b>	Die-Cast Aluminum
		IP66 Weather Proof Standard
		IK-10 Impact-Resistant
	<b>Color</b>	Ivory (Pantone® Cool Gray 1C)
	<b>Dimensions</b>	5.01" W (127.32mm) x 4.92" H (125mm)
	<b>Weight</b>	<b>w/o Camera</b> 0.32lbs (0.15kg)

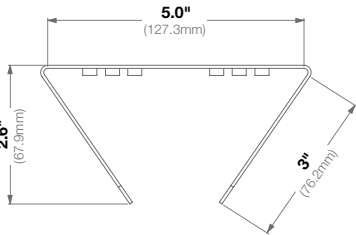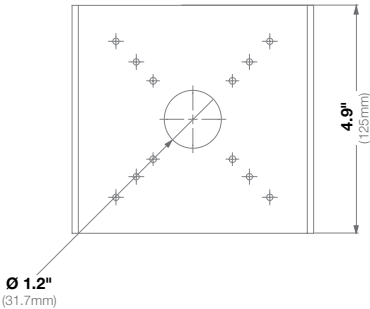

AV-CRMA

Corner Mount Adapter





Features:

- Easy Installation and Superior Design
- Heavy Duty Enclosure Protection for Applications in Harsh Environments
- Die-Cast Aluminum is Resistant to Impact and Salt Damage

**Compatibility** Works with AV-WMJB, AV-SWMJB, MDD-WMT, MCD-WMT, and AV-JBA

<b>Mechanical</b>	<b>Casing</b>	Die-Cast Aluminum
		IP66 Weather Proof Standard
		IK-10 Impact-Resistant
	<b>Color</b>	Ivory (Pantone® Cool Gray 1C)
	<b>Dimensions</b>	13.04" W (331.25mm) x 4.92" H (125mm)
	<b>Weight</b>	<b>w/o Camera</b> 0.59lbs (0.27kg)

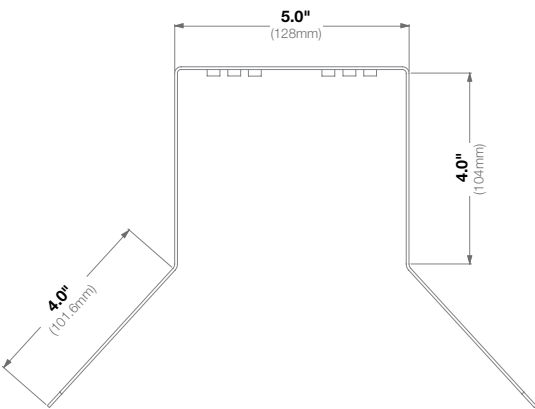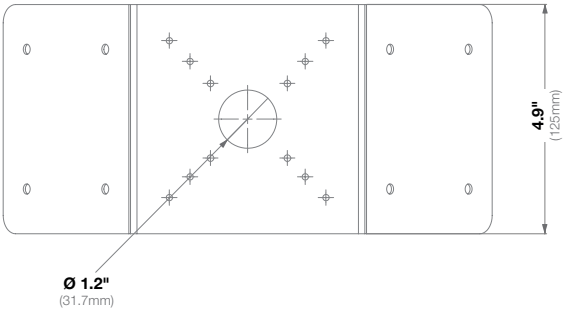


SO3-CAP  
Mounting Cap



- Features:**
- Easy Installation and Superior Design
  - Heavy Duty Enclosure Protection for Applications in Harsh Environments
  - Die-Cast Aluminum is Resistant to Impact and Salt Damage

Compatibility	Compatible with 1.5" NPT Male	
	Works with SurroundVideo® Omni G3	

Mechanical	Casing	Die-Cast Aluminum	
		IP66 Weather Proof Standard	
		IK-10 Impact-Resistant	
	Color	Ivory (Pantone® Cool Gray 1C)	
	Dimensions	Ø 8.9" (227.4mm) x 1.8" H (46.5mm)	
	Weight	w/o Camera	1.22lbs (0.55kg)

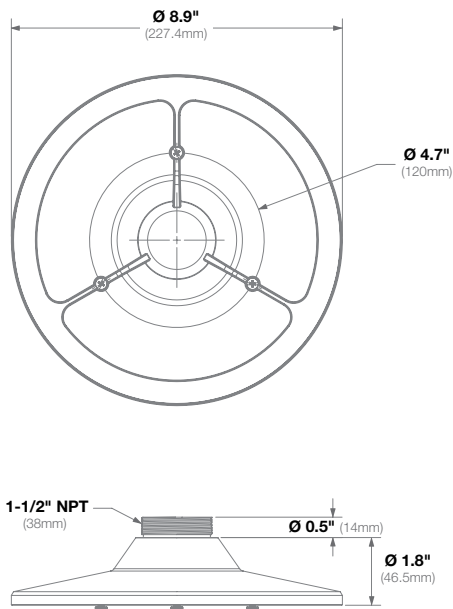


SO-CAP  
Mounting Cap



- Features:**
- Easy Installation and Superior Design
  - Heavy Duty Enclosure Protection for Applications in Harsh Environments
  - Die-Cast Aluminum is Resistant to Impact and Salt Damage

Compatibility	Compatible with 1.5" NPT Male	
	Works with SurroundVideo® Omni and SurroundVideo® Omni G2	

Mechanical	Casing	Die-Cast Aluminum	
		IP66 Weather Proof Standard	
		IK-10 Impact-Resistant	
	Color	Ivory (Pantone® Cool Gray 1C)	
	Dimensions	Ø 7.87" (200mm) x 1.6" H (40.79mm)	
	Weight	w/o Camera	0.85lbs (0.39kg)

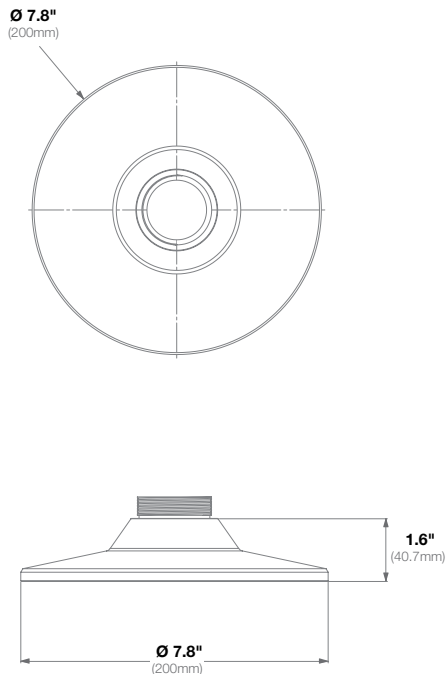


SV-CAP  
Mounting Cap



- Features:**
- Easy Installation and Superior Design
  - Heavy Duty Enclosure Protection for Applications in Harsh Environments
  - Die-Cast Aluminum is Resistant to Impact and Salt Damage

Compatibility	Compatible with 1.5" NPT standard	
	Works with SurroundVideo®** and SurroundVideo® G5	

Mechanical	Casing	Die-Cast Aluminum	
		IP66 Weather Proof Standard	
		IK-10 Impact-Resistant	
	Color	Ivory (Pantone® Cool Gray 1C)	
	Dimensions	Ø 7.4" (189mm) x 4.33" H (110mm)	
	Weight	w/o Camera	1.47lbs (0.69kg)

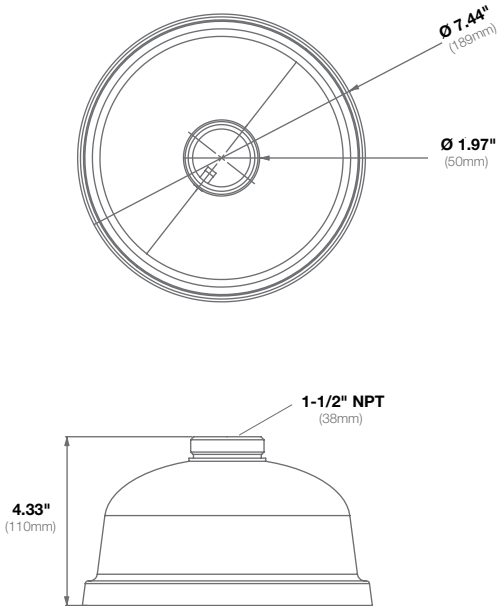


MD-CAP  
Mounting Cap



- Features:**
- Easy Installation and Superior Design
  - Heavy Duty Enclosure Protection for Applications in Harsh Environments
  - Die-Cast Aluminum is Resistant to Impact and Salt Damage

Compatibility	Compatible with 1.5" NPT standard	
	Works with MegaDome® 4K, MegaDome® Series, SurroundVideo® G5 Mini and MegaVideo® Compact D4SO	

Mechanical	Casing	Die-Cast Aluminum	
		IP66 Weather Proof Standard	
		IK-10 Impact-Resistant	
	Color	Ivory (Pantone® Cool Gray 1C)	
	Dimensions	Ø 6.06" (154.1mm) x 2.57" H (65.3mm)	
	Weight	w/o Camera	1.02lbs (0.465kg)

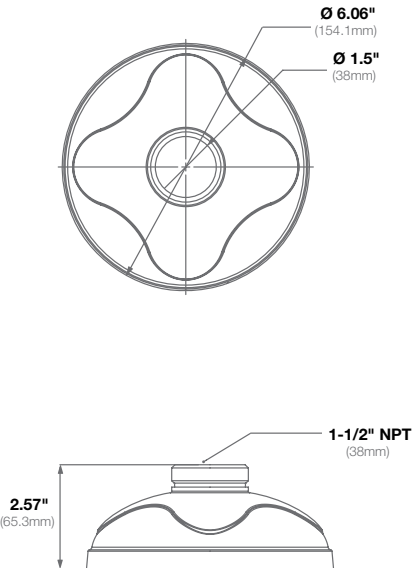

\*\* SurroundVideo models with WDR are compatible with MD-CAP and AV-FMA accessories due to their smaller form factor housing

## SO3-FMA


Flush Mount Adapter

**Features:**

- Easy Installation and Superior Design
- Low Profile Installation

**Compatibility** Works with SurroundVideo® Omni G3

<b>Mechanical</b>	<b>Casing</b>	Aluminum and Plastic	
	<b>Color</b>	Ivory (Pantone® Cool Gray 1C)	
	<b>Dimensions</b>	Ø 11.2" (285.2mm) x 3.21" H (81.7mm)	
	<b>Weight</b>	<b>w/o Camera</b>	2.43lbs (1.1kg)

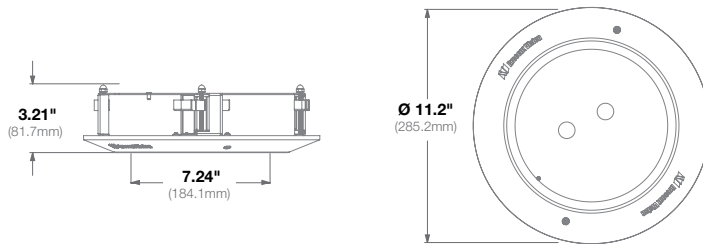

## SV-FMA


Flush Mount Adapter

**Features:**

- Easy Installation and Superior Design
- Low Profile Installation

**Compatibility** Works with SurroundVideo®\*\* and SurroundVideo® G5

<b>Mechanical</b>	<b>Casing</b>	Aluminum and Plastic	
	<b>Color</b>	Ivory (Pantone® Cool Gray 1C)	
	<b>Dimensions</b>	Ø 8.54" (217mm) x 2.92" H (74.2mm)	
	<b>Weight</b>	<b>w/o Camera</b>	1.3lbs (0.59kg)

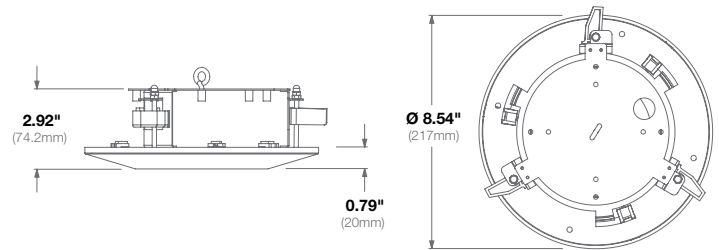

## SO-FMA


Flush Mount Adapter

**Features:**

- Easy Installation and Superior Design
- Low Profile Installation

**Compatibility** Works with SurroundVideo® Omni and SurroundVideo® Omni G2

<b>Mechanical</b>	<b>Casing</b>	Aluminum and Plastic	
	<b>Color</b>	Ivory (Pantone® Cool Gray 1C)	
	<b>Dimensions</b>	Ø 9.46" (240.3mm) x 2.67" H (67.9mm)	
	<b>Weight</b>	<b>w/o Camera</b>	1.15lbs (0.52kg)

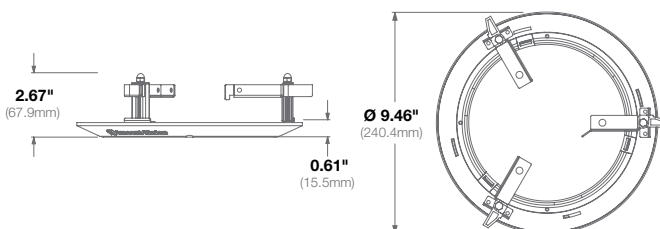

## AV-FMA


Flush Mount Adapter

**Features:**

- Easy Installation and Superior Design
- Low Profile Installation

**Compatibility** Works with MegaDome® 4K, MegaDome® Series, SurroundVideo® G5 Mini and MegaVideo® Compact D4SO

<b>Mechanical</b>	<b>Casing</b>	Aluminum and Plastic	
	<b>Color</b>	Ivory (Pantone® Cool Gray 1C)	
	<b>Dimensions</b>	Ø 7.36" (187mm) x 3.9" H (99.1mm)	
	<b>Weight</b>	<b>w/o Camera</b>	1.10lb (0.5kg)

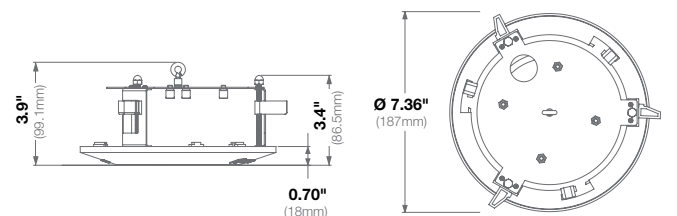

\*\* SurroundVideo models with WDR are compatible with MD-CAP and AV-FMA accessories due to their smaller form factor housing

AV-JBA

Square Junction Box Adapter




Features:

- Easy Installation and Superior Design
- Heavy Duty Enclosure Protection for Applications in Harsh Environments
- Die-Cast Aluminum is Resistant to Impact and Salt Damage

Compatibility	Compatible with 3/4" NPT standard	
	Works with AV-PMJB***, AV-WMJB***, HSG2-WMT, and MegaView® 2***	

Mechanical	Casing	Die-Cast Aluminum	
		IP66 Weather Proof Standard	
		IK-10 Impact-Resistant	
	Color	Ivory (Pantone® Cool Gray 1C)	
	Dimensions	4.7" L (120mm) x 4.7" W (120mm) x 1.89" H (48.1mm)	
	Weight	w/o Camera	1.3lbs (0.63kg)

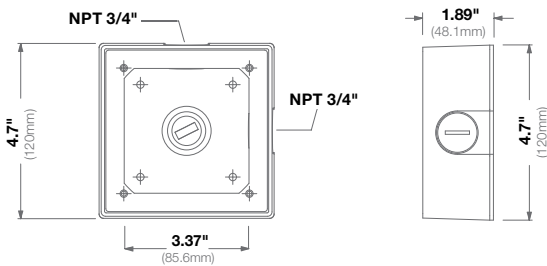

SO-SSA

Sun Shield Accessory




Features:

- Easy Installation and Superior Design
- Protects SurroundVideo Omni Series Sensors from Sun Glare

Compatibility	Works with SurroundVideo® Omni and SurroundVideo® Omni G2	
---------------	---	--

Mechanical	Casing	Plastic	
	Color	Ivory (Pantone® Cool Gray 1C)	
	Dimensions	11.03" L (280.22mm) x 0.79" H (20.25mm)	
	Weight	w/o Camera	0.17lb (0.08kg)

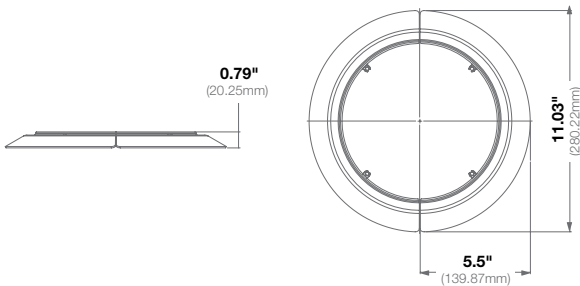

MD-JBA

Round Junction Box Adapter




Features:

- Easy Installation and Superior Design
- Heavy Duty Enclosure Protection for Applications in Harsh Environments
- Die-Cast Aluminum is Resistant to Impact and Salt Damage

Compatibility	Compatible with 3/4" NPT standard	
	Works with MegaDome® 4K, MegaDome® Series, SurroundVideo® G5 Mini and MegaVideo® Compact D4SO	

Mechanical	Casing	Die-Cast Aluminum	
		IP66 Weather Proof Standard	
		IK-10 Impact-Resistant	
	Color	Ivory (Pantone® Cool Gray 1C)	
	Dimensions	Ø 6.06" (154mm) x 1.5" H (40mm)	
	Weight	w/o Camera	1lbs (0.45kg)

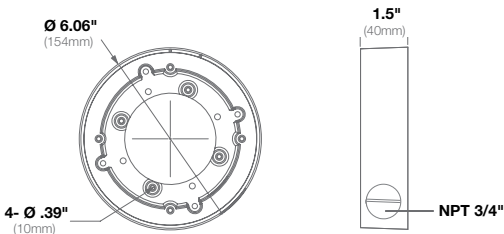

\*\*\* Replacement part for these models